



**Adjustable handles with new retaining screw with six-lobed socket to fit Torx® tool:**

**Current retaining screw with hexagon socket**

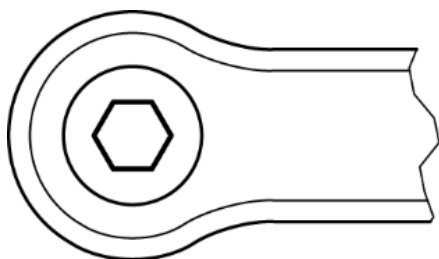

**New retaining screw with six-lobed socket**

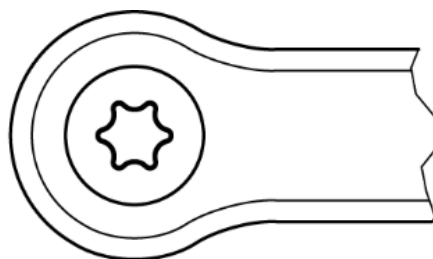

Dear Elesa Partners,

We inform you that, due to a project of improvement, the available existing products [ERM.](#), [ERZ.](#), [GN 300](#), [GN 300.1](#), [GN 300.4](#), [GN 300.5](#), [GN 302](#) and [GN 306](#) adjustable handles will be available in the version with hexagon socket while stocks last. Then they will be replaced by adjustable handles having a six-lobed socket to fit Torx® tool (registered trademark of TEXTRON INC.).



**GN 300**  
**GN 300.1**  
**GN 300.5**

**GN 300.4**



**GN 302**

**ERM.**



**ERZ.**



**GN 306**



See also the updated datasheets of the mentioned products on [elesa.com](http://elesa.com).

Thank you for your attention. We remain at your disposal for any further information you may need.

**ELESA S.p.A.**

Via Pompei, 29 - 20900 Monza (MB) Italia  
tel. +39 039 2811.1 - fax +39 039 836351  
[www.elesa.com](http://www.elesa.com) - [info@elesa.com](mailto:info@elesa.com)

**STANDARD MACHINE ELEMENTS WORLDWIDE**

**elesa®**



1

**LEVER BODY**

Die-cast zinc alloy with epoxy resin coating, or stainless steel, sandblasted matte finish.



2

**STANDARD EXECUTIONS**

Threaded hole or threaded stud.

- **GN 300:** zinc alloy lever, black-oxide steel clamping element and retaining screw with hexagon socket. Stainless steel return spring.
- **GN 300.1:** zinc alloy lever, AISI 303 stainless steel clamping element and retaining screw with hexagon socket. AISI 301 stainless steel return spring.
- **GN 300.5:** stainless steel lever, AISI 303 stainless steel clamping element and retaining screw with hexagon socket. AISI 301 stainless steel return spring.



3



4

**FEATURES AND APPLICATIONS**

Particularly suitable when the lever turning angle is limited owing to lack of space.



5

**INSTRUCTIONS OF USE**

For clamping, lift the lever to disengage the clamping device teeth and bring it back to start position. By releasing the lever, the return spring automatically engages the teeth.

If the lever cannot make a 360° rotation, the clamping element can be easily screwed by means of the hexagon socket front head screw (after having disengaged the lever).



6

**SPECIAL EXECUTIONS ON REQUEST FOR GN 300 AND GN 300.1**

- Lever body in different colours.
- Chrome-plated lever.
- Clamping element with different threadings and lengths.



7

**SPECIAL EXECUTIONS ON REQUEST FOR GN 300.5**

- Clamping element with different threadings and lengths.
- Adjustable handle with hexagonal head retaining screw (GN 300.5-AS).
- Adjustable handles with lever in cast CF-8 stainless steel with electropolished finish (GN 300.6).



8



9



10



11



12



13



14



15



16




17



18



GN 300 - GN 300.1 - GN 300.5  
(d1)

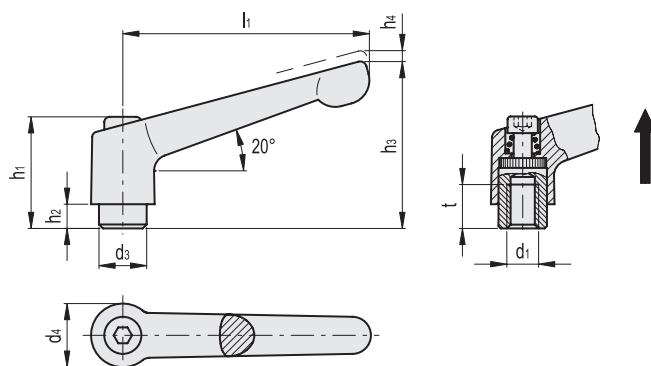

\* Complete with colour index of the lever body (SW, OS, GR)

**SW**  
RAL9005

**OS**  
RAL2004

**GR**  
RAL7031

**GN 300 (d1)**

| Code SW  | Code OS  | Code GR  | Description     | l1  | d1  | d3   | d4   | h1   | h2  | h3 | h4  | tmin |  |
|----------|----------|----------|-----------------|-----|-----|------|------|------|-----|----|-----|------|-------------------------------------------------------------------------------------|
| GN.15801 | GN.15802 | -        | GN 300-30-M3*   | 30  | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 7    | 15                                                                                  |
| GN.15806 | GN.15807 | -        | GN 300-30-M4*   | 30  | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 7    | 15                                                                                  |
| GN.15811 | GN.15812 | -        | GN 300-30-M5*   | 30  | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 7    | 15                                                                                  |
| GN.15816 | GN.15817 | -        | GN 300-30-M6*   | 30  | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 7    | 15                                                                                  |
| GN.16101 | GN.16102 | GN.16104 | GN 300-45-M5*   | 45  | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 9    | 34                                                                                  |
| GN.16111 | GN.16112 | GN.16114 | GN 300-45-M6*   | 45  | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 9    | 33                                                                                  |
| GN.16121 | GN.16122 | GN.16124 | GN 300-63-M6*   | 63  | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 11   | 76                                                                                  |
| GN.16131 | GN.16132 | GN.16134 | GN 300-63-M8*   | 63  | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 11   | 74                                                                                  |
| GN.16141 | GN.16142 | GN.16144 | GN 300-78-M8*   | 78  | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 14   | 123                                                                                 |
| GN.16151 | GN.16152 | GN.16154 | GN 300-78-M10*  | 78  | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 17   | 194                                                                                 |
| GN.16161 | GN.16162 | GN.16164 | GN 300-92-M10*  | 92  | M10 | 19   | 24   | 43   | 11  | 65 | 4   | 17   | 194                                                                                 |
| GN.16171 | GN.16172 | GN.16174 | GN 300-92-M12*  | 92  | M12 | 19   | 24   | 43   | 11  | 65 | 4   | 17   | 171                                                                                 |
| GN.16181 | GN.16182 | GN.16184 | GN 300-108-M12* | 108 | M12 | 23   | 30   | 50.5 | 12  | 76 | 5   | 22   | 306                                                                                 |
| GN.16185 | GN.16186 | GN.16188 | GN 300-108-M14* | 108 | M14 | 23   | 30   | 50.5 | 12  | 76 | 5   | 22   | 298                                                                                 |
| GN.16191 | GN.16192 | GN.16194 | GN 300-108-M16* | 108 | M16 | 23   | 30   | 50.5 | 12  | 76 | 5   | 22   | 306                                                                                 |

**GN 300.1 (d1)****INOX** STAINLESS STEEL

| Code     | Description         | l1  | d1  | d3   | d4   | h1   | h2  | h3 | h4  | tmin |  |
|----------|---------------------|-----|-----|------|------|------|-----|----|-----|------|---------------------------------------------------------------------------------------|
| GN.15101 | GN 300.1-30-M3-SW   | 30  | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 7    | 26                                                                                    |
| GN.15102 | GN 300.1-30-M4-SW   | 30  | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 25                                                                                    |
| GN.15103 | GN 300.1-30-M5-SW   | 30  | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 24                                                                                    |
| GN.15104 | GN 300.1-30-M6-SW   | 30  | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 24                                                                                    |
| GN.15111 | GN 300.1-45-M6-SW   | 45  | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 9    | 33                                                                                    |
| GN.15131 | GN 300.1-63-M8-SW   | 63  | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 11   | 74                                                                                    |
| GN.15151 | GN 300.1-78-M10-SW  | 78  | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 14   | 119                                                                                   |
| GN.15171 | GN 300.1-92-M12-SW  | 92  | M12 | 19   | 24   | 43   | 11  | 65 | 4   | 17   | 178                                                                                   |
| GN.15191 | GN 300.1-108-M16-SW | 108 | M16 | 23   | 30   | 50.5 | 12  | 76 | 5   | 22   | 289                                                                                   |




**GN 300.5 (d1)****INOX** STAINLESS STEEL

| Code     | Description        | l1 | d1  | d3   | d4   | h1   | h2  | h3 | h4  | tmin |  |
|----------|--------------------|----|-----|------|------|------|-----|----|-----|------|---------------------------------------------------------------------------------------|
| GN.15641 | GN 300.5-30-M3-IS  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 7    | 27                                                                                    |
| GN.15642 | GN 300.5-30-M4-IS  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 27                                                                                    |
| GN.15643 | GN 300.5-30-M5-IS  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 26                                                                                    |
| GN.15644 | GN 300.5-30-M6-IS  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 25                                                                                    |
| GN.15699 | GN 300.5-45-M4-IS  | 45 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 35                                                                                    |
| GN.15700 | GN 300.5-45-M5-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 40                                                                                    |
| GN.15701 | GN 300.5-45-M6-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 9    | 39                                                                                    |
| GN.15710 | GN 300.5-63-M6-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 11   | 90                                                                                    |
| GN.15711 | GN 300.5-63-M8-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 11   | 88                                                                                    |
| GN.15720 | GN 300.5-78-M8-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 14   | 147                                                                                   |
| GN.15721 | GN 300.5-78-M10-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 14   | 143                                                                                   |
| GN.15725 | GN 300.5-92-M10-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 17   | 187                                                                                   |
| GN.15726 | GN 300.5-92-M12-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 17   | 178                                                                                   |





  GN 300 - GN 300.1  
(d1-l2)

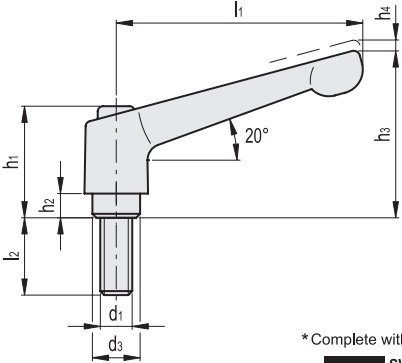

\* Complete with colour index of the lever body (SW, OS, GR)

SW  
RAL9005

OS  
RAL2004

GR  
RAL7031

GN 300 (d1 - l2)

| Code SW  | Code OS  | Code SR  | Description        | l1 | d1  | d3   | d4   | h1   | h2  | h3 | h4  | l2 |     |
|----------|----------|----------|--------------------|----|-----|------|------|------|-----|----|-----|----|-----|
| GN.15831 | GN.15832 | -        | GN 300-30-M3-6-*   | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 6  | 26  |
| GN.15836 | GN.15837 | -        | GN 300-30-M3-8-*   | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 8  | 26  |
| GN.15841 | GN.15842 | -        | GN 300-30-M3-10-*  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 10 | 26  |
| GN.15846 | GN.15847 | -        | GN 300-30-M3-12-*  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 26  |
| GN.15851 | GN.15852 | -        | GN 300-30-M3-16-*  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 26  |
| GN.15861 | GN.15862 | -        | GN 300-30-M4-12-*  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 27  |
| GN.15866 | GN.15867 | -        | GN 300-30-M4-16-*  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 27  |
| GN.15871 | GN.15872 | -        | GN 300-30-M4-20-*  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 20 | 27  |
| GN.15876 | GN.15877 | -        | GN 300-30-M4-25-*  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 25 | 28  |
| GN.15881 | GN.15882 | -        | GN 300-30-M4-32-*  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 32 | 28  |
| GN.15901 | GN.15902 | -        | GN 300-30-M5-12-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 28  |
| GN.15906 | GN.15907 | -        | GN 300-30-M5-16-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 28  |
| GN.15911 | GN.15912 | -        | GN 300-30-M5-20-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 20 | 29  |
| GN.15916 | GN.15917 | -        | GN 300-30-M5-25-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 25 | 29  |
| GN.15921 | GN.15922 | -        | GN 300-30-M5-32-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 32 | 30  |
| GN.15926 | GN.15927 | -        | GN 300-30-M5-40-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 40 | 31  |
| GN.15931 | GN.15932 | -        | GN 300-30-M5-50-*  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 50 | 32  |
| GN.15951 | GN.15952 | -        | GN 300-30-M6-12-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 29  |
| GN.15956 | GN.15957 | -        | GN 300-30-M6-16-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 29  |
| GN.15961 | GN.15962 | -        | GN 300-30-M6-20-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 20 | 30  |
| GN.15966 | GN.15967 | -        | GN 300-30-M6-25-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 25 | 31  |
| GN.15971 | GN.15972 | -        | GN 300-30-M6-32-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 32 | 32  |
| GN.15976 | GN.15977 | -        | GN 300-30-M6-40-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 40 | 33  |
| GN.15981 | GN.15982 | -        | GN 300-30-M6-50-*  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 50 | 34  |
| GN.16201 | GN.16202 | GN.16204 | GN 300-45-M6-12-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 12 | 36  |
| GN.16211 | GN.16212 | GN.16214 | GN 300-45-M6-16-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 16 | 37  |
| GN.16221 | GN.16222 | GN.16224 | GN 300-45-M6-20-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 20 | 37  |
| GN.16231 | GN.16232 | GN.16234 | GN 300-45-M6-25-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 25 | 38  |
| GN.16241 | GN.16242 | GN.16244 | GN 300-45-M6-32-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 32 | 40  |
| GN.16251 | GN.16252 | GN.16254 | GN 300-45-M6-40-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 40 | 41  |
| GN.16261 | GN.16262 | GN.16264 | GN 300-45-M6-50-*  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 50 | 43  |
| GN.16271 | GN.16272 | GN.16274 | GN 300-63-M8-16-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 16 | 83  |
| GN.16281 | GN.16282 | GN.16284 | GN 300-63-M8-20-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 20 | 84  |
| GN.16291 | GN.16292 | GN.16294 | GN 300-63-M8-25-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 25 | 86  |
| GN.16301 | GN.16302 | GN.16304 | GN 300-63-M8-32-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 32 | 88  |
| GN.16311 | GN.16312 | GN.16314 | GN 300-63-M8-40-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 40 | 91  |
| GN.16321 | GN.16322 | GN.16324 | GN 300-63-M8-50-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 50 | 93  |
| GN.16331 | GN.16332 | GN.16334 | GN 300-63-M8-63-*  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 63 | 98  |
| GN.16341 | GN.16342 | GN.16344 | GN 300-78-M10-20-* | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 20 | 139 |
| GN.16351 | GN.16352 | GN.16354 | GN 300-78-M10-25-* | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 25 | 141 |
| GN.16361 | GN.16362 | GN.16364 | GN 300-78-M10-32-* | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 32 | 142 |
| GN.16371 | GN.16372 | GN.16374 | GN 300-78-M10-40-* | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 40 | 146 |
| GN.16381 | GN.16382 | GN.16384 | GN 300-78-M10-50-* | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 50 | 152 |
| GN.16391 | GN.16392 | GN.16394 | GN 300-78-M10-63-* | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 63 | 159 |

## GN 300 (d1 - l2)


| Code SW  | Code OS  | Code SR  | Description         | l1  | d1  | d3 | d4 | h1   | h2 | h3 | h4 | l2 |  |
|----------|----------|----------|---------------------|-----|-----|----|----|------|----|----|----|----|-------------------------------------------------------------------------------------|
| GN.16401 | GN.16402 | GN.16404 | GN 300-78-M10-80-*  | 78  | M10 | 16 | 21 | 36   | 8  | 55 | 4  | 80 | 166                                                                                 |
| GN.16601 | GN.16602 | GN.16604 | GN 300-78-M12-25-*  | 78  | M12 | 16 | 21 | 36   | 8  | 55 | 4  | 25 | 145                                                                                 |
| GN.16611 | GN.16612 | GN.16614 | GN 300-78-M12-32-*  | 78  | M12 | 16 | 21 | 36   | 8  | 55 | 4  | 32 | 150                                                                                 |
| GN.16621 | GN.16622 | GN.16624 | GN 300-78-M12-40-*  | 78  | M12 | 16 | 21 | 36   | 8  | 55 | 4  | 40 | 156                                                                                 |
| GN.16631 | GN.16632 | GN.16634 | GN 300-78-M12-50-*  | 78  | M12 | 16 | 21 | 36   | 8  | 55 | 4  | 50 | 163                                                                                 |
| GN.16641 | GN.16642 | GN.16644 | GN 300-78-M12-63-*  | 78  | M12 | 16 | 21 | 36   | 8  | 55 | 4  | 63 | 171                                                                                 |
| GN.16651 | GN.16652 | GN.16654 | GN 300-78-M12-80-*  | 78  | M12 | 16 | 21 | 36   | 8  | 55 | 4  | 80 | 183                                                                                 |
| GN.16411 | GN.16412 | GN.16414 | GN 300-92-M12-25-*  | 92  | M12 | 19 | 24 | 43   | 11 | 65 | 4  | 25 | 212                                                                                 |
| GN.16421 | GN.16422 | GN.16424 | GN 300-92-M12-32-*  | 92  | M12 | 19 | 24 | 43   | 11 | 65 | 4  | 32 | 217                                                                                 |
| GN.16431 | GN.16432 | GN.16434 | GN 300-92-M12-40-*  | 92  | M12 | 19 | 24 | 43   | 11 | 65 | 4  | 40 | 222                                                                                 |
| GN.16441 | GN.16442 | GN.16444 | GN 300-92-M12-50-*  | 92  | M12 | 19 | 24 | 43   | 11 | 65 | 4  | 50 | 229                                                                                 |
| GN.16451 | GN.16452 | GN.16454 | GN 300-92-M12-63-*  | 92  | M12 | 19 | 24 | 43   | 11 | 65 | 4  | 63 | 239                                                                                 |
| GN.16461 | GN.16462 | GN.16464 | GN 300-92-M12-80-*  | 92  | M12 | 19 | 24 | 43   | 11 | 65 | 4  | 80 | 250                                                                                 |
| -        | GN.16702 | -        | GN 300-92-M14-25-*  | 92  | M14 | 19 | 24 | 43   | 11 | 65 | 4  | 25 | 200                                                                                 |
| GN.16721 | -        | GN.16724 | GN 300-92-M14-40-*  | 92  | M14 | 19 | 24 | 43   | 11 | 65 | 4  | 40 | 241                                                                                 |
| GN.16731 | GN.16732 | -        | GN 300-92-M14-50-*  | 92  | M14 | 19 | 24 | 43   | 11 | 65 | 4  | 50 | 242                                                                                 |
| GN.16741 | GN.16742 | GN.16744 | GN 300-92-M14-63-*  | 92  | M14 | 19 | 24 | 43   | 11 | 65 | 4  | 63 | 263                                                                                 |
| GN.16471 | GN.16472 | GN.16474 | GN 300-108-M16-32-* | 108 | M16 | 23 | 30 | 50.5 | 12 | 76 | 5  | 32 | 365                                                                                 |
| GN.16481 | GN.16482 | GN.16484 | GN 300-108-M16-40-* | 108 | M16 | 23 | 30 | 50.5 | 12 | 76 | 5  | 40 | 376                                                                                 |
| GN.16491 | GN.16492 | GN.16494 | GN 300-108-M16-50-* | 108 | M16 | 23 | 30 | 50.5 | 12 | 76 | 5  | 50 | 388                                                                                 |
| GN.16501 | GN.16502 | GN.16504 | GN 300-108-M16-63-* | 108 | M16 | 23 | 30 | 50.5 | 12 | 76 | 5  | 63 | 407                                                                                 |
| GN.16511 | GN.16512 | GN.16514 | GN 300-108-M16-80-* | 108 | M16 | 23 | 30 | 50.5 | 12 | 76 | 5  | 80 | 429                                                                                 |

## GN 300.1 (d1 - l2)

INOX STAINLESS STEEL

| Code     | Description           | l1 | d1  | d3   | d4   | h1   | h2  | h3 | h4  | l2 |  |
|----------|-----------------------|----|-----|------|------|------|-----|----|-----|----|-------------------------------------------------------------------------------------|
| GN.15235 | GN 300.1-30-M3-6-SW   | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 6  | 26                                                                                  |
| GN.15236 | GN 300.1-30-M3-8-SW   | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 8  | 26                                                                                  |
| GN.15237 | GN 300.1-30-M3-10-SW  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 10 | 27                                                                                  |
| GN.15238 | GN 300.1-30-M3-12-SW  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 27                                                                                  |
| GN.15239 | GN 300.1-30-M3-16-SW  | 30 | M3  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 28                                                                                  |
| GN.15241 | GN 300.1-30-M4-12-SW  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 28                                                                                  |
| GN.15242 | GN 300.1-30-M4-16-SW  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 29                                                                                  |
| GN.15243 | GN 300.1-30-M4-20-SW  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 20 | 29                                                                                  |
| GN.15244 | GN 300.1-30-M4-25-SW  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 25 | 30                                                                                  |
| GN.15245 | GN 300.1-30-M4-32-SW  | 30 | M4  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 32 | 31                                                                                  |
| GN.15251 | GN 300.1-30-M5-12-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 30                                                                                  |
| GN.15252 | GN 300.1-30-M5-16-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 31                                                                                  |
| GN.15253 | GN 300.1-30-M5-20-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 20 | 32                                                                                  |
| GN.15254 | GN 300.1-30-M5-25-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 25 | 33                                                                                  |
| GN.15255 | GN 300.1-30-M5-32-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 32 | 35                                                                                  |
| GN.15256 | GN 300.1-30-M5-40-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 40 | 37                                                                                  |
| GN.15257 | GN 300.1-30-M5-50-SW  | 30 | M5  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 50 | 40                                                                                  |
| GN.15261 | GN 300.1-30-M6-12-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 12 | 31                                                                                  |
| GN.15262 | GN 300.1-30-M6-16-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 16 | 32                                                                                  |
| GN.15263 | GN 300.1-30-M6-20-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 20 | 33                                                                                  |
| GN.15264 | GN 300.1-30-M6-25-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 25 | 35                                                                                  |
| GN.15265 | GN 300.1-30-M6-32-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 32 | 38                                                                                  |
| GN.15266 | GN 300.1-30-M6-40-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 40 | 42                                                                                  |
| GN.15267 | GN 300.1-30-M6-50-SW  | 30 | M6  | 10   | 13   | 24.5 | 4   | 31 | 3.5 | 50 | 45                                                                                  |
| GN.15211 | GN 300.1-45-M6-16-SW  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 16 | 37                                                                                  |
| GN.15221 | GN 300.1-45-M6-20-SW  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 20 | 37                                                                                  |
| GN.15231 | GN 300.1-45-M6-25-SW  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 25 | 38                                                                                  |
| GN.15271 | GN 300.1-63-M8-16-SW  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 16 | 83                                                                                  |
| GN.15281 | GN 300.1-63-M8-20-SW  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 20 | 84                                                                                  |
| GN.15291 | GN 300.1-63-M8-25-SW  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 25 | 86                                                                                  |
| GN.15301 | GN 300.1-63-M8-32-SW  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 32 | 88                                                                                  |
| GN.15311 | GN 300.1-63-M8-40-SW  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 40 | 91                                                                                  |
| GN.15341 | GN 300.1-78-M10-20-SW | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 20 | 139                                                                                 |
| GN.15361 | GN 300.1-78-M10-25-SW | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 25 | 141                                                                                 |
| GN.15371 | GN 300.1-78-M10-32-SW | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 32 | 142                                                                                 |
| GN.15381 | GN 300.1-78-M10-40-SW | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 40 | 146                                                                                 |
| GN.15421 | GN 300.1-92-M12-32-SW | 92 | M12 | 19   | 24   | 43   | 11  | 65 | 4   | 32 | 217                                                                                 |
| GN.15431 | GN 300.1-92-M12-40-SW | 92 | M12 | 19   | 24   | 43   | 11  | 65 | 4   | 40 | 222                                                                                 |



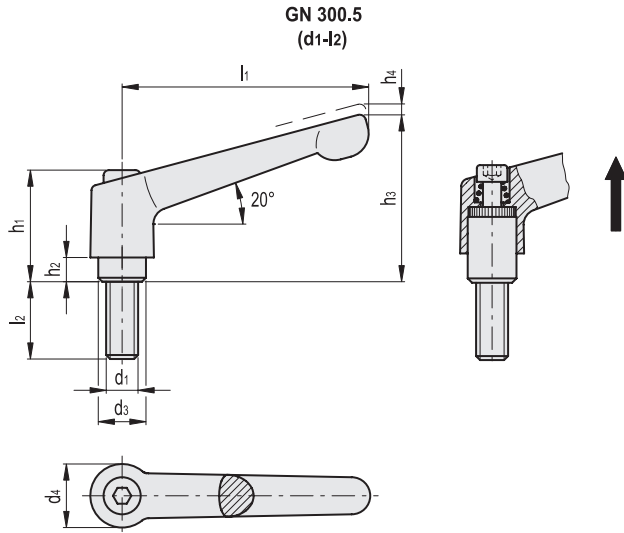

INOX STAINLESS STEEL

GN 300.5 (d1 - l2)

| Code     | Description          | l1 | d1 | d3 | d4 | h1   | h2 | h3 | h4  | l2 |    |
|----------|----------------------|----|----|----|----|------|----|----|-----|----|----|
| GN.15651 | GN 300.5-30-M3-6-IS  | 30 | M3 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 6  | 27 |
| GN.15652 | GN 300.5-30-M3-8-IS  | 30 | M3 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 8  | 28 |
| GN.15653 | GN 300.5-30-M3-10-IS | 30 | M3 | 10 | 13 | 24.5 | 4  | 35 | 3.5 | 10 | 29 |
| GN.15654 | GN 300.5-30-M3-12-IS | 30 | M3 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 12 | 30 |
| GN.15655 | GN 300.5-30-M3-16-IS | 30 | M3 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 16 | 31 |
| GN.15656 | GN 300.5-30-M4-12-IS | 30 | M4 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 12 | 30 |
| GN.15657 | GN 300.5-30-M4-16-IS | 30 | M4 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 16 | 31 |
| GN.15658 | GN 300.5-30-M4-20-IS | 30 | M4 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 20 | 32 |
| GN.15659 | GN 300.5-30-M4-25-IS | 30 | M4 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 25 | 33 |
| GN.15660 | GN 300.5-30-M4-32-IS | 30 | M4 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 32 | 34 |
| GN.15661 | GN 300.5-30-M5-12-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 35 | 3.5 | 12 | 37 |
| GN.15662 | GN 300.5-30-M5-16-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 16 | 38 |
| GN.15663 | GN 300.5-30-M5-20-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 20 | 39 |
| GN.15664 | GN 300.5-30-M5-25-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 25 | 40 |
| GN.15665 | GN 300.5-30-M5-32-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 32 | 41 |
| GN.15666 | GN 300.5-30-M5-40-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 35 | 3.5 | 40 | 42 |
| GN.15667 | GN 300.5-30-M5-50-IS | 30 | M5 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 50 | 43 |
| GN.15668 | GN 300.5-30-M6-12-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 35 | 3.5 | 12 | 38 |
| GN.15669 | GN 300.5-30-M6-16-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 16 | 39 |
| GN.15670 | GN 300.5-30-M6-20-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 20 | 40 |
| GN.15671 | GN 300.5-30-M6-25-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 25 | 41 |
| GN.15672 | GN 300.5-30-M6-32-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 35 | 3.5 | 32 | 42 |
| GN.15673 | GN 300.5-30-M6-40-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 35 | 3.5 | 40 | 43 |
| GN.15674 | GN 300.5-30-M6-50-IS | 30 | M6 | 10 | 13 | 24.5 | 4  | 31 | 3.5 | 50 | 44 |

Clamping levers

## GN 300.5 (d1 - l2)

INOX STAINLESS STEEL

| Code     | Description           | l1 | d1  | d3   | d4   | h1   | h2  | h3 | h4  | l2 | ⚖   |
|----------|-----------------------|----|-----|------|------|------|-----|----|-----|----|-----|
| GN.15760 | GN 300.5-45-M4-12-IS  | 45 | M4  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 12 | 35  |
| GN.15761 | GN 300.5-45-M4-16-IS  | 45 | M4  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 16 | 36  |
| GN.15762 | GN 300.5-45-M4-20-IS  | 45 | M4  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 20 | 37  |
| GN.15763 | GN 300.5-45-M4-25-IS  | 45 | M4  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 25 | 38  |
| GN.15764 | GN 300.5-45-M4-32-IS  | 45 | M4  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 32 | 39  |
| GN.15765 | GN 300.5-45-M5-12-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 12 | 41  |
| GN.15766 | GN 300.5-45-M5-16-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 16 | 42  |
| GN.15767 | GN 300.5-45-M5-20-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 20 | 43  |
| GN.15768 | GN 300.5-45-M5-25-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 25 | 43  |
| GN.15769 | GN 300.5-45-M5-32-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 32 | 44  |
| GN.15770 | GN 300.5-45-M5-40-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 40 | 45  |
| GN.15771 | GN 300.5-45-M5-50-IS  | 45 | M5  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 50 | 49  |
| GN.15730 | GN 300.5-45-M6-12-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 12 | 42  |
| GN.15731 | GN 300.5-45-M6-16-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 16 | 43  |
| GN.15732 | GN 300.5-45-M6-20-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 20 | 43  |
| GN.15733 | GN 300.5-45-M6-25-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 25 | 44  |
| GN.15734 | GN 300.5-45-M6-32-IS  | 30 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 32 | 46  |
| GN.15735 | GN 300.5-45-M6-40-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 40 | 47  |
| GN.15736 | GN 300.5-45-M6-50-IS  | 45 | M6  | 10   | 13   | 24.5 | 4   | 35 | 3.5 | 50 | 47  |
| GN.15772 | GN 300.5-63-M6-16-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 16 | 97  |
| GN.15773 | GN 300.5-63-M6-20-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 20 | 98  |
| GN.15774 | GN 300.5-63-M6-25-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 25 | 100 |
| GN.15775 | GN 300.5-63-M6-32-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 32 | 102 |
| GN.15776 | GN 300.5-63-M6-40-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 40 | 105 |
| GN.15777 | GN 300.5-63-M6-50-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 50 | 100 |
| GN.15778 | GN 300.5-63-M6-63-IS  | 63 | M6  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 63 | 102 |
| GN.15741 | GN 300.5-63-M8-16-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 16 | 97  |
| GN.15742 | GN 300.5-63-M8-20-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 20 | 98  |
| GN.15743 | GN 300.5-63-M8-25-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 25 | 100 |
| GN.15744 | GN 300.5-63-M8-32-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 32 | 102 |
| GN.15745 | GN 300.5-63-M8-40-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 40 | 105 |
| GN.15746 | GN 300.5-63-M8-50-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 50 | 107 |
| GN.15747 | GN 300.5-63-M8-63-IS  | 63 | M8  | 13.5 | 17.5 | 31   | 6.5 | 45 | 4   | 63 | 112 |
| GN.15779 | GN 300.5-78-M8-20-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 20 | 155 |
| GN.15780 | GN 300.5-78-M8-25-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 25 | 157 |
| GN.15781 | GN 300.5-78-M8-32-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 32 | 158 |
| GN.15782 | GN 300.5-78-M8-40-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 40 | 162 |
| GN.15783 | GN 300.5-78-M8-50-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 50 | 167 |
| GN.15784 | GN 300.5-78-M8-63-IS  | 78 | M8  | 16   | 21   | 136  | 8   | 55 | 4   | 63 | 174 |
| GN.15785 | GN 300.5-78-M8-80-IS  | 78 | M8  | 16   | 21   | 36   | 8   | 55 | 4   | 80 | 181 |
| GN.15752 | GN 300.5-78-M10-20-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 20 | 163 |
| GN.15753 | GN 300.5-78-M10-25-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 25 | 165 |
| GN.15754 | GN 300.5-78-M10-32-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 32 | 166 |
| GN.15755 | GN 300.5-78-M10-40-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 40 | 170 |
| GN.15756 | GN 300.5-78-M10-50-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 50 | 176 |
| GN.15757 | GN 300.5-78-M10-63-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 63 | 183 |
| GN.15758 | GN 300.5-78-M10-80-IS | 78 | M10 | 16   | 21   | 36   | 8   | 55 | 4   | 80 | 190 |
| GN.15786 | GN 300.5-92-M10-20-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 20 | 240 |
| GN.15787 | GN 300.5-92-M10-25-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 25 | 245 |
| GN.15788 | GN 300.5-92-M10-32-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 32 | 249 |
| GN.15789 | GN 300.5-92-M10-40-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 40 | 253 |
| GN.15790 | GN 300.5-92-M10-50-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 50 | 259 |
| GN.15791 | GN 300.5-92-M10-63-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 63 | 265 |
| GN.15792 | GN 300.5-92-M10-80-IS | 92 | M10 | 19   | 24   | 43   | 11  | 63 | 4   | 80 | 275 |
| GN.15793 | GN 300.5-92-M12-20-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 20 | 242 |
| GN.15794 | GN 300.5-92-M12-25-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 25 | 245 |
| GN.15795 | GN 300.5-92-M12-32-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 32 | 249 |
| GN.15796 | GN 300.5-92-M12-40-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 40 | 253 |
| GN.15797 | GN 300.5-92-M12-50-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 50 | 259 |
| GN.15798 | GN 300.5-92-M12-63-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 63 | 265 |
| GN.15799 | GN 300.5-92-M12-80-IS | 92 | M12 | 19   | 24   | 43   | 11  | 63 | 4   | 80 | 275 |

