

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

MATERIAL

Ovalprofil, Aluminium, Oberfläche sandgestrahlt, satinfinish.



STANDARDAUSFÜHRUNGEN

Gewinde-Sacklöcher:

- **RHBG-11:** naturfarben.
- **RHBG-14:** schwarz.

SONDERAUSFÜHRUNGEN AUF ANFRAGE

- Verschiedene Längen.
- Verschiedene Oberflächen.

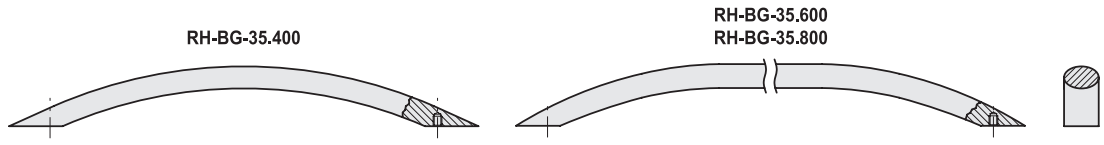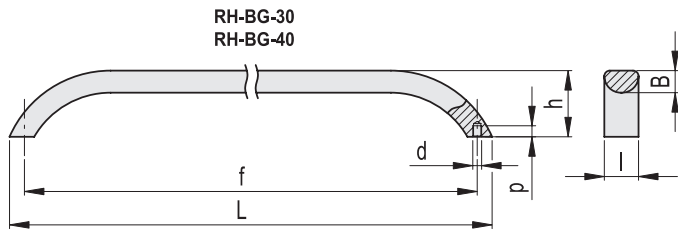

Code	Code	f	L	d	p	l	B	h	⚖️
RHBG-30.350.11	RHBG-30.350.14	350	377	M8	10	31	20	60	525
RHBG-30.400.11	RHBG-30.400.14	400	427	M8	10	31	20	60	525
RHBG-30.450.11	RHBG-30.450.14	450	477	M8	10	31	20	60	594
RHBG-30.500.11	RHBG-30.500.14	500	527	M8	10	31	20	60	594
RHBG-35.400.11	RHBG-35.400.14	400	480	M8	10	35	25	62	780
RHBG-35.600.11	RHBG-35.600.14	600	680	M8	10	35	25	62	1164
RHBG-35.800.11	RHBG-35.800.14	800	880	M8	10	35	25	62	1533
RHBG-40.500.11	RHBG-40.500.14	500	540	M10	15	41	30	80	1512
RHBG-40.600.11	RHBG-40.600.14	600	640	M10	15	41	30	80	1512
RHBG-40.700.11	RHBG-40.700.14	700	740	M10	15	41	30	80	1782
RHBG-40.800.11	RHBG-40.800.14	800	840	M10	15	41	30	80	1782