

CABLE

Cable with grey PVC sheath \varnothing 5.8 mm, 2.5 or 5 m long.

CONNECTOR (PROTECTION IP67)

8 pole M12x1 female connector with polyamide-based (PA) technopolymer housing and contact holder.

NUT

AISI 316 stainless steel nut.


COMPATIBILITY

ESC-SFT: handles with built-in safety switch (see page -).



Technical data	
Conductors cross-section	6xAWG 24 STYLE 2517
Maximum applicable voltage	30Vac/dc
Maximum current intensity	1A
Insulation resistance	$\geq 100\text{M}\Omega$ 500VDC
Working temperature	-25°C, +80°C
Protection class	IP67 *

* With the connector properly screwed

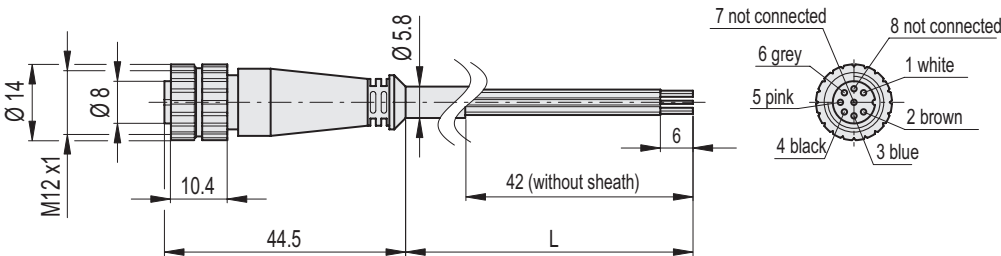

Code	Description	L	Δ
426513	FC-ESC-P8-2.5	2500	225
426516	FC-ESC-P8-5.0	5000	423