



MATERIAL

Cast AISI CF-8 stainless steel, sandblasted matte finish.

AISI 304 stainless steel screws and nuts.



FEATURES AND APPLICATIONS

The assembly holes of GN 131-NI connecting clamps allow an excellent match with tubes GN 990 (see page 1368).

The clamping screw d3 may be replaced by clamping kit GN 911 – GN 911.3 (see page 1372).

SPECIAL EXECUTIONS ON REQUEST

Different combinations of holes d1/d2.

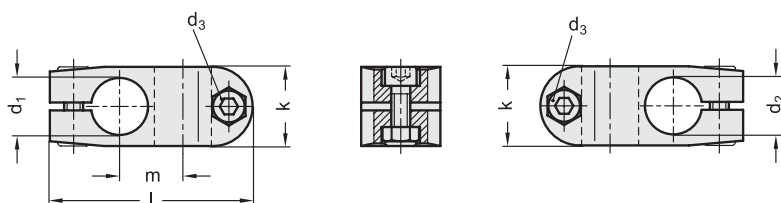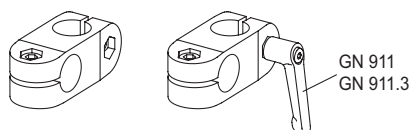

INOX STAINLESS STEEL

Code	Description	d1	d2	d3	k	l	m	d3 Clamping kit	
GN.42033	GN 131-B12-B12-2-NI	12	12	M6	25	64	20	GN 911-M6-22	203
GN.42053	GN 131-B14-B14-2-NI	14	14	M6	25	64	20	GN 911-M6-22	180
GN.42073	GN 131-B15-B15-2-NI	15	15	M6	25	64	20	GN 911-M6-22	190
GN.42093	GN 131-B16-B16-2-NI	16	16	M6	25	64	20	GN 911-M6-22	170
GN.42113	GN 131-B18-B18-2-NI	18	18	M6	25	64	20	GN 911-M6-22	148
GN.42123	GN 131-B20-B20-2-NI	20	20	M6	25	64	20	GN 911-M6-22	144