



MATERIAL


Cast AISI CF-8 stainless steel, sandblasted matte finish.
AISI 304 stainless steel screw and washer.
AISI 304 zinc-plated stainless steel nut.

STANDARD EXECUTIONS

Base with 4 assembly holes.
- **GN 146.5-A:** without sealing washers and closing ring.
- **GN 146.5-B:** with acetal resin based (POM) technopolymer sealing washers and silicone closing ring.

FEATURES AND APPLICATIONS

GN 146.5 connecting clamps are shaped so as to provide an optimum clamping with tubes GN 990 (see page 1368).
The particular shape of the screws and nuts prevents the formation of condensation.
In the execution GN 146.5-B, the presence of technopolymer sealing washers and silicone ring allows the sealing of the hole and thread making them waterproof.

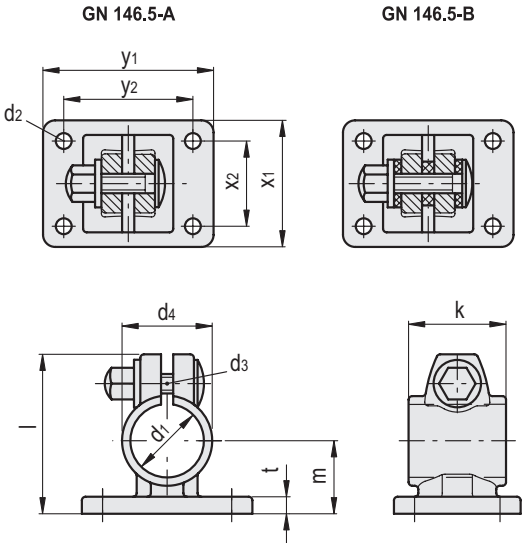

GN 146.5-A

Code	Description	d1	d2	d3	d4	k	l	m	t	x1	x2	y1	y2	⚖
GN.46901	GN 146.5-B30-A-4	30	6.5	M8	37	40	66	30	7	52	35	70	53	270
GN.46903	GN 146.5-B40-A-4	40	8.5	M10	50.5	56	86	42	7.6	78	52	108	82	743
GN.46905	GN 146.5-B50-A-4	50	10.7	M10	60	65	98.5	50	9	92	62	128	98	1081

GN 146.5-B

Code	Description	d1	d2	d3	d4	k	l	m	t	x1	x2	y1	y2	⚖
GN.46902	GN 146.5-B30-B-4	30	6.5	M8	37	40	66	30	7	52	35	70	53	270
GN.46904	GN 146.5-B40-B-4	40	8.5	M10	50.5	56	86	42	7.6	78	52	108	82	743
GN.46906	GN 146.5-B50-B-4	50	10.7	M10	60	65	98.5	50	9	92	62	128	98	1081