

TYPES

- Type **A**: without sealing washers
- Type **B**: with sealing washers

Main specifications

AISI CF-8 stainless steel
Sandblasted matte finish

Sleeve bearing
Plastic (PTFE)

Carriage bolt DIN 603
Stainless steel

Cap nuts DIN 917 / Washers
Stainless steel

Seals
- Sealing washers
Plastic (Polyacetal POM)
- Spacer ring
Silicon, 40 ... 60 Shore A

FEATURES AND APPLICATIONS


T-angle linear actuator connectors GN 192.15 are based on T-angle connector clamps. The additionally provided mounting holes are used to connect to the drive key of a linear actuator. Bores with the designation **G** are equipped with sleeve bearings.

With the screw locations z2, the play of the guide bore d1 can be adjusted or the linear actuator connectors can be clamped after adjustment. Type B is equipped with seals at the screw locations.


For quick clamping without tools, the cap nuts can be replaced by the adjustable hand levers GN 911.3 (see page) listed in the table as accessories.

ACCESSORY




Adjustable Hand Levers GN 911.3 (see page).

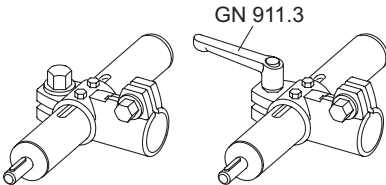

GN 192.15-A

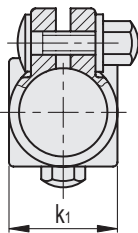

GN 192.15-B

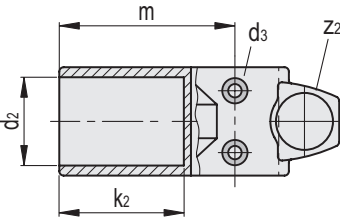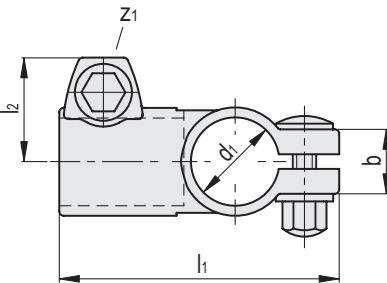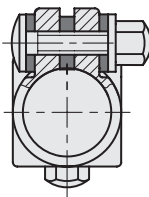

GN 192.15-A

Code	Description	d1 Bore with sleeve bearing	d2	d3	b	k1	k2	l1	l2	m	z1	z2	z1 Clamping kit	z2 Clamping kit	
GN.48971	GN 192.15-G30-B30-A-4	G 30	B 30	M 4	22	37	42	96	35	60	M 8	M 8	GN 911.3-63 / GN 911.3-78	GN 911.3-63 / GN 911.3-78	320
GN.48975	GN 192.15-G50-B50-A-4	G 50	B 50	M 6	30	65	75	151.5	48.5	103	M 10	M 10	GN 911.3-78 / GN 911.3-92	GN 911.3-78 / GN 911.3-92	1023

GN 192.15-B

Code	Description	d1 Bore with sleeve bearing	d2	d3	b	k1	k2	l1	l2	m	z1	z2	z1 Clamping kit	z2 Clamping kit	
GN.48973	GN 192.15-G30-B30-B-4	G 30	B 50	M 4	22	37	42	96	35	60	M 8	M 8	GN 911.3-63 / GN 911.3-78	GN 911.3-63 / GN 911.3-78	320
GN.48977	GN 192.15-G50-B50-B-4	G 50	B 50	M 6	30	65	75	151.5	48.5	103	M 10	M 10	GN 911.3-78 / GN 911.3-92	GN 911.3-78 / GN 911.3-92	1023