

MATERIAL


Aluminium, matte finish.
AISI 304 stainless steel screws and nuts.

STANDARD EXECUTIONS

- **GN 241-B**: for round tubes.
 - **GN 241-V**: for square tubes.
- Surface finish index:
- **BL**: natural colour.
 - **SW**: epoxy resin coating resistant to UV rays, RAL 9005 black colour.


FEATURES AND APPLICATIONS

GN 241 tube supports allow an excellent match with tubes GN 990 (see page 1368).
The clamping screw d2 may be replaced by clamping kits GN 911 (see page 1372).

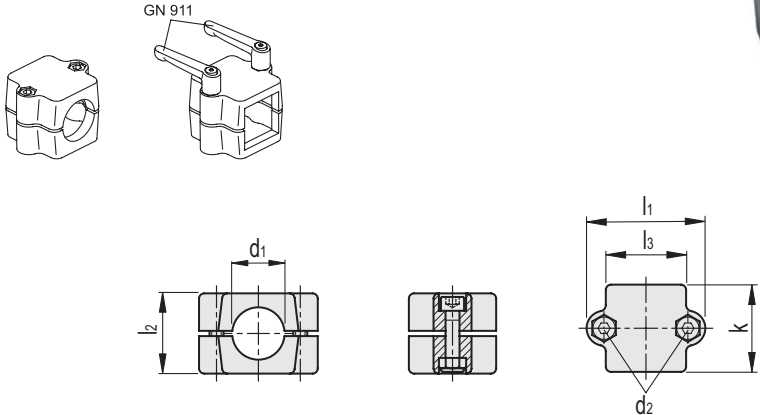

GN 241-B

Code	Description	d1 Hole	d2	k	l1	l2	l3	d2 Clamping kit	⚖
GN.56011	GN 241-B20-50-2-BL	20	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	195
GN.56031	GN 241-B25-50-2-BL	25	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	190
GN.56051	GN 241-B30-50-2-BL	30	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	185
GN.56071	GN 241-B30-60-2-BL	30	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	390
GN.56091	GN 241-B32-60-2-BL	32	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	386
GN.56111	GN 241-B35-60-2-BL	35	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	374
GN.56131	GN 241-B40-60-2-BL	40	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	365
GN.56151	GN 241-B40-76-2-BL	40	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	495
GN.56171	GN 241-B42-76-2-BL	42	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	490
GN.56191	GN 241-B45-76-2-BL	45	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	485
GN.56211	GN 241-B48-76-2-BL	48	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	479
GN.56231	GN 241-B50-76-2-BL	50	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	465
GN.56241	GN 241-B60-90-2-BL	60	M10	90	108.5	84	83	-	572
GN.56016	GN 241-B20-50-2-SW	20	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	195
GN.56036	GN 241-B25-50-2-SW	25	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	190
GN.56056	GN 241-B30-50-2-SW	30	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	185
GN.56076	GN 241-B30-60-2-SW	30	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	390
GN.56096	GN 241-B32-60-2-SW	32	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	386
GN.56116	GN 241-B35-60-2-SW	35	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	374
GN.56136	GN 241-B40-60-2-SW	40	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	365
GN.56156	GN 241-B40-76-2-SW	40	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	495
GN.56176	GN 241-B42-76-2-SW	42	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	490
GN.56196	GN 241-B45-76-2-SW	45	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	485
GN.56216	GN 241-B48-76-2-SW	48	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	479
GN.56236	GN 241-B50-76-2-SW	50	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	465
GN.56246	GN 241-B60-90-2-SW	60	M10	90	108.5	84	83	-	572

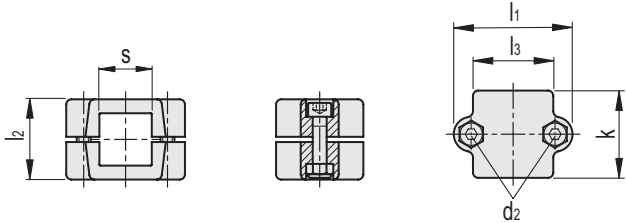

GN 241-V

Code	Description	s Square hole	d2	k	l1	l2	l3	d2 Clamping kit	⚖
GN.56311	GN 241-V20-50-2-BL	20x20	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	210
GN.56331	GN 241-V25-50-2-BL	25x25	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	180
GN.56351	GN 241-V30-50-2-BL	30x30	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	160
GN.56371	GN 241-V30-60-2-BL	30x30	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	376
GN.56391	GN 241-V35-60-2-BL	35x35	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	350
GN.56411	GN 241-V40-60-2-BL	40x40	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	300
GN.56431	GN 241-V40-76-2-BL	40x40	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	450
GN.56451	GN 241-V45-76-2-BL	45x45	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	420
GN.56471	GN 241-V50-76-2-BL	50x50	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	400
GN.56481	GN 241-V60-90-2-BL	60x60	M10	90	108.5	84	83	-	482
GN.56316	GN 241-V20-50-2-SW	20x20	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	210
GN.56336	GN 241-V25-50-2-SW	25x25	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	180
GN.56356	GN 241-V30-50-2-SW	30x30	M8	50	68	46	48	GN 911-63-M8-40 / GN 911-78-M8-40	160
GN.56376	GN 241-V30-60-2-SW	30x30	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	376
GN.56396	GN 241-V35-60-2-SW	35x35	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	350
GN.56416	GN 241-V40-60-2-SW	40x40	M8	60	79	59	58	GN 911-63-M8-40 / GN 911-78-M8-40	300
GN.56436	GN 241-V40-76-2-SW	40x40	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	450
GN.56456	GN 241-V45-76-2-SW	45x45	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	420
GN.56476	GN 241-V50-76-2-SW	50x50	M10	76	98	70	73	GN 911-78-M10-78 / GN 911-92-M10-92	400
GN.56486	GN 241-V60-90-2-SW	60x60	M10	90	108.5	84	83	-	482

