



MATERIAL



Cast AISI CF-8 stainless steel, sandblasted matte finish.
AISI 304 stainless steel screw and nut.

FEATURES AND APPLICATIONS

The assembly hole of GN 277-NI connecting clamps allows an excellent match with tubes GN 990 (see page 1778).

GN 277-NI connecting clamps can be assembled with connecting clamps GN 271-NI (see page 1751), GN 273-NI (see page 1753) or GN 275-NI (see page 1756).

The clamping screw d3 may be replaced by clamping kit GN 911 (see page 1782).

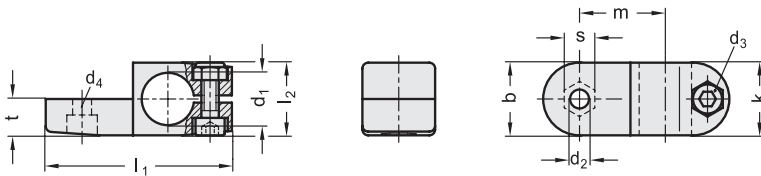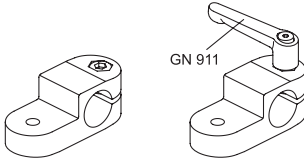

INOX
STAINLESS
STEEL

Code	Description	b	d1	d2	d3	d4	k	l1	l2	m	t	s	d3 Clamping kit	⚖
GN.60013	GN 277-B12-2-NI	25	12	6.5	M6	M6	25	64	25	29.5	12.5	10	GN 911-M6-22	158
GN.60033	GN 277-B14-2-NI	25	14	6.5	M6	M6	25	64	25	29.5	12.5	10	GN 911-M6-22	152
GN.60043	GN 277-B15-2-NI	25	15	6.5	M6	M6	25	64	25	29.5	12.5	10	GN 911-M6-22	148
GN.60053	GN 277-B16-2-NI	25	16	6.5	M6	M6	25	64	25	29.5	12.5	10	GN 911-M6-22	144
GN.60073	GN 277-B18-2-NI	25	18	6.5	M6	M6	25	64	25	29.5	12.5	10	GN 911-M6-22	135
GN.60083	GN 277-B20-2-NI	25	20	6.5	M6	M6	25	64	25	29.5	12.5	10	GN 911-M6-22	125