



VERSIONS

- Version **A**: without accessories
- Version **C**: with fastening set and cover cap

Angle bracket

Die-cast zinc alloy

Painted, white aluminum **ZW**

Screws and T-Nuts (only for Type C)

Zinc-plated steel, blue passivated **SZ**

Cover cap (only for Type C)

Polyamide based (PA) technopolymer

Black **S**

FEATURES AND APPLICATIONS

Angle brackets GN 30I fasten aluminum profiles to objects such as tables and panels or at right angles to each other. Machining of the profile is not necessary.


The connection can be freely positioned and slid along the slot. To fasten the angle brackets to a panel or transversely to an aluminum profile, the guide steps must be broken off.

ACCESSORIES ON REQUEST


- GN 50I: T-Nuts




Assembly of cover cap  
(only for GN 30I-C-ZWSZS)

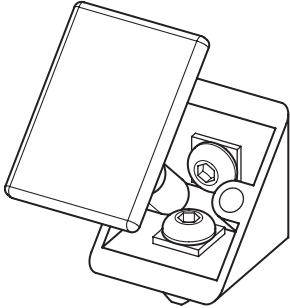


Application examples

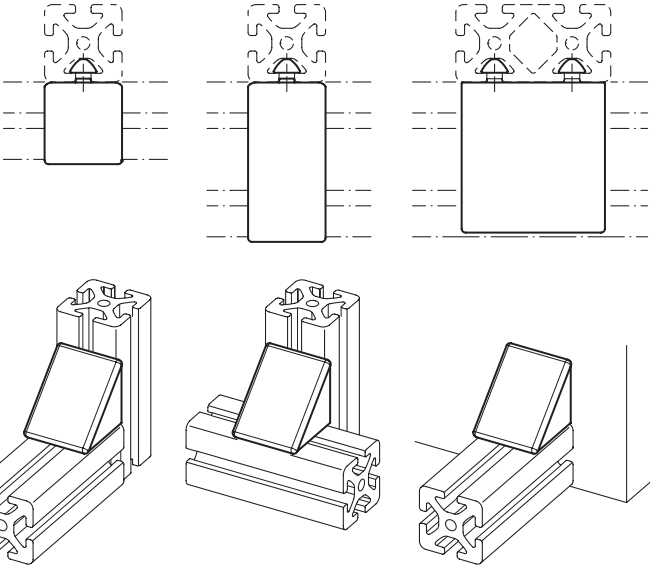

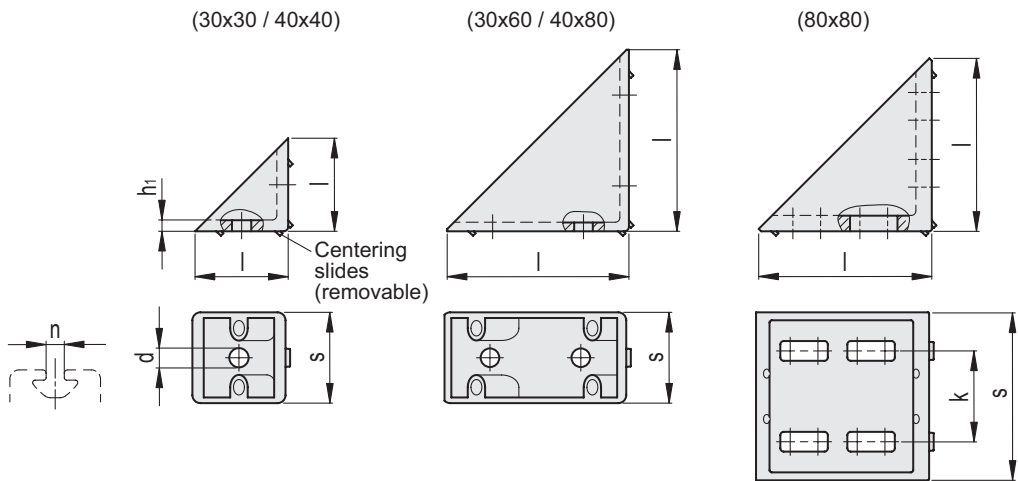

GN 30I-A-ZW

| Code     | Description       | h1 | l* | l# | d For screws | k  | n | s* | s# | ⚖   |
|----------|-------------------|----|----|----|--------------|----|---|----|----|-----|
| GN.67801 | GN 30I-30306-A-ZW | 30 | 30 | M6 | 2.5          | -  | 6 | 30 | 30 | 47  |
| GN.67806 | GN 30I-30606-A-ZW | 60 | 60 | M6 | 3.5          | -  | 6 | 30 | 30 | 130 |
| GN.67811 | GN 30I-40408-A-ZW | 40 | 40 | M8 | 5            | -  | 8 | 40 | 40 | 85  |
| GN.67816 | GN 30I-40808-A-ZW | 80 | 80 | M8 | 5            | -  | 8 | 40 | 40 | 271 |
| GN.67821 | GN 30I-80808-A-ZW | 80 | 76 | M8 | 8            | 40 | 8 | 80 | 74 | 407 |

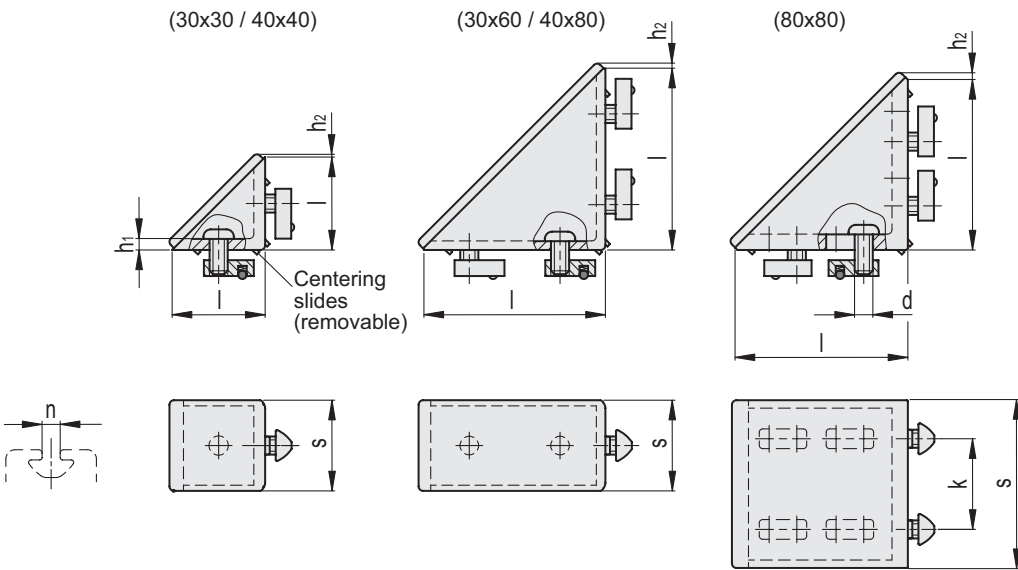

GN 30I-C-ZWSZS

| Code     | Description          | h1 | l* | l# | d   | h2 | k  | n | s* | s# | ⚖   |
|----------|----------------------|----|----|----|-----|----|----|---|----|----|-----|
| GN.67851 | GN 30I-30306-C-ZWSZS | 30 | 30 | M6 | 2.5 | 2  | -  | 6 | 30 | 30 | 52  |
| GN.67856 | GN 30I-30606-C-ZWSZS | 60 | 60 | M6 | 3.5 | 2  | -  | 6 | 30 | 30 | 166 |
| GN.67861 | GN 30I-40408-C-ZWSZS | 40 | 40 | M8 | 5   | 2  | -  | 8 | 40 | 40 | 158 |
| GN.67866 | GN 30I-40808-C-ZWSZS | 80 | 80 | M8 | 5   | 2  | -  | 8 | 40 | 40 | 355 |
| GN.67871 | GN 30I-80808-C-ZWSZS | 80 | 76 | M8 | 8   | 7  | 40 | 8 | 80 | 74 | 575 |

\* Nominal dimension  
# Real dimension