

HANDLE SHANKS

AISI CF-8 stainless steel, sandblasted matte finish.
Threaded blind holes.

STANDARD EXECUTION


AISI 304 stainless steel tube, thickness 2 mm, sandblasted matte finish.

APPLICATIONS

These handles are typically used on turning or rolling doors for machines and equipment.

SPECIAL EXECUTIONS ON REQUEST

Different lengths.

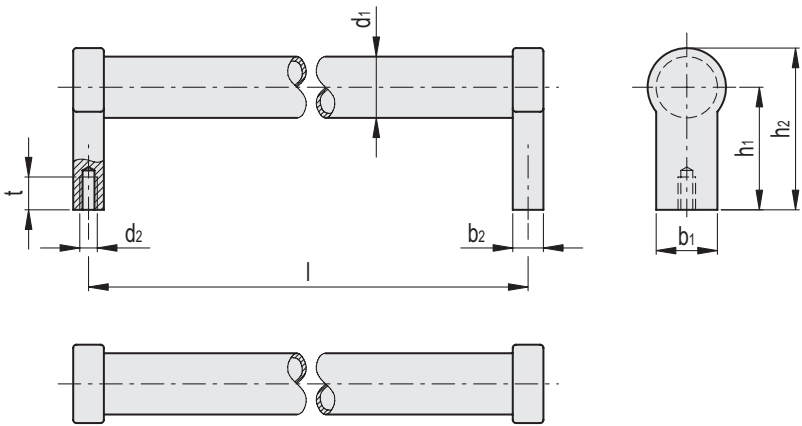

Code	Description	d1	l±0.5	b1	b2	d2	h1	h2	tmin	⚖
GN.33372	GN 333.7-28-200	28	200	25	14	M8	50	66	15	514
GN.33373	GN 333.7-28-300	28	300	25	14	M8	50	66	15	643
GN.33375	GN 333.7-28-500	28	500	25	14	M8	50	66	15	901