

STANDARD EXECUTIONS

Aluminium, oval cross section bar.


Threaded blind holes.

Surface finish index:

- **BL**: natural colour.
- **EL**: anodised, natural colour.
- **RS**: epoxy resin coating, RAL 3000 red colour, matte finish.
- **SR**: epoxy resin coating, RAL 9006 silver colour, matte finish.
- **SW**: epoxy resin coating resistant to UV rays, RAL 9005 black colour, matte finish.

SPECIAL EXECUTIONS ON REQUEST

Lengths and colours other than the standard executions.

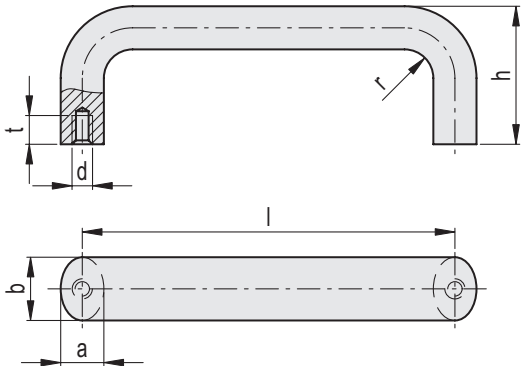

GN 565-SW

Code	Description	b	d	l±0.25	a	h	r	tmin	⚖
GN.27092	GN 565-20-100-SW	20	M6	100	13	49	13	10	87
GN.27096	GN 565-20-112-SW	20	M6	112	13	49	13	10	97
GN.27072	GN 565-20-117-SW	20	M6	117	13	49	13	10	100
GN.27075	GN 565-20-120-SW	20	M6	120	13	49	13	10	105
GN.27102	GN 565-20-128-SW	20	M6	128	13	51	13	10	107
GN.27106	GN 565-20-160-SW	20	M6	160	13	51	13	10	127
GN.27163	GN 565-20-180-SW	20	M6	180	13	51	13	10	138
GN.27166	GN 565-20-200-SW	20	M6	200	13	51	13	10	150
GN.27169	GN 565-20-235-SW	20	M6	235	13	51	13	10	172
GN.27108	GN 565-26-112-SW	26	M8	112	17	55	17	12	160
GN.27078	GN 565-26-117-SW	26	M8	117	17	55	17	12	166
GN.27081	GN 565-26-120-SW	26	M8	120	17	55	17	12	170
GN.27084	GN 565-26-125-SW	26	M8	125	17	55	17	12	178
GN.27110	GN 565-26-128-SW	26	M8	128	17	55	17	12	183
GN.27112	GN 565-26-160-SW	26	M8	160	17	57	17	12	211
GN.27087	GN 565-26-179-SW	26	M8	179	17	57	17	12	230
GN.27116	GN 565-26-192-SW	26	M8	192	17	57	17	12	245
GN.27122	GN 565-26-300-SW	26	M8	300	17	57	17	12	350
GN.27126	GN 565-26-400-SW	26	M8	400	17	57	17	12	445
GN.27090	GN 565-26-500-SW	26	M8	500	17	57	17	12	538

GN 565

Code	Description	b	d	l±0.25	a	h	r	tmin	Δ
GN.27091	GN 565-20-100-BL	20	M6	100	13	49	13	10	87
GN.27095	GN 565-20-112-BL	20	M6	112	13	49	13	10	97
GN.27070	GN 565-20-117-BL	20	M6	117	13	49	13	10	100
GN.27073	GN 565-20-120-BL	20	M6	120	13	49	13	10	105
GN.27101	GN 565-20-128-BL	20	M6	128	13	51	13	10	107
GN.27105	GN 565-20-160-BL	20	M6	160	13	51	13	10	127
GN.27161	GN 565-20-180-BL	20	M6	180	13	51	13	10	138
GN.27164	GN 565-20-200-BL	20	M6	200	13	51	13	10	150
GN.27167	GN 565-20-235-BL	20	M6	235	13	51	13	10	172
GN.27107	GN 565-26-112-BL	26	M8	112	17	55	17	12	160
GN.27076	GN 565-26-117-BL	26	M8	117	17	55	17	12	166
GN.27079	GN 565-26-120-BL	26	M8	120	17	55	17	12	170
GN.27082	GN 565-26-125-BL	26	M8	125	17	55	17	12	178
GN.27109	GN 565-26-128-BL	26	M8	128	17	55	17	12	183
GN.27111	GN 565-26-160-BL	26	M8	160	17	57	17	12	211
GN.27085	GN 565-26-179-BL	26	M8	179	17	57	17	12	230
GN.27115	GN 565-26-192-BL	26	M8	192	17	57	17	12	245
GN.27121	GN 565-26-300-BL	26	M8	300	17	57	17	12	350
GN.27125	GN 565-26-400-BL	26	M8	400	17	57	17	12	445
GN.27088	GN 565-26-500-BL	26	M8	500	17	57	17	12	538
GN.27131	GN 565-20-100-EL	20	M6	100	13	49	13	10	87
GN.27132	GN 565-20-112-EL	20	M6	112	13	49	13	10	97
GN.27071	GN 565-20-117-EL	20	M6	117	13	49	13	10	100
GN.27074	GN 565-20-120-EL	20	M6	120	13	49	13	10	105
GN.27133	GN 565-20-128-EL	20	M6	128	13	51	13	10	107
GN.27134	GN 565-20-160-EL	20	M6	160	13	51	13	10	127
GN.27162	GN 565-20-180-EL	20	M6	180	13	51	13	10	138
GN.27165	GN 565-20-200-EL	20	M6	200	13	51	13	10	150
GN.27168	GN 565-20-235-EL	20	M6	235	13	51	13	10	172
GN.27141	GN 565-26-112-EL	26	M8	112	17	55	17	12	160
GN.27077	GN 565-26-117-EL	26	M8	117	17	55	17	12	166
GN.27080	GN 565-26-120-EL	26	M8	120	17	55	17	12	170
GN.27083	GN 565-26-125-EL	26	M8	125	17	55	17	12	178
GN.27142	GN 565-26-128-EL	26	M8	128	17	55	17	12	183
GN.27143	GN 565-26-160-EL	26	M8	160	17	57	17	12	211
GN.27086	GN 565-26-179-EL	26	M8	179	17	57	17	12	230
GN.27144	GN 565-26-192-EL	26	M8	192	17	57	17	12	245
GN.27145	GN 565-26-300-EL	26	M8	300	17	57	17	12	350
GN.27089	GN 565-26-500-EL	26	M8	500	17	57	17	12	538
GN.27146	GN 565-26-400-EL	26	M8	400	17	57	17	12	445

Code	Description	b	d	l±0.25	a	h	r	tmin	Δ
GN.64681	GN 565-20-100-RS	20	M6	100	13	49	13	10	87
GN.64686	GN 565-20-112-RS	20	M6	112	13	49	13	10	93
GN.64691	GN 565-20-117-RS	20	M6	117	13	49	13	10	100
GN.64696	GN 565-20-120-RS	20	M6	120	13	49	13	10	107
GN.64701	GN 565-20-128-RS	20	M6	128	13	51	13	10	114
GN.64706	GN 565-20-160-RS	20	M6	160	13	51	13	10	121
GN.64711	GN 565-20-180-RS	20	M6	180	13	51	13	10	128
GN.64716	GN 565-20-200-RS	20	M6	200	13	51	13	10	150
GN.64721	GN 565-20-235-RS	20	M6	235	13	51	13	10	172
GN.64726	GN 565-26-112-RS	26	M8	112	17	55	17	12	161
GN.64731	GN 565-26-117-RS	26	M8	117	17	55	17	12	166
GN.64736	GN 565-26-120-RS	26	M8	120	17	55	17	12	171
GN.64741	GN 565-26-125-RS	26	M8	125	17	55	17	12	180
GN.64746	GN 565-26-128-RS	26	M8	128	17	55	17	12	189
GN.64751	GN 565-26-160-RS	26	M8	160	17	57	17	12	210
GN.64756	GN 565-26-179-RS	26	M8	179	17	57	17	12	234
GN.64761	GN 565-26-192-RS	26	M8	192	17	57	17	12	245
GN.64766	GN 565-26-300-RS	26	M8	300	17	57	17	12	345
GN.64771	GN 565-26-400-RS	26	M8	400	17	57	17	12	440
GN.64776	GN 565-26-500-RS	26	M8	500	17	57	17	12	538
GN.64683	GN 565-20-100-SR	20	M6	100	13	49	13	10	87
GN.64688	GN 565-20-112-SR	20	M6	112	13	49	13	10	93
GN.64693	GN 565-20-117-SR	20	M6	117	13	49	13	10	100
GN.64698	GN 565-20-120-SR	20	M6	120	13	49	13	10	107
GN.64703	GN 565-20-128-SR	20	M6	128	13	51	13	10	114
GN.64708	GN 565-20-160-SR	20	M6	160	13	51	13	10	121
GN.64713	GN 565-20-180-SR	20	M6	180	13	51	13	10	128
GN.64718	GN 565-20-200-SR	20	M6	200	13	51	13	10	150
GN.64723	GN 565-20-235-SR	20	M6	235	13	51	13	10	172
GN.64728	GN 565-26-112-SR	26	M8	112	17	55	17	12	161
GN.64733	GN 565-26-117-SR	26	M8	117	17	55	17	12	166
GN.64738	GN 565-26-120-SR	26	M8	120	17	55	17	12	171
GN.64743	GN 565-26-125-SR	26	M8	125	17	55	17	12	180
GN.64748	GN 565-26-128-SR	26	M8	128	17	55	17	12	189
GN.64753	GN 565-26-160-SR	26	M8	160	17	57	17	12	210
GN.64758	GN 565-26-179-SR	26	M8	179	17	57	17	12	234
GN.64763	GN 565-26-192-SR	26	M8	192	17	57	17	12	245
GN.64768	GN 565-26-300-SR	26	M8	300	17	57	17	12	345
GN.64773	GN 565-26-400-SR	26	M8	400	17	57	17	12	440
GN.64778	GN 565-26-500-SR	26	M8	500	17	57	17	12	538

