



1

**LEVER**

Black-oxide steel.



2

**HANDLE**

Type PLX. (see page 386) Phenolic based (PF) Duroplast, black colour, glossy finish.



3

**WASHER**

Hardened steel.



4

**ECCENTRIC CAM**

Hardened steel.



5

**REFERENCE BUSHING** (EXECUTIONS GN 918-KVS, GN 918-GVS, GN 918-SKS)

Hardened steel.



6

**THREADED BUSHING** (EXECUTIONS GN 918-KVB, GN 918-GVB, GN 918-SKB)

Hardened steel.



7

**STANDARD EXECUTIONS**

Nitrided steel threaded pin:

- **GN 918-KV**: with angled lever- **GN 918-GV**: with straight lever.- **GN 918-SK**: with hexagon.

8

Nitrided and black-oxide steel cylindrical head screw on the operator side:

- **GN 918-KVS**: with angled lever- **GN 918-GVS**: with straight lever.- **GN 918-SKS**: with hexagon.

9

Nitrided and black-oxide steel cylindrical head screw on the rear side:

- **GN 918-KVB**: with angled lever- **GN 918-GVB**: with straight lever.- **GN 918-SKB**: with hexagon.

10

Suffix for the direction of the locking action:

- **L**: anticlockwise locking action.- **R**: clockwise locking action (version shown in the drawings).

11

**FEATURES AND APPLICATIONS**

GN 918 cam locking levers allow the achievement of strong locking values with safe and fast lock-unlock movements.

The system is self-locking at any angular positioning.

The lever is connected to the cam by means of a toothed element providing precise positioning while releasing the screw.

The washer eliminates the need for expensive items with female threadings and therefore the screw can be used directly on T-nuts for connection plates.



12



13



14



15



16



17



18

 
 





19

**GN 918 L/R**

Movement 270°

Movement 261,6°

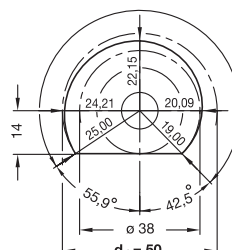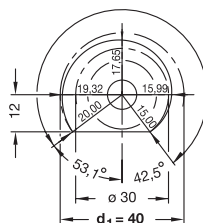

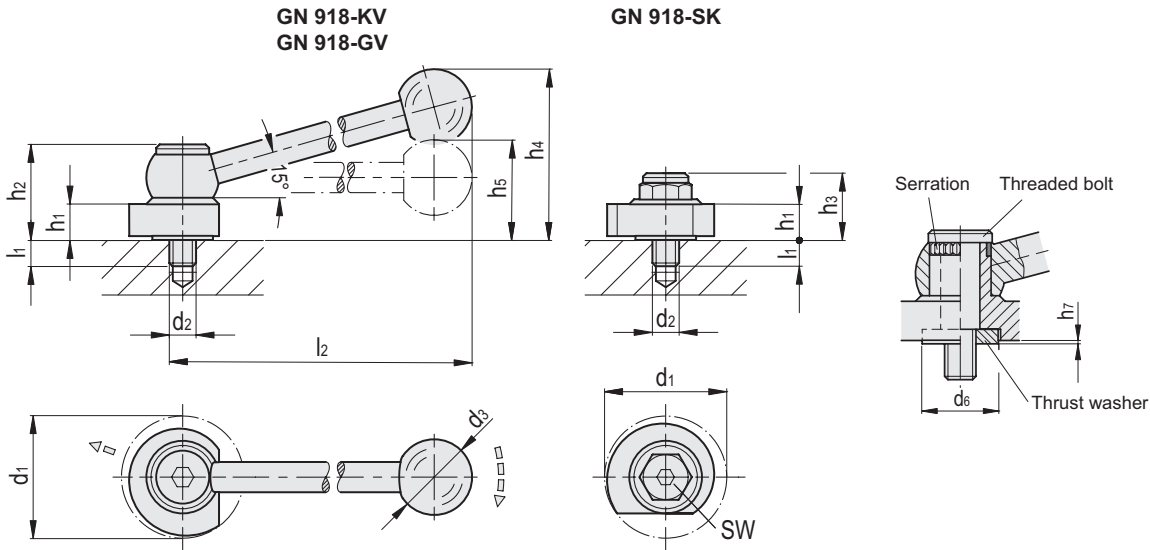

GN 918-KV


| Code     | Description    | d3 | d1 -0.5 | d2  | d6 | l1 | l2  | h1 | h2 | h4 | h7  | ⚖   |
|----------|----------------|----|---------|-----|----|----|-----|----|----|----|-----|-----|
| GN.31795 | GN 918-40-KV-L | 25 | 40      | M8  | 20 | 8  | 100 | 10 | 31 | 55 | 0.2 | 178 |
| GN.31796 | GN 918-40-KV-R | 25 | 40      | M8  | 20 | 8  | 100 | 10 | 31 | 55 | 0.2 | 177 |
| GN.31800 | GN 918-50-KV-L | 30 | 50      | M10 | 24 | 11 | 116 | 12 | 35 | 62 | 0.2 | 297 |
| GN.31801 | GN 918-50-KV-R | 30 | 50      | M10 | 24 | 11 | 116 | 12 | 35 | 62 | 0.2 | 297 |

GN 918-GV

| Code     | Description    | d3 | d1 -0.5 | d2  | d6 | l1 | l2  | h1 | h2 | h5 | h7  | ⚖   |
|----------|----------------|----|---------|-----|----|----|-----|----|----|----|-----|-----|
| GN.84501 | GN 918-40-GV-L | 25 | 40      | M8  | 20 | 8  | 100 | 10 | 31 | 31 | 0.2 | 176 |
| GN.84521 | GN 918-40-GV-R | 25 | 40      | M8  | 20 | 8  | 100 | 10 | 31 | 31 | 0.2 | 176 |
| GN.84701 | GN 918-50-GV-L | 30 | 50      | M10 | 24 | 11 | 116 | 12 | 35 | 36 | 0.2 | 297 |
| GN.84721 | GN 918-50-GV-R | 30 | 50      | M10 | 24 | 11 | 116 | 12 | 35 | 36 | 0.2 | 297 |



GN 918-SK

| Code     | Description    | d1 -0.5 | d2  | d6 | l1 | h1 | h3   | h7  | sw | ⚖   |
|----------|----------------|---------|-----|----|----|----|------|-----|----|-----|
| GN.84631 | GN 918-40-SK-L | 40      | M8  | 20 | 8  | 10 | 21.5 | 0.2 | 15 | 87  |
| GN.84651 | GN 918-40-SK-R | 40      | M8  | 20 | 8  | 10 | 21.5 | 0.2 | 15 | 88  |
| GN.84831 | GN 918-50-SK-L | 50      | M10 | 24 | 11 | 12 | 24.5 | 0.2 | 19 | 160 |
| GN.84851 | GN 918-50-SK-R | 50      | M10 | 24 | 11 | 12 | 24.5 | 0.2 | 19 | 160 |

 


Standard machine parts

3

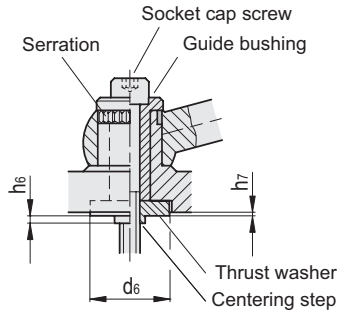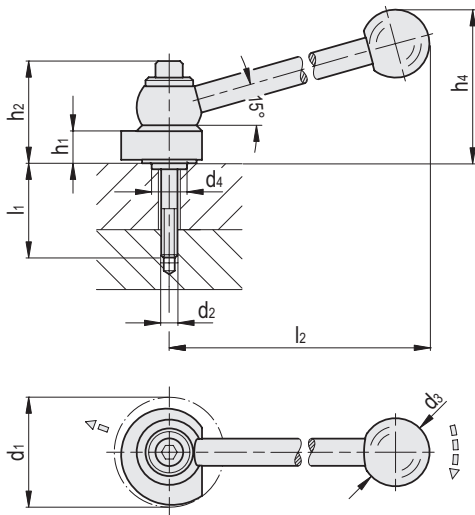


GN 918-KVS

| Code     | Description         | d3 | d1 -0.5 | d2 | d4 h9 | d6 | l1  | l2  | h1 | h2 | h4 | h6 -0.1 | h7  | Δ   |
|----------|---------------------|----|---------|----|-------|----|-----|-----|----|----|----|---------|-----|-----|
| GN.84601 | GN 918-40-KVS-L-10  | 25 | 40      | M6 | 9     | 20 | 10* | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 179 |
| GN.84602 | GN 918-40-KVS-L-15  | 25 | 40      | M6 | 9     | 20 | 15  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 180 |
| GN.84603 | GN 918-40-KVS-L-20  | 25 | 40      | M6 | 9     | 20 | 20  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 181 |
| GN.84604 | GN 918-40-KVS-L-25  | 25 | 40      | M6 | 9     | 20 | 25  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 182 |
| GN.84605 | GN 918-40-KVS-L-30  | 25 | 40      | M6 | 9     | 20 | 30  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 183 |
| GN.84606 | GN 918-40-KVS-L-40  | 25 | 40      | M6 | 9     | 20 | 40  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 185 |
| GN.84607 | GN 918-40-KVS-L-45  | 25 | 40      | M6 | 9     | 20 | 45* | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 185 |
| GN.84608 | GN 918-40-KVS-L-50  | 25 | 40      | M6 | 9     | 20 | 50  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 186 |
| GN.84609 | GN 918-40-KVS-L-60  | 25 | 40      | M6 | 9     | 20 | 60  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 188 |
| GN.84610 | GN 918-40-KVS-L-65  | 25 | 40      | M6 | 9     | 20 | 65* | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 190 |
| GN.84611 | GN 918-40-KVS-L-70  | 25 | 40      | M6 | 9     | 20 | 70  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 192 |
| GN.84612 | GN 918-40-KVS-L-80  | 25 | 40      | M6 | 9     | 20 | 80  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 193 |
| GN.84613 | GN 918-40-KVS-L-90  | 25 | 40      | M6 | 9     | 20 | 90  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 196 |
| GN.84616 | GN 918-40-KVS-R-10  | 25 | 40      | M6 | 9     | 20 | 10* | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 179 |
| GN.84617 | GN 918-40-KVS-R-15  | 25 | 40      | M6 | 9     | 20 | 15  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 180 |
| GN.84618 | GN 918-40-KVS-R-20  | 25 | 40      | M6 | 9     | 20 | 20  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 181 |
| GN.84619 | GN 918-40-KVS-R-25  | 25 | 40      | M6 | 9     | 20 | 25  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 182 |
| GN.84620 | GN 918-40-KVS-R-30  | 25 | 40      | M6 | 9     | 20 | 30  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 183 |
| GN.84621 | GN 918-40-KVS-R-40  | 25 | 40      | M6 | 9     | 20 | 40  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 185 |
| GN.84622 | GN 918-40-KVS-R-45  | 25 | 40      | M6 | 9     | 20 | 45* | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 185 |
| GN.84623 | GN 918-40-KVS-R-50  | 25 | 40      | M6 | 9     | 20 | 50  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 186 |
| GN.84624 | GN 918-40-KVS-R-60  | 25 | 40      | M6 | 9     | 20 | 60  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 188 |
| GN.84625 | GN 918-40-KVS-R-65  | 25 | 40      | M6 | 9     | 20 | 65* | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 190 |
| GN.84626 | GN 918-40-KVS-R-70  | 25 | 40      | M6 | 9     | 20 | 70  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 192 |
| GN.84627 | GN 918-40-KVS-R-80  | 25 | 40      | M6 | 9     | 20 | 80  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 193 |
| GN.84628 | GN 918-40-KVS-R-90  | 25 | 40      | M6 | 9     | 20 | 90  | 100 | 10 | 36 | 55 | 2.5     | 0.2 | 196 |
| GN.84801 | GN 918-50-KVS-L-12  | 30 | 50      | M8 | 11    | 24 | 12  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 297 |
| GN.84802 | GN 918-50-KVS-L-22  | 30 | 50      | M8 | 11    | 24 | 22  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 301 |
| GN.84803 | GN 918-50-KVS-L-32  | 30 | 50      | M8 | 11    | 24 | 32  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 305 |
| GN.84804 | GN 918-50-KVS-L-42  | 30 | 50      | M8 | 11    | 24 | 42  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 308 |
| GN.84805 | GN 918-50-KVS-L-52  | 30 | 50      | M8 | 11    | 24 | 52  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 313 |
| GN.84806 | GN 918-50-KVS-L-62  | 30 | 50      | M8 | 11    | 24 | 62  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 316 |
| GN.84807 | GN 918-50-KVS-L-72  | 30 | 50      | M8 | 11    | 24 | 72  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 320 |
| GN.84808 | GN 918-50-KVS-L-82  | 30 | 50      | M8 | 11    | 24 | 82  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 324 |
| GN.84809 | GN 918-50-KVS-L-92  | 30 | 50      | M8 | 11    | 24 | 92  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 326 |
| GN.84810 | GN 918-50-KVS-L-102 | 30 | 50      | M8 | 11    | 24 | 102 | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 324 |
| GN.84811 | GN 918-50-KVS-L-112 | 30 | 50      | M8 | 11    | 24 | 112 | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 333 |
| GN.84815 | GN 918-50-KVS-R-12  | 30 | 50      | M8 | 11    | 24 | 12  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 297 |
| GN.84816 | GN 918-50-KVS-R-22  | 30 | 50      | M8 | 11    | 24 | 22  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 301 |
| GN.84817 | GN 918-50-KVS-R-32  | 30 | 50      | M8 | 11    | 24 | 32  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 305 |
| GN.84818 | GN 918-50-KVS-R-42  | 30 | 50      | M8 | 11    | 24 | 42  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 308 |
| GN.84819 | GN 918-50-KVS-R-52  | 30 | 50      | M8 | 11    | 24 | 52  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 313 |
| GN.84820 | GN 918-50-KVS-R-62  | 30 | 50      | M8 | 11    | 24 | 62  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 316 |
| GN.84821 | GN 918-50-KVS-R-72  | 30 | 50      | M8 | 11    | 24 | 72  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 320 |
| GN.84822 | GN 918-50-KVS-R-82  | 30 | 50      | M8 | 11    | 24 | 82  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 324 |
| GN.84823 | GN 918-50-KVS-R-92  | 30 | 50      | M8 | 11    | 24 | 92  | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 326 |
| GN.84824 | GN 918-50-KVS-R-102 | 30 | 50      | M8 | 11    | 24 | 102 | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 324 |
| GN.84825 | GN 918-50-KVS-R-112 | 30 | 50      | M8 | 11    | 24 | 112 | 116 | 12 | 41 | 62 | 2.5     | 0.2 | 333 |

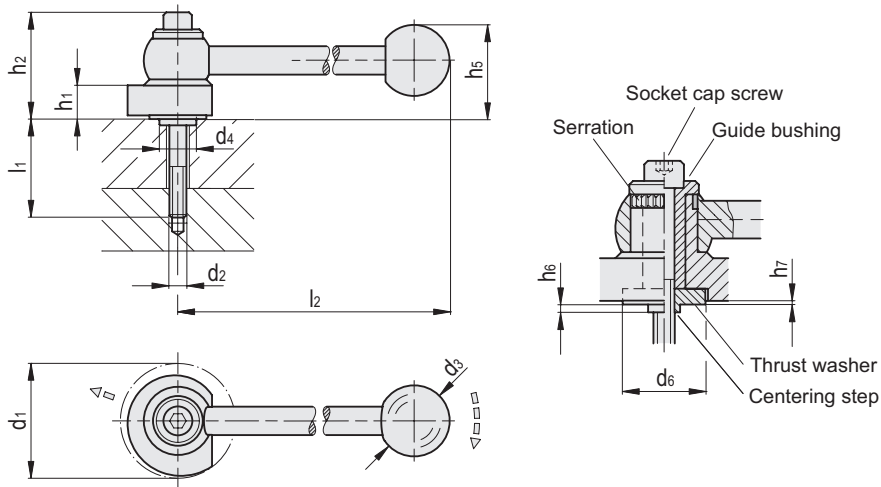


GN 918-GVS

| Code     | Description         | d3 | d1 -0.5 | d2 | d4 h9 | d6 | l1  | l2  | h1 | h2 | h5 | h6 -0.1 | h7  | Δ   |
|----------|---------------------|----|---------|----|-------|----|-----|-----|----|----|----|---------|-----|-----|
| GN.84541 | GN 918-40-GVS-L-10  | 25 | 40      | M6 | 9     | 20 | 10* | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 178 |
| GN.84542 | GN 918-40-GVS-L-15  | 25 | 40      | M6 | 9     | 20 | 15  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 178 |
| GN.84543 | GN 918-40-GVS-L-20  | 25 | 40      | M6 | 9     | 20 | 20  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 180 |
| GN.84544 | GN 918-40-GVS-L-25  | 25 | 40      | M6 | 9     | 20 | 25  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 180 |
| GN.84545 | GN 918-40-GVS-L-30  | 25 | 40      | M6 | 9     | 20 | 30  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 182 |
| GN.84546 | GN 918-40-GVS-L-40  | 25 | 40      | M6 | 9     | 20 | 40  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 183 |
| GN.84547 | GN 918-40-GVS-L-45  | 25 | 40      | M6 | 9     | 20 | 45* | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 184 |
| GN.84548 | GN 918-40-GVS-L-50  | 25 | 40      | M6 | 9     | 20 | 50  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 184 |
| GN.84549 | GN 918-40-GVS-L-60  | 25 | 40      | M6 | 9     | 20 | 60  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 186 |
| GN.84550 | GN 918-40-GVS-L-65  | 25 | 40      | M6 | 9     | 20 | 65* | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 188 |
| GN.84551 | GN 918-40-GVS-L-70  | 25 | 40      | M6 | 9     | 20 | 70  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 190 |
| GN.84552 | GN 918-40-GVS-L-80  | 25 | 40      | M6 | 9     | 20 | 80  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 192 |
| GN.84553 | GN 918-40-GVS-L-90  | 25 | 40      | M6 | 9     | 20 | 90  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 194 |
| GN.84556 | GN 918-40-GVS-R-10  | 25 | 40      | M6 | 9     | 20 | 10* | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 178 |
| GN.84557 | GN 918-40-GVS-R-15  | 25 | 40      | M6 | 9     | 20 | 15  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 178 |
| GN.84558 | GN 918-40-GVS-R-20  | 25 | 40      | M6 | 9     | 20 | 20  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 180 |
| GN.84559 | GN 918-40-GVS-R-25  | 25 | 40      | M6 | 9     | 20 | 25  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 180 |
| GN.84560 | GN 918-40-GVS-R-30  | 25 | 40      | M6 | 9     | 20 | 30  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 182 |
| GN.84561 | GN 918-40-GVS-R-40  | 25 | 40      | M6 | 9     | 20 | 40  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 183 |
| GN.84562 | GN 918-40-GVS-R-45  | 25 | 40      | M6 | 9     | 20 | 45* | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 184 |
| GN.84563 | GN 918-40-GVS-R-50  | 25 | 40      | M6 | 9     | 20 | 50  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 184 |
| GN.84564 | GN 918-40-GVS-R-60  | 25 | 40      | M6 | 9     | 20 | 60  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 186 |
| GN.84565 | GN 918-40-GVS-R-65  | 25 | 40      | M6 | 9     | 20 | 65* | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 188 |
| GN.84566 | GN 918-40-GVS-R-70  | 25 | 40      | M6 | 9     | 20 | 70  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 190 |
| GN.84567 | GN 918-40-GVS-R-80  | 25 | 40      | M6 | 9     | 20 | 80  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 192 |
| GN.84568 | GN 918-40-GVS-R-90  | 25 | 40      | M6 | 9     | 20 | 90  | 100 | 10 | 36 | 31 | 2.5     | 0.2 | 194 |
| GN.84741 | GN 918-50-GVS-L-12  | 30 | 50      | M8 | 11    | 24 | 12  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 297 |
| GN.84742 | GN 918-50-GVS-L-22  | 30 | 50      | M8 | 11    | 24 | 22  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 301 |
| GN.84743 | GN 918-50-GVS-L-32  | 30 | 50      | M8 | 11    | 24 | 32  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 305 |
| GN.84744 | GN 918-50-GVS-L-42  | 30 | 50      | M8 | 11    | 24 | 42  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 308 |
| GN.84745 | GN 918-50-GVS-L-52  | 30 | 50      | M8 | 11    | 24 | 52  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 313 |
| GN.84746 | GN 918-50-GVS-L-62  | 30 | 50      | M8 | 11    | 24 | 62  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 316 |
| GN.84747 | GN 918-50-GVS-L-72  | 30 | 50      | M8 | 11    | 24 | 72  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 320 |
| GN.84748 | GN 918-50-GVS-L-82  | 30 | 50      | M8 | 11    | 24 | 82  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 324 |
| GN.84749 | GN 918-50-GVS-L-92  | 30 | 50      | M8 | 11    | 24 | 92  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 326 |
| GN.84750 | GN 918-50-GVS-L-102 | 30 | 50      | M8 | 11    | 24 | 102 | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 324 |
| GN.84751 | GN 918-50-GVS-L-112 | 30 | 50      | M8 | 11    | 24 | 112 | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 333 |
| GN.84755 | GN 918-50-GVS-R-12  | 30 | 50      | M8 | 11    | 24 | 12  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 297 |
| GN.84756 | GN 918-50-GVS-R-22  | 30 | 50      | M8 | 11    | 24 | 22  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 301 |
| GN.84757 | GN 918-50-GVS-R-32  | 30 | 50      | M8 | 11    | 24 | 32  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 305 |
| GN.84758 | GN 918-50-GVS-R-42  | 30 | 50      | M8 | 11    | 24 | 42  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 308 |
| GN.84759 | GN 918-50-GVS-R-52  | 30 | 50      | M8 | 11    | 24 | 52  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 313 |
| GN.84760 | GN 918-50-GVS-R-62  | 30 | 50      | M8 | 11    | 24 | 62  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 316 |
| GN.84761 | GN 918-50-GVS-R-72  | 30 | 50      | M8 | 11    | 24 | 72  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 320 |
| GN.84762 | GN 918-50-GVS-R-82  | 30 | 50      | M8 | 11    | 24 | 82  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 324 |
| GN.84763 | GN 918-50-GVS-R-92  | 30 | 50      | M8 | 11    | 24 | 92  | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 326 |
| GN.84764 | GN 918-50-GVS-R-102 | 30 | 50      | M8 | 11    | 24 | 102 | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 324 |
| GN.84765 | GN 918-50-GVS-R-112 | 30 | 50      | M8 | 11    | 24 | 112 | 116 | 12 | 41 | 36 | 2.5     | 0.2 | 333 |

 


Standard machine parts

5

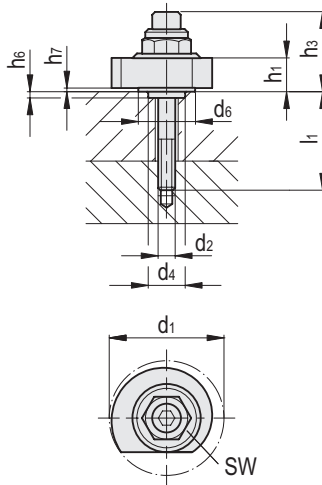

GN 918-SKS

| Code     | Description         | d1 -0.5 | d2 | d4 h9 | d6 | l1   | h1 | h3 | h6 -0.1 | h7  | sw | △   |
|----------|---------------------|---------|----|-------|----|------|----|----|---------|-----|----|-----|
| GN.84671 | GN 918-40-SKS-L-15  | 40      | M6 | 9     | 20 | 15   | 10 | 26 | 2.5     | 0.2 | 15 | 92  |
| GN.84672 | GN 918-40-SKS-L-20  | 40      | M6 | 9     | 20 | 20   | 10 | 26 | 2.5     | 0.2 | 15 | 92  |
| GN.84673 | GN 918-40-SKS-L-25  | 40      | M6 | 9     | 20 | 25   | 10 | 26 | 2.5     | 0.2 | 15 | 94  |
| GN.84674 | GN 918-40-SKS-L-30  | 40      | M6 | 9     | 20 | 30   | 10 | 26 | 2.5     | 0.2 | 15 | 94  |
| GN.84675 | GN 918-40-SKS-L-35  | 40      | M6 | 9     | 20 | 35   | 10 | 26 | 2.5     | 0.2 | 15 | 96  |
| GN.84676 | GN 918-40-SKS-L-40  | 40      | M6 | 9     | 20 | 40   | 10 | 26 | 2.5     | 0.2 | 15 | 97  |
| GN.84677 | GN 918-40-SKS-L-50  | 40      | M6 | 9     | 20 | 50   | 10 | 26 | 2.5     | 0.2 | 15 | 98  |
| GN.84678 | GN 918-40-SKS-L-55  | 40      | M6 | 9     | 20 | 55** | 10 | 26 | 2.5     | 0.2 | 15 | 98  |
| GN.84679 | GN 918-40-SKS-L-60  | 40      | M6 | 9     | 20 | 60   | 10 | 26 | 2.5     | 0.2 | 15 | 100 |
| GN.84680 | GN 918-40-SKS-L-70  | 40      | M6 | 9     | 20 | 70   | 10 | 26 | 2.5     | 0.2 | 15 | 102 |
| GN.84681 | GN 918-40-SKS-L-75  | 40      | M6 | 9     | 20 | 75** | 10 | 26 | 2.5     | 0.2 | 15 | 104 |
| GN.84682 | GN 918-40-SKS-L-80  | 40      | M6 | 9     | 20 | 80   | 10 | 26 | 2.5     | 0.2 | 15 | 106 |
| GN.84683 | GN 918-40-SKS-L-90  | 40      | M6 | 9     | 20 | 90   | 10 | 26 | 2.5     | 0.2 | 15 | 108 |
| GN.84686 | GN 918-40-SKS-R-15  | 40      | M6 | 9     | 20 | 15   | 10 | 26 | 2.5     | 0.2 | 15 | 92  |
| GN.84687 | GN 918-40-SKS-R-20  | 40      | M6 | 9     | 20 | 20   | 10 | 26 | 2.5     | 0.2 | 15 | 92  |
| GN.84688 | GN 918-40-SKS-R-25  | 40      | M6 | 9     | 20 | 25   | 10 | 26 | 2.5     | 0.2 | 15 | 94  |
| GN.84689 | GN 918-40-SKS-R-30  | 40      | M6 | 9     | 20 | 30   | 10 | 26 | 2.5     | 0.2 | 15 | 94  |
| GN.84690 | GN 918-40-SKS-R-35  | 40      | M6 | 9     | 20 | 35   | 10 | 26 | 2.5     | 0.2 | 15 | 96  |
| GN.84691 | GN 918-40-SKS-R-40  | 40      | M6 | 9     | 20 | 40   | 10 | 26 | 2.5     | 0.2 | 15 | 97  |
| GN.84692 | GN 918-40-SKS-R-50  | 40      | M6 | 9     | 20 | 50   | 10 | 26 | 2.5     | 0.2 | 15 | 98  |
| GN.84693 | GN 918-40-SKS-R-55  | 40      | M6 | 9     | 20 | 55** | 10 | 26 | 2.5     | 0.2 | 15 | 98  |
| GN.84694 | GN 918-40-SKS-R-60  | 40      | M6 | 9     | 20 | 60   | 10 | 26 | 2.5     | 0.2 | 15 | 100 |
| GN.84695 | GN 918-40-SKS-R-70  | 40      | M6 | 9     | 20 | 70   | 10 | 26 | 2.5     | 0.2 | 15 | 102 |
| GN.84696 | GN 918-40-SKS-R-75  | 40      | M6 | 9     | 20 | 75** | 10 | 26 | 2.5     | 0.2 | 15 | 104 |
| GN.84697 | GN 918-40-SKS-R-80  | 40      | M6 | 9     | 20 | 80   | 10 | 26 | 2.5     | 0.2 | 15 | 106 |
| GN.84698 | GN 918-40-SKS-R-90  | 40      | M6 | 9     | 20 | 90   | 10 | 26 | 2.5     | 0.2 | 15 | 108 |
| GN.84871 | GN 918-50-SKS-L-12  | 50      | M8 | 11    | 24 | 12   | 12 | 31 | 2.5     | 0.2 | 19 | 165 |
| GN.84872 | GN 918-50-SKS-L-22  | 50      | M8 | 11    | 24 | 22   | 12 | 31 | 2.5     | 0.2 | 19 | 169 |
| GN.84873 | GN 918-50-SKS-L-32  | 50      | M8 | 11    | 24 | 32   | 12 | 31 | 2.5     | 0.2 | 19 | 173 |
| GN.84874 | GN 918-50-SKS-L-42  | 50      | M8 | 11    | 24 | 42   | 12 | 31 | 2.5     | 0.2 | 19 | 176 |
| GN.84875 | GN 918-50-SKS-L-52  | 50      | M8 | 11    | 24 | 52   | 12 | 31 | 2.5     | 0.2 | 19 | 181 |
| GN.84876 | GN 918-50-SKS-L-62  | 50      | M8 | 11    | 24 | 62   | 12 | 31 | 2.5     | 0.2 | 19 | 184 |
| GN.84877 | GN 918-50-SKS-L-72  | 50      | M8 | 11    | 24 | 72   | 12 | 31 | 2.5     | 0.2 | 19 | 188 |
| GN.84878 | GN 918-50-SKS-L-82  | 50      | M8 | 11    | 24 | 82   | 12 | 31 | 2.5     | 0.2 | 19 | 192 |
| GN.84879 | GN 918-50-SKS-L-92  | 50      | M8 | 11    | 24 | 92   | 12 | 31 | 2.5     | 0.2 | 19 | 194 |
| GN.84880 | GN 918-50-SKS-L-102 | 50      | M8 | 11    | 24 | 102  | 12 | 31 | 2.5     | 0.2 | 19 | 192 |
| GN.84881 | GN 918-50-SKS-L-112 | 50      | M8 | 11    | 24 | 112  | 12 | 31 | 2.5     | 0.2 | 19 | 201 |
| GN.84886 | GN 918-50-SKS-R-12  | 50      | M8 | 11    | 24 | 12   | 12 | 31 | 2.5     | 0.2 | 19 | 165 |
| GN.84887 | GN 918-50-SKS-R-22  | 50      | M8 | 11    | 24 | 22   | 12 | 31 | 2.5     | 0.2 | 19 | 169 |
| GN.84888 | GN 918-50-SKS-R-32  | 50      | M8 | 11    | 24 | 32   | 12 | 31 | 2.5     | 0.2 | 19 | 173 |
| GN.84889 | GN 918-50-SKS-R-42  | 50      | M8 | 11    | 24 | 42   | 12 | 31 | 2.5     | 0.2 | 19 | 176 |
| GN.84890 | GN 918-50-SKS-R-52  | 50      | M8 | 11    | 24 | 52   | 12 | 31 | 2.5     | 0.2 | 19 | 181 |
| GN.84891 | GN 918-50-SKS-R-62  | 50      | M8 | 11    | 24 | 62   | 12 | 31 | 2.5     | 0.2 | 19 | 184 |
| GN.84892 | GN 918-50-SKS-R-72  | 50      | M8 | 11    | 24 | 72   | 12 | 31 | 2.5     | 0.2 | 19 | 188 |
| GN.84893 | GN 918-50-SKS-R-82  | 50      | M8 | 11    | 24 | 82   | 12 | 31 | 2.5     | 0.2 | 19 | 192 |
| GN.84894 | GN 918-50-SKS-R-92  | 50      | M8 | 11    | 24 | 92   | 12 | 31 | 2.5     | 0.2 | 19 | 194 |
| GN.84895 | GN 918-50-SKS-R-102 | 50      | M8 | 11    | 24 | 102  | 12 | 31 | 2.5     | 0.2 | 19 | 192 |
| GN.84896 | GN 918-50-SKS-R-112 | 50      | M8 | 11    | 24 | 112  | 12 | 31 | 2.5     | 0.2 | 19 | 201 |

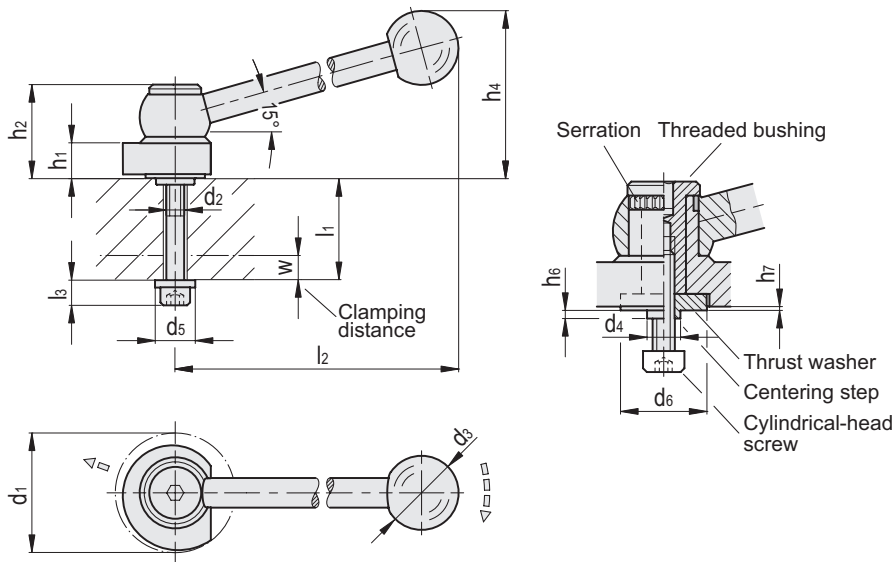


GN 918-KVB



| Code     | Description         | d3 | d1 -0.5 | d2 | d4 h9 | d5 | d6 | l1 max | l2  | l3   | h1 | h2   | h4 | h6 -0.1 | h7  | wmax |  |
|----------|---------------------|----|---------|----|-------|----|----|--------|-----|------|----|------|----|---------|-----|------|-------------------------------------------------------------------------------------|
| GN.84571 | GN 918-40-KVB-L-12  | 25 | 40      | M6 | 9     | 12 | 20 | 12     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 180                                                                                 |
| GN.84572 | GN 918-40-KVB-L-22  | 25 | 40      | M6 | 9     | 12 | 20 | 22     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 182                                                                                 |
| GN.84573 | GN 918-40-KVB-L-27  | 25 | 40      | M6 | 9     | 12 | 20 | 27     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 183                                                                                 |
| GN.84574 | GN 918-40-KVB-L-32  | 25 | 40      | M6 | 9     | 12 | 20 | 32     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 184                                                                                 |
| GN.84575 | GN 918-40-KVB-L-37  | 25 | 40      | M6 | 9     | 12 | 20 | 37     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 185                                                                                 |
| GN.84576 | GN 918-40-KVB-L-42  | 25 | 40      | M6 | 9     | 12 | 20 | 42     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 186                                                                                 |
| GN.84577 | GN 918-40-KVB-L-47  | 25 | 40      | M6 | 9     | 12 | 20 | 47     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 187                                                                                 |
| GN.84578 | GN 918-40-KVB-L-57  | 25 | 40      | M6 | 9     | 12 | 20 | 57     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 189                                                                                 |
| GN.84579 | GN 918-40-KVB-L-62  | 25 | 40      | M6 | 9     | 12 | 20 | 62     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 189                                                                                 |
| GN.84580 | GN 918-40-KVB-L-67  | 25 | 40      | M6 | 9     | 12 | 20 | 67     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 190                                                                                 |
| GN.84581 | GN 918-40-KVB-L-77  | 25 | 40      | M6 | 9     | 12 | 20 | 77     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 192                                                                                 |
| GN.84582 | GN 918-40-KVB-L-82  | 25 | 40      | M6 | 9     | 12 | 20 | 82     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 194                                                                                 |
| GN.84586 | GN 918-40-KVB-R-12  | 25 | 40      | M6 | 9     | 12 | 20 | 12     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 180                                                                                 |
| GN.84587 | GN 918-40-KVB-R-22  | 25 | 40      | M6 | 9     | 12 | 20 | 22     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 182                                                                                 |
| GN.84588 | GN 918-40-KVB-R-27  | 25 | 40      | M6 | 9     | 12 | 20 | 27     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 183                                                                                 |
| GN.84589 | GN 918-40-KVB-R-32  | 25 | 40      | M6 | 9     | 12 | 20 | 32     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 184                                                                                 |
| GN.84590 | GN 918-40-KVB-R-37  | 25 | 40      | M6 | 9     | 12 | 20 | 37     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 185                                                                                 |
| GN.84591 | GN 918-40-KVB-R-42  | 25 | 40      | M6 | 9     | 12 | 20 | 42     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 186                                                                                 |
| GN.84592 | GN 918-40-KVB-R-47  | 25 | 40      | M6 | 9     | 12 | 20 | 47     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 187                                                                                 |
| GN.84593 | GN 918-40-KVB-R-57  | 25 | 40      | M6 | 9     | 12 | 20 | 57     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 189                                                                                 |
| GN.84594 | GN 918-40-KVB-R-62  | 25 | 40      | M6 | 9     | 12 | 20 | 62     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 189                                                                                 |
| GN.84595 | GN 918-40-KVB-R-67  | 25 | 40      | M6 | 9     | 12 | 20 | 67     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 190                                                                                 |
| GN.84596 | GN 918-40-KVB-R-77  | 25 | 40      | M6 | 9     | 12 | 20 | 77     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 192                                                                                 |
| GN.84597 | GN 918-40-KVB-R-82  | 25 | 40      | M6 | 9     | 12 | 20 | 82     | 100 | 8.5  | 10 | 30.5 | 55 | 2.5     | 0.2 | 5    | 194                                                                                 |
| GN.84771 | GN 918-50-KVB-L-10  | 30 | 50      | M8 | 11    | 16 | 24 | 10     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 301                                                                                 |
| GN.84772 | GN 918-50-KVB-L-20  | 30 | 50      | M8 | 11    | 16 | 24 | 20     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 303                                                                                 |
| GN.84773 | GN 918-50-KVB-L-30  | 30 | 50      | M8 | 11    | 16 | 24 | 30     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 307                                                                                 |
| GN.84774 | GN 918-50-KVB-L-40  | 30 | 50      | M8 | 11    | 16 | 24 | 40     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 311                                                                                 |
| GN.84775 | GN 918-50-KVB-L-50  | 30 | 50      | M8 | 11    | 16 | 24 | 50     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 315                                                                                 |
| GN.84776 | GN 918-50-KVB-L-60  | 30 | 50      | M8 | 11    | 16 | 24 | 60     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 318                                                                                 |
| GN.84777 | GN 918-50-KVB-L-70  | 30 | 50      | M8 | 11    | 16 | 24 | 70     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 323                                                                                 |
| GN.84778 | GN 918-50-KVB-L-80  | 30 | 50      | M8 | 11    | 16 | 24 | 80     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 326                                                                                 |
| GN.84779 | GN 918-50-KVB-L-90  | 30 | 50      | M8 | 11    | 16 | 24 | 90     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 330                                                                                 |
| GN.84780 | GN 918-50-KVB-L-100 | 30 | 50      | M8 | 11    | 16 | 24 | 100    | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 334                                                                                 |
| GN.84785 | GN 918-50-KVB-R-10  | 30 | 50      | M8 | 11    | 16 | 24 | 10     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 301                                                                                 |
| GN.84786 | GN 918-50-KVB-R-20  | 30 | 50      | M8 | 11    | 16 | 24 | 20     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 303                                                                                 |
| GN.84787 | GN 918-50-KVB-R-30  | 30 | 50      | M8 | 11    | 16 | 24 | 30     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 307                                                                                 |
| GN.84788 | GN 918-50-KVB-R-40  | 30 | 50      | M8 | 11    | 16 | 24 | 40     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 311                                                                                 |
| GN.84789 | GN 918-50-KVB-R-50  | 30 | 50      | M8 | 11    | 16 | 24 | 50     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 315                                                                                 |
| GN.84790 | GN 918-50-KVB-R-60  | 30 | 50      | M8 | 11    | 16 | 24 | 60     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 318                                                                                 |
| GN.84791 | GN 918-50-KVB-R-70  | 30 | 50      | M8 | 11    | 16 | 24 | 70     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 323                                                                                 |
| GN.84792 | GN 918-50-KVB-R-80  | 30 | 50      | M8 | 11    | 16 | 24 | 80     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 326                                                                                 |
| GN.84793 | GN 918-50-KVB-R-90  | 30 | 50      | M8 | 11    | 16 | 24 | 90     | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 330                                                                                 |
| GN.84794 | GN 918-50-KVB-R-100 | 30 | 50      | M8 | 11    | 16 | 24 | 100    | 116 | 10.5 | 12 | 34.5 | 62 | 2.5     | 0.2 | 5    | 334                                                                                 |





 


Standard machine parts

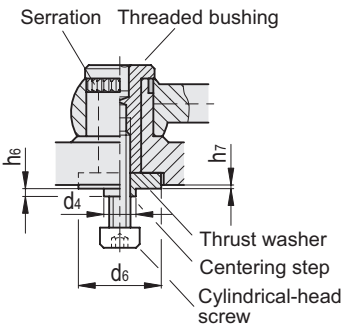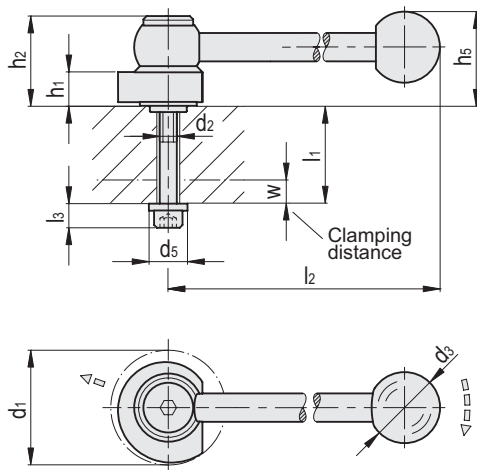

GN 918-GVB

| Code     | Description         | d3 | d1 -0.5 | d2 | d4 h9 | d5 | d6 | l1 max | l2  | l3   | h1 | h2   | h5 | h6 -0.1 | h7  | wmax | Δ   |
|----------|---------------------|----|---------|----|-------|----|----|--------|-----|------|----|------|----|---------|-----|------|-----|
| GN.84506 | GN 918-40-GVB-L-12  | 25 | 40      | M6 | 9     | 12 | 20 | 12     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 178 |
| GN.84507 | GN 918-40-GVB-L-22  | 25 | 40      | M6 | 9     | 12 | 20 | 22     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 180 |
| GN.84508 | GN 918-40-GVB-L-27  | 25 | 40      | M6 | 9     | 12 | 20 | 27     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 182 |
| GN.84509 | GN 918-40-GVB-L-32  | 25 | 40      | M6 | 9     | 12 | 20 | 32     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 182 |
| GN.84510 | GN 918-40-GVB-L-37  | 25 | 40      | M6 | 9     | 12 | 20 | 37     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 184 |
| GN.84511 | GN 918-40-GVB-L-42  | 25 | 40      | M6 | 9     | 12 | 20 | 42     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 184 |
| GN.84512 | GN 918-40-GVB-L-47  | 25 | 40      | M6 | 9     | 12 | 20 | 47     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 186 |
| GN.84513 | GN 918-40-GVB-L-57  | 25 | 40      | M6 | 9     | 12 | 20 | 57     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 187 |
| GN.84514 | GN 918-40-GVB-L-62  | 25 | 40      | M6 | 9     | 12 | 20 | 62     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 188 |
| GN.84515 | GN 918-40-GVB-L-67  | 25 | 40      | M6 | 9     | 12 | 20 | 67     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 188 |
| GN.84516 | GN 918-40-GVB-L-77  | 25 | 40      | M6 | 9     | 12 | 20 | 77     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 190 |
| GN.84517 | GN 918-40-GVB-L-82  | 25 | 40      | M6 | 9     | 12 | 20 | 82     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 192 |
| GN.84526 | GN 918-40-GVB-R-12  | 25 | 40      | M6 | 9     | 12 | 20 | 12     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 178 |
| GN.84527 | GN 918-40-GVB-R-22  | 25 | 40      | M6 | 9     | 12 | 20 | 22     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 180 |
| GN.84528 | GN 918-40-GVB-R-27  | 25 | 40      | M6 | 9     | 12 | 20 | 27     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 182 |
| GN.84529 | GN 918-40-GVB-R-32  | 25 | 40      | M6 | 9     | 12 | 20 | 32     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 182 |
| GN.84530 | GN 918-40-GVB-R-37  | 25 | 40      | M6 | 9     | 12 | 20 | 37     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 184 |
| GN.84531 | GN 918-40-GVB-R-42  | 25 | 40      | M6 | 9     | 12 | 20 | 42     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 184 |
| GN.84532 | GN 918-40-GVB-R-47  | 25 | 40      | M6 | 9     | 12 | 20 | 47     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 186 |
| GN.84533 | GN 918-40-GVB-R-57  | 25 | 40      | M6 | 9     | 12 | 20 | 57     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 187 |
| GN.84534 | GN 918-40-GVB-R-62  | 25 | 40      | M6 | 9     | 12 | 20 | 62     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 188 |
| GN.84535 | GN 918-40-GVB-R-67  | 25 | 40      | M6 | 9     | 12 | 20 | 67     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 188 |
| GN.84536 | GN 918-40-GVB-R-77  | 25 | 40      | M6 | 9     | 12 | 20 | 77     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 190 |
| GN.84537 | GN 918-40-GVB-R-82  | 25 | 40      | M6 | 9     | 12 | 20 | 82     | 100 | 8.5  | 10 | 30.5 | 31 | 2.5     | 0.2 | 5    | 192 |
| GN.84706 | GN 918-50-GVB-L-10  | 30 | 50      | M8 | 11    | 16 | 24 | 10     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 301 |
| GN.84707 | GN 918-50-GVB-L-20  | 30 | 50      | M8 | 11    | 16 | 24 | 20     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 303 |
| GN.84708 | GN 918-50-GVB-L-30  | 30 | 50      | M8 | 11    | 16 | 24 | 30     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 307 |
| GN.84709 | GN 918-50-GVB-L-40  | 30 | 50      | M8 | 11    | 16 | 24 | 40     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 311 |
| GN.84710 | GN 918-50-GVB-L-50  | 30 | 50      | M8 | 11    | 16 | 24 | 50     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 315 |
| GN.84711 | GN 918-50-GVB-L-60  | 30 | 50      | M8 | 11    | 16 | 24 | 60     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 318 |
| GN.84712 | GN 918-50-GVB-L-70  | 30 | 50      | M8 | 11    | 16 | 24 | 70     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 323 |
| GN.84713 | GN 918-50-GVB-L-80  | 30 | 50      | M8 | 11    | 16 | 24 | 80     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 326 |
| GN.84714 | GN 918-50-GVB-L-90  | 30 | 50      | M8 | 11    | 16 | 24 | 90     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 330 |
| GN.84716 | GN 918-50-GVB-L-100 | 30 | 50      | M8 | 11    | 16 | 24 | 100    | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 334 |
| GN.84725 | GN 918-50-GVB-R-10  | 30 | 50      | M8 | 11    | 16 | 24 | 10     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 301 |
| GN.84726 | GN 918-50-GVB-R-20  | 30 | 50      | M8 | 11    | 16 | 24 | 20     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 303 |
| GN.84727 | GN 918-50-GVB-R-30  | 30 | 50      | M8 | 11    | 16 | 24 | 30     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 307 |
| GN.84728 | GN 918-50-GVB-R-40  | 30 | 50      | M8 | 11    | 16 | 24 | 40     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 311 |
| GN.84729 | GN 918-50-GVB-R-50  | 30 | 50      | M8 | 11    | 16 | 24 | 50     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 315 |
| GN.84730 | GN 918-50-GVB-R-60  | 30 | 50      | M8 | 11    | 16 | 24 | 60     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 318 |
| GN.84731 | GN 918-50-GVB-R-70  | 30 | 50      | M8 | 11    | 16 | 24 | 70     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 323 |
| GN.84732 | GN 918-50-GVB-R-80  | 30 | 50      | M8 | 11    | 16 | 24 | 80     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 326 |
| GN.84733 | GN 918-50-GVB-R-90  | 30 | 50      | M8 | 11    | 16 | 24 | 90     | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 330 |
| GN.84734 | GN 918-50-GVB-R-100 | 30 | 50      | M8 | 11    | 16 | 24 | 100    | 116 | 10.5 | 12 | 34.5 | 36 | 2.5     | 0.2 | 5    | 334 |

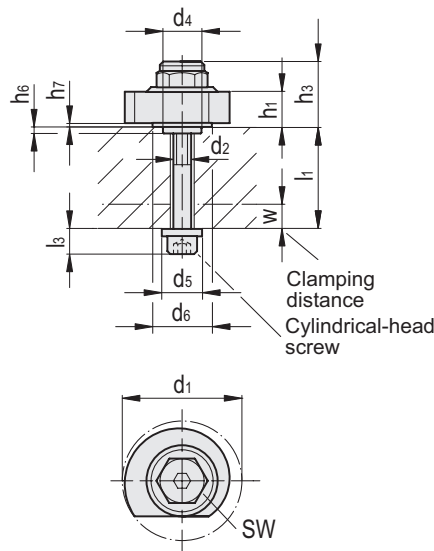

GN 918-SKB

| Code     | Description         | d1 -0.5 | d2 | d4 h9 | d5 | d6 | l1 max | l3   | h1 | h3 | h6 -0.1 | h7  | wmax | ⚖   |
|----------|---------------------|---------|----|-------|----|----|--------|------|----|----|---------|-----|------|-----|
| GN.84636 | GN 918-40-SKB-L-12  | 40      | M6 | 9     | 12 | 20 | 12     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 92  |
| GN.84637 | GN 918-40-SKB-L-22  | 40      | M6 | 9     | 12 | 20 | 22     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 94  |
| GN.84638 | GN 918-40-SKB-L-27  | 40      | M6 | 9     | 12 | 20 | 27     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 96  |
| GN.84639 | GN 918-40-SKB-L-32  | 40      | M6 | 9     | 12 | 20 | 32     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 96  |
| GN.84640 | GN 918-40-SKB-L-37  | 40      | M6 | 9     | 12 | 20 | 37     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 98  |
| GN.84641 | GN 918-40-SKB-L-42  | 40      | M6 | 9     | 12 | 20 | 42     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 98  |
| GN.84642 | GN 918-40-SKB-L-47  | 40      | M6 | 9     | 12 | 20 | 47     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 100 |
| GN.84643 | GN 918-40-SKB-L-57  | 40      | M6 | 9     | 12 | 20 | 57     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 101 |
| GN.84644 | GN 918-40-SKB-L-62  | 40      | M6 | 9     | 12 | 20 | 62     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 102 |
| GN.84645 | GN 918-40-SKB-L-67  | 40      | M6 | 9     | 12 | 20 | 67     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 102 |
| GN.84646 | GN 918-40-SKB-L-77  | 40      | M6 | 9     | 12 | 20 | 77     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 104 |
| GN.84647 | GN 918-40-SKB-L-82  | 40      | M6 | 9     | 12 | 20 | 82     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 106 |
| GN.84656 | GN 918-40-SKB-R-12  | 40      | M6 | 9     | 12 | 20 | 12     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 92  |
| GN.84657 | GN 918-40-SKB-R-22  | 40      | M6 | 9     | 12 | 20 | 22     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 94  |
| GN.84658 | GN 918-40-SKB-R-27  | 40      | M6 | 9     | 12 | 20 | 27     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 96  |
| GN.84659 | GN 918-40-SKB-R-32  | 40      | M6 | 9     | 12 | 20 | 32     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 96  |
| GN.84660 | GN 918-40-SKB-R-37  | 40      | M6 | 9     | 12 | 20 | 37     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 98  |
| GN.84661 | GN 918-40-SKB-R-42  | 40      | M6 | 9     | 12 | 20 | 42     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 98  |
| GN.84662 | GN 918-40-SKB-R-47  | 40      | M6 | 9     | 12 | 20 | 47     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 100 |
| GN.84663 | GN 918-40-SKB-R-57  | 40      | M6 | 9     | 12 | 20 | 57     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 101 |
| GN.84664 | GN 918-40-SKB-R-62  | 40      | M6 | 9     | 12 | 20 | 62     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 102 |
| GN.84665 | GN 918-40-SKB-R-67  | 40      | M6 | 9     | 12 | 20 | 67     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 102 |
| GN.84666 | GN 918-40-SKB-R-77  | 40      | M6 | 9     | 12 | 20 | 77     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 104 |
| GN.84667 | GN 918-40-SKB-R-82  | 40      | M6 | 9     | 12 | 20 | 82     | 8.5  | 10 | 21 | 2.5     | 0.2 | 5    | 106 |
| GN.84835 | GN 918-50-SKB-L-10  | 50      | M8 | 11    | 16 | 24 | 10     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 165 |
| GN.84836 | GN 918-50-SKB-L-20  | 50      | M8 | 11    | 16 | 24 | 20     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 167 |
| GN.84837 | GN 918-50-SKB-L-30  | 50      | M8 | 11    | 16 | 24 | 30     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 171 |
| GN.84838 | GN 918-50-SKB-L-40  | 50      | M8 | 11    | 16 | 24 | 40     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 175 |
| GN.84839 | GN 918-50-SKB-L-50  | 50      | M8 | 11    | 16 | 24 | 50     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 179 |
| GN.84840 | GN 918-50-SKB-L-60  | 50      | M8 | 11    | 16 | 24 | 60     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 182 |
| GN.84841 | GN 918-50-SKB-L-70  | 50      | M8 | 11    | 16 | 24 | 70     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 187 |
| GN.84842 | GN 918-50-SKB-L-80  | 50      | M8 | 11    | 16 | 24 | 80     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 190 |
| GN.84843 | GN 918-50-SKB-L-90  | 50      | M8 | 11    | 16 | 24 | 90     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 194 |
| GN.84844 | GN 918-50-SKB-L-100 | 50      | M8 | 11    | 16 | 24 | 100    | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 198 |
| GN.84855 | GN 918-50-SKB-R-10  | 50      | M8 | 11    | 16 | 24 | 10     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 165 |
| GN.84856 | GN 918-50-SKB-R-20  | 50      | M8 | 11    | 16 | 24 | 20     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 167 |
| GN.84857 | GN 918-50-SKB-R-30  | 50      | M8 | 11    | 16 | 24 | 30     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 171 |
| GN.84858 | GN 918-50-SKB-R-40  | 50      | M8 | 11    | 16 | 24 | 40     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 175 |
| GN.84859 | GN 918-50-SKB-R-50  | 50      | M8 | 11    | 16 | 24 | 50     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 179 |
| GN.84860 | GN 918-50-SKB-R-60  | 50      | M8 | 11    | 16 | 24 | 60     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 182 |
| GN.84861 | GN 918-50-SKB-R-70  | 50      | M8 | 11    | 16 | 24 | 70     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 187 |
| GN.84862 | GN 918-50-SKB-R-80  | 50      | M8 | 11    | 16 | 24 | 80     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 190 |
| GN.84863 | GN 918-50-SKB-R-90  | 50      | M8 | 11    | 16 | 24 | 90     | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 194 |
| GN.84864 | GN 918-50-SKB-R-100 | 50      | M8 | 11    | 16 | 24 | 100    | 10.5 | 12 | 24 | 2.5     | 0.2 | 5    | 198 |

