

**Pressed steel
spoked handwheels**

RoHS

• **Material**

AISI 316L pressed stainless steel, sandblasted matte finish.

• **Standard executions**

- **GN 227.4-B**: welded hub, H9 reamed pass-through hole.
- **GN 227.4-V**: welded hub, H11 square pass-through hole.

Features and applications


AISI 316L stainless steel (A4 quality) GN 227.4 handwheels are available without handle only. Thanks to their high mechanical strength they are particularly suitable for applications that may receive knocks and bumps.

Special executions on request


Handwheels with keyway in compliance with DIN 6885/1 tolerance P9 .



GN 227.4-B

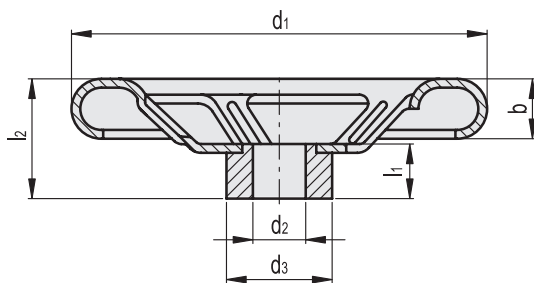

GN 227.4-V

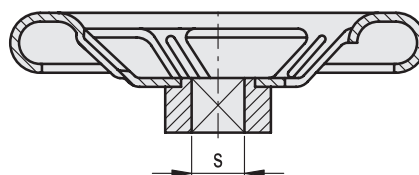

Code	Description	d1	d2 H9*	SH11	d3	b	l1	l2	Spokes no.	Thickness stainless steel	⚖
GN.25381	GN 227.4-160-B12-A	160	12	-	30	22	20	39	4	2	430
GN.25382	GN 227.4-160-V12-A	160	-	12	30	22	20	39	4	2	428
GN.25384	GN 227.4-200-B14-A	200	14	-	40	22	24	44	4	2.5	824
GN.25385	GN 227.4-200-V14-A	200	-	14	40	22	24	44	4	2.5	824
GN.25387	GN 227.4-250-B17-A	250	17	-	45	30	28	52	5	3	1477
GN.25398	GN 227.4-250-V17-A	250	-	17	45	30	28	52	5	3	1465
GN.25401	GN 227.4-315-B19-A	315	19	-	55	36	33	64	5	3	2330
GN.25402	GN 227.4-315-V19-A	315	-	19	55	36	33	64	5	3	2100
GN.25404	GN 227.4-400-B24-A	400	24	-	65	43	38	81	5	3	4210
GN.25405	GN 227.4-400-V24-A	400	-	24	65	43	38	81	5	3	4180