

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19

**BODY AND EXTERNAL BUSHING**

Polyamide based (PA) technopolymer, black colour.

**PROTECTIVE SHIELD**

Polyamide-based (PA) technopolymer, grey colour.

**BEARINGS**

Chrome steel

**FEATURES AND APPLICATIONS**



Bearing supports for GVD motorised rollers are inserted into the ends of the tubes of the conveyor rollers (Fig.1). Drive sprocket with 14 teeth for roller chain type DIN 8187-08-B1. Recommended maximum load: 200 [N].

**SPECIAL EXECUTIONS ON REQUEST**

- Stainless steel bearing.
- Versions for tubes with an external diameter of 60 mm and an internal diameter of 54.5, 56, and 57 mm.



Fig.1

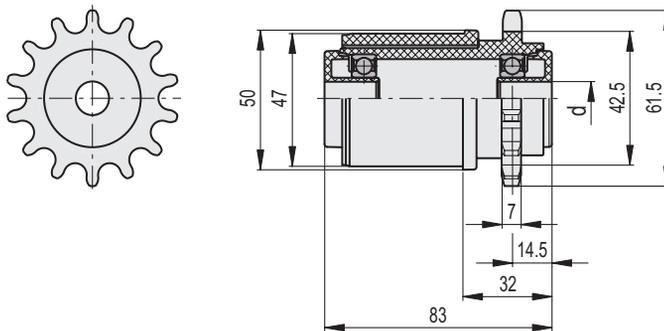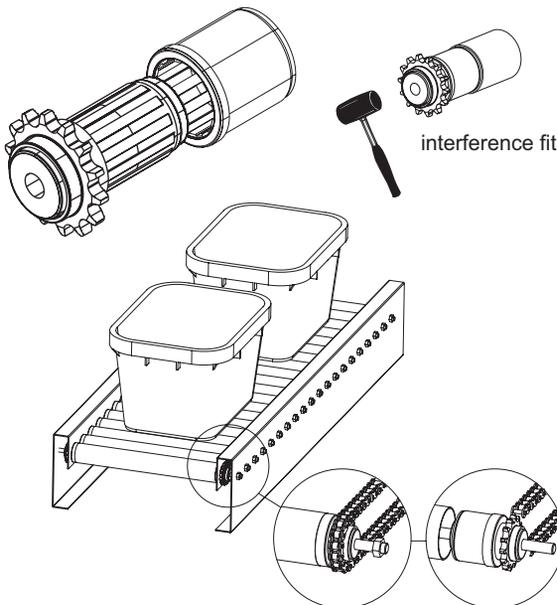

Code	Description	d	⚖
419911	GVD-50-12	12	145
419913	GVD-50-14	14	145