

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19

BODY AND EXTERNAL BUSHING

Polyamide based (PA) technopolymer, black colour.

PROTECTIVE SHIELD

Polyamide-based (PA) technopolymer, grey colour.

BEARINGS

Chrome steel

FEATURES AND APPLICATIONS

Bearing supports for GVF friction rollers are inserted into the ends of the tubes of the conveyor rollers (Fig.1). Drive sprocket with 14 teeth for roller chain type DIN 8187-08-B1.



Recommended maximum load: 200 [N].

SPECIAL EXECUTIONS ON REQUEST

- Stainless steel bearing.
- Versions for tubes with an external diameter of 60 mm and an internal diameter of 54.5, 56, and 57 mm.



Fig.1

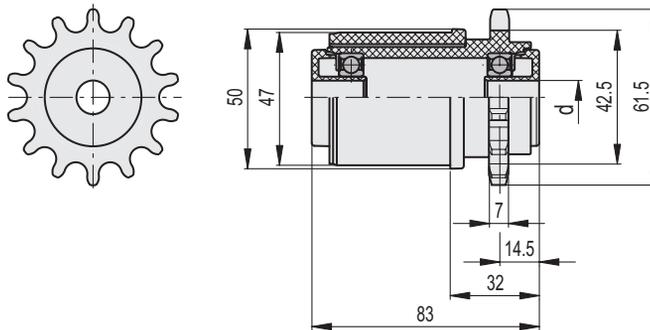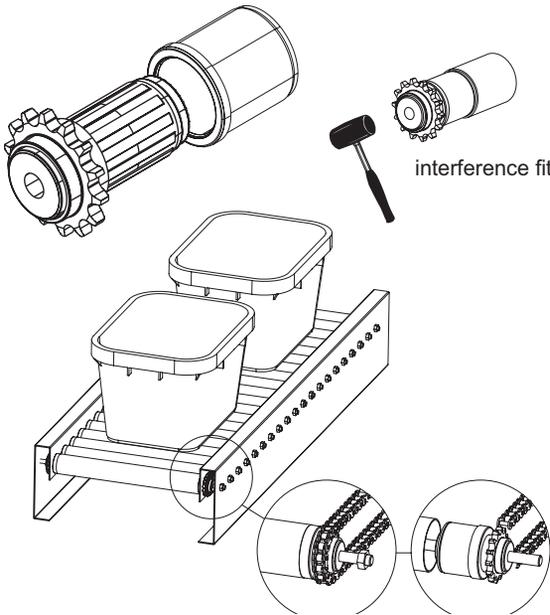

Code	Description	d	
419921	GVF-50-12	12	145
419923	GVF-50-14	14	145