

STANDARD EXECUTIONS

Base with a slotted pass-through hole and AISI 304 stainless steel threaded blind joint or AISI 303 stainless steel threaded stem with AISI 304 stainless steel nut:

- **LMD.F-SL-SST (d2)**: threaded blind ball joint, without no-slip disk.
- **LMD.F-SL-SST-TV (d2)**: threaded blind ball joint, with vulcanised rubber (NBR) with no-slip coating hardness 70 Shore A tolerance +/-5.
- **LMD.F-SL-SST (d2 - I)**: threaded stem, without no-slip disk.
- **LMD.F-SL-SST-TV (d2 - I)**: threaded stem, with vulcanised rubber (NBR) with no-slip coating hardness 70 Shore A tolerance +/-5.

Base with two slotted pass-through holes and AISI 304 stainless steel threaded blind joint or AISI 303 stainless steel threaded stem with AISI 304 stainless steel nut:

- **LMD.F-2SL-SST (d2)**: threaded blind ball joint, without no-slip disk.
- **LMD.F-2SL-SST-TV (d2)**: threaded blind ball joint, with vulcanised rubber (NBR) with no-slip coating hardness 70 Shore A tolerance +/-5.
- **LMD.F-2SL-SST (d2 - I)**: threaded stem, without no-slip disk.
- **LMD.F-2SL-SST-TV (d2 - I)**: threaded stem, with vulcanised rubber (NBR) with no-slip coating hardness 70 Shore A tolerance +/-5.

SET SCREW


Stainless steel.

FEATURES

The bases of the LMD.F-SST levelling feet are provided with one or two slotted pass-through holes to allow fixing to the mounting surface and correct adjustment, preventing lateral movement.



The versions with non-slip coating are particularly suitable for use on sensitive surfaces.

The levelling feet are supplied fully assembled, not removable.

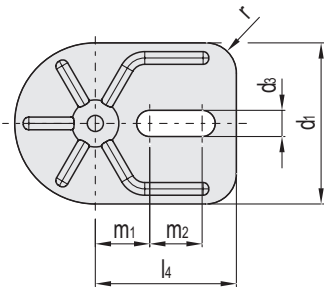

LMD.F-SL-SST

 LMD.F-SL-SST-TV

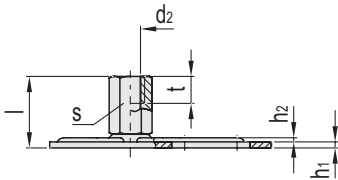


LMD.F-SL-SST (d2)

LMD.F-SL-SST-TV (d2)

| Code   | Description         | Code   | Description            | d1 | l  | l4 | d2  | d3 | h1 | h2  | h3# | m1 | m2 | s  | r  | t  | Max. limit static load* [N] | Δ   |
|--------|---------------------|--------|------------------------|----|----|----|-----|----|----|-----|-----|----|----|----|----|----|-----------------------------|-----|
| 409171 | LMD.F-SL-80-SST-M8  | 409172 | LMD.F-SL-80-SST-M8-TV  | 80 | 26 | 70 | M8  | 13 | 3  | 1.3 | 3   | 27 | 26 | 14 | 15 | 8  | 8000                        | 221 |
| 409181 | LMD.F-SL-80-SST-M10 | 409182 | LMD.F-SL-80-SST-M10-TV | 80 | 29 | 70 | M10 | 13 | 3  | 1.3 | 3   | 27 | 26 | 14 | 15 | 10 | 14000                       | 221 |
| 409193 | LMD.F-SL-80-SST-M12 | 409194 | LMD.F-SL-80-SST-M12-TV | 80 | 32 | 70 | M12 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | 15 | 12 | 20000                       | 232 |
| 409205 | LMD.F-SL-80-SST-M16 | 409206 | LMD.F-SL-80-SST-M16-TV | 80 | 38 | 70 | M16 | 13 | 3  | 1.3 | 3   | 27 | 26 | 22 | 15 | 16 | 20000                       | 248 |
| 409219 | LMD.F-SL-80-SST-M20 | 409220 | LMD.F-SL-80-SST-M20-TV | 80 | 45 | 70 | M20 | 13 | 3  | 1.3 | 3   | 27 | 26 | 27 | 15 | 20 | 20000                       | 314 |

# only for TV executions

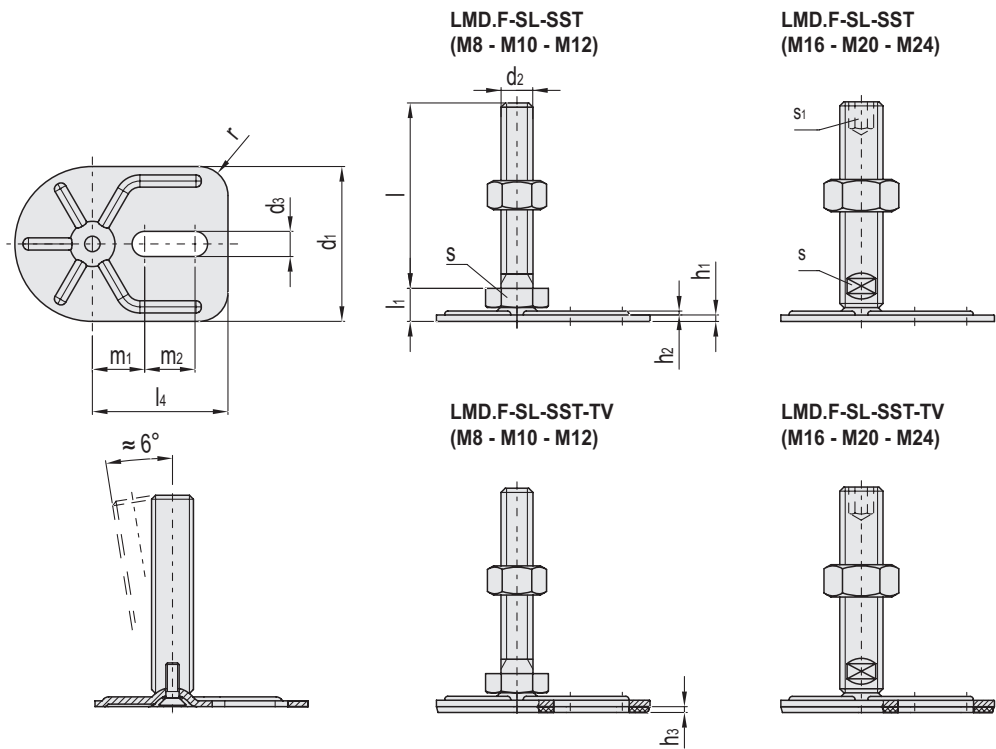



LMD.F-SL-SST (d2 - l)

LMD.F-SL-SST-TV (d2 - l)

INOX STAINLESS STEEL



| Code   | Description             | Code   | Description                | d1 | l   | l1 | l4 | d2  | d3 | h1 | h2  | h3# | m1 | m2 | s  | s1 | r  | Max. limit static load* [N] |     |
|--------|-------------------------|--------|----------------------------|----|-----|----|----|-----|----|----|-----|-----|----|----|----|----|----|-----------------------------|-----|
| 409173 | LMD.F-SL-80-SST-M8x40   | 409174 | LMD.F-SL-80-SST-M8x40-TV   | 80 | 40  | 12 | 70 | M8  | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 8000                        | 203 |
| 409175 | LMD.F-SL-80-SST-M8x50   | 409176 | LMD.F-SL-80-SST-M8x50-TV   | 80 | 50  | 12 | 70 | M8  | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 8000                        | 206 |
| 409177 | LMD.F-SL-80-SST-M8x63   | 409178 | LMD.F-SL-80-SST-M8x63-TV   | 80 | 63  | 12 | 70 | M8  | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 8000                        | 210 |
| 409183 | LMD.F-SL-80-SST-M10x50  | 409184 | LMD.F-SL-80-SST-M10x50-TV  | 80 | 50  | 12 | 70 | M10 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 14000                       | 241 |
| 409185 | LMD.F-SL-80-SST-M10x60  | 409186 | LMD.F-SL-80-SST-M10x60-TV  | 80 | 60  | 12 | 70 | M10 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 14000                       | 245 |
| 409187 | LMD.F-SL-80-SST-M10x80  | 409188 | LMD.F-SL-80-SST-M10x80-TV  | 80 | 80  | 12 | 70 | M10 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 14000                       | 255 |
| 409189 | LMD.F-SL-80-SST-M10x100 | 409190 | LMD.F-SL-80-SST-M10x100-TV | 80 | 100 | 12 | 70 | M10 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 14000                       | 266 |
| 409195 | LMD.F-SL-80-SST-M12x60  | 409196 | LMD.F-SL-80-SST-M12x60-TV  | 80 | 60  | 12 | 70 | M12 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 20000                       | 258 |
| 409197 | LMD.F-SL-80-SST-M12x80  | 409198 | LMD.F-SL-80-SST-M12x80-TV  | 80 | 80  | 12 | 70 | M12 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 20000                       | 272 |
| 409199 | LMD.F-SL-80-SST-M12x100 | 409200 | LMD.F-SL-80-SST-M12x100-TV | 80 | 100 | 12 | 70 | M12 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 20000                       | 287 |
| 409201 | LMD.F-SL-80-SST-M12x125 | 409202 | LMD.F-SL-80-SST-M12x125-TV | 80 | 125 | 12 | 70 | M12 | 13 | 3  | 1.3 | 3   | 27 | 26 | 17 | -  | 15 | 20000                       | 304 |
| 409207 | LMD.F-SL-80-SST-M16x75  | 409208 | LMD.F-SL-80-SST-M16x75-TV  | 80 | 75  | 18 | 70 | M16 | 13 | 3  | 1.3 | 3   | 27 | 26 | 12 | 8  | 15 | 20000                       | 313 |
| 409209 | LMD.F-SL-80-SST-M16x100 | 409210 | LMD.F-SL-80-SST-M16x100-TV | 80 | 100 | 18 | 70 | M16 | 13 | 3  | 1.3 | 3   | 27 | 26 | 12 | 8  | 15 | 20000                       | 345 |
| 409211 | LMD.F-SL-80-SST-M16x125 | 409212 | LMD.F-SL-80-SST-M16x125-TV | 80 | 125 | 18 | 70 | M16 | 13 | 3  | 1.3 | 3   | 27 | 26 | 12 | 8  | 15 | 20000                       | 378 |
| 409213 | LMD.F-SL-80-SST-M16x150 | 409214 | LMD.F-SL-80-SST-M16x150-TV | 80 | 150 | 18 | 70 | M16 | 13 | 3  | 1.3 | 3   | 27 | 26 | 12 | 8  | 15 | 20000                       | 410 |
| 409215 | LMD.F-SL-80-SST-M16x200 | 409216 | LMD.F-SL-80-SST-M16x200-TV | 80 | 200 | 18 | 70 | M16 | 13 | 3  | 1.3 | 3   | 27 | 26 | 12 | 8  | 15 | 20000                       | 476 |
| 409221 | LMD.F-SL-80-SST-M20x75  | 409222 | LMD.F-SL-80-SST-M20x75-TV  | 80 | 75  | 19 | 70 | M20 | 13 | 3  | 1.3 | 3   | 27 | 26 | 15 | 10 | 15 | 20000                       | 395 |
| 409223 | LMD.F-SL-80-SST-M20x100 | 409224 | LMD.F-SL-80-SST-M20x100-TV | 80 | 100 | 19 | 70 | M20 | 13 | 3  | 1.3 | 3   | 27 | 26 | 15 | 10 | 15 | 20000                       | 633 |
| 409225 | LMD.F-SL-80-SST-M20x125 | 409226 | LMD.F-SL-80-SST-M20x125-TV | 80 | 125 | 19 | 70 | M20 | 13 | 3  | 1.3 | 3   | 27 | 26 | 15 | 10 | 15 | 20000                       | 496 |
| 409227 | LMD.F-SL-80-SST-M20x150 | 409228 | LMD.F-SL-80-SST-M20x150-TV | 80 | 150 | 19 | 70 | M20 | 13 | 3  | 1.3 | 3   | 27 | 26 | 15 | 10 | 15 | 20000                       | 554 |
| 409229 | LMD.F-SL-80-SST-M20x200 | 409230 | LMD.F-SL-80-SST-M20x200-TV | 80 | 200 | 19 | 70 | M20 | 13 | 3  | 1.3 | 3   | 27 | 26 | 15 | 10 | 15 | 20000                       | 649 |
| 409233 | LMD.F-SL-80-SST-M24x100 | 409234 | LMD.F-SL-80-SST-M24x100-TV | 80 | 100 | 22 | 70 | M24 | 13 | 3  | 1.3 | 3   | 27 | 26 | 19 | 12 | 15 | 22000                       | 672 |
| 409235 | LMD.F-SL-80-SST-M24x125 | 409236 | LMD.F-SL-80-SST-M24x125-TV | 80 | 125 | 22 | 70 | M24 | 13 | 3  | 1.3 | 3   | 27 | 26 | 19 | 12 | 15 | 22000                       | 664 |
| 409237 | LMD.F-SL-80-SST-M24x150 | 409238 | LMD.F-SL-80-SST-M24x150-TV | 80 | 150 | 22 | 70 | M24 | 13 | 3  | 1.3 | 3   | 27 | 26 | 19 | 12 | 15 | 22000                       | 745 |
| 409239 | LMD.F-SL-80-SST-M24x200 | 409240 | LMD.F-SL-80-SST-M24x200-TV | 80 | 200 | 22 | 70 | M24 | 13 | 3  | 1.3 | 3   | 27 | 26 | 19 | 12 | 15 | 22000                       | 881 |

# only for TV executions

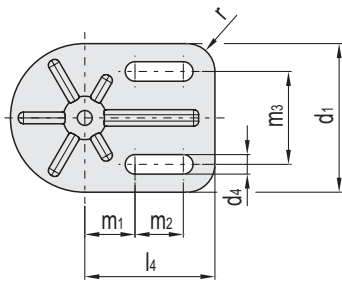 

LMD.F-2SL-SST

 LMD.F-2SL-SST-TV

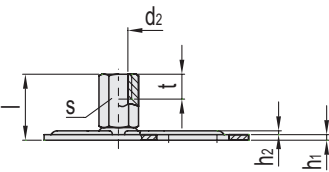

INOX STAINLESS STEEL




LMD.F-2SL-SST (d2)

LMD.F-2SL-SST-TV (d2)

| Code   | Description          | Code   | Description             | d1 | l  | l4 | d2  | d4   | h1 | h2  | h3# | m1 | m2 | m3 | s  | r  | t  | Max. limit static load* [N] | ⚖️  |
|--------|----------------------|--------|-------------------------|----|----|----|-----|------|----|-----|-----|----|----|----|----|----|----|-----------------------------|-----|
| 409315 | LMD.F-2SL-80-SST-M8  | 409316 | LMD.F-2SL-80-SST-M8-TV  | 80 | 26 | 70 | M8  | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 14 | 15 | 8  | 8000                        | 214 |
| 409325 | LMD.F-2SL-80-SST-M10 | 409326 | LMD.F-2SL-80-SST-M10-TV | 80 | 29 | 70 | M10 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 14 | 15 | 10 | 14000                       | 214 |
| 409337 | LMD.F-2SL-80-SST-M12 | 409338 | LMD.F-2SL-80-SST-M12-TV | 80 | 32 | 70 | M12 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | 15 | 12 | 20000                       | 227 |
| 409349 | LMD.F-2SL-80-SST-M16 | 409350 | LMD.F-2SL-80-SST-M16-TV | 80 | 38 | 70 | M16 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 22 | 15 | 16 | 20000                       | 243 |
| 409363 | LMD.F-2SL-80-SST-M20 | 409364 | LMD.F-2SL-80-SST-M20-TV | 80 | 45 | 70 | M20 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 27 | 15 | 20 | 20000                       | 308 |




LMD.F-2SL-SST (M8 - M10 - M12)

LMD.F-2SL-SST (M16 - M20 - M24)

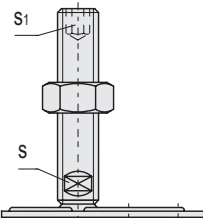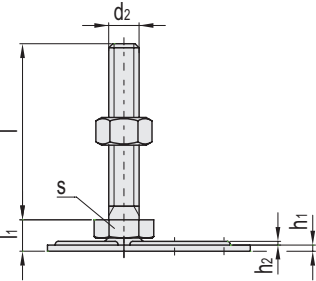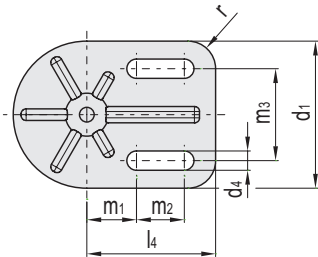

LMD.F-2SL-SST-TV (M8 - M10 - M12)

LMD.F-2SL-SST-TV (M16 - M20 - M24)

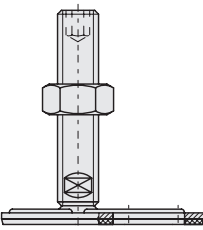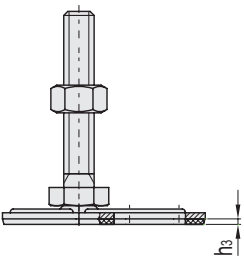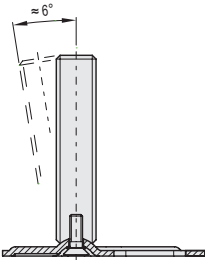


INOX STAINLESS STEEL

LMD.F-2SL-SST (d2 - l)

LMD.F-2SL-SST-TV (d2 - l)

| Code   | Description              | Code   | Description                 | d1 | l   | l1 | l4 | d2  | d4   | h1 | h2  | h3# | m1 | m2 | m3 | s  | s1 | r  | Max. limit static load* [N] | ⚖️  |
|--------|--------------------------|--------|-----------------------------|----|-----|----|----|-----|------|----|-----|-----|----|----|----|----|----|----|-----------------------------|-----|
| 409317 | LMD.F-2SL-80-SST-M8x40   | 409318 | LMD.F-2SL-80-SST-M8x40-TV   | 80 | 40  | 12 | 70 | M8  | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 8000                        | 193 |
| 409319 | LMD.F-2SL-80-SST-M8x50   | 409320 | LMD.F-2SL-80-SST-M8x50-TV   | 80 | 50  | 12 | 70 | M8  | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 8000                        | 196 |
| 409321 | LMD.F-2SL-80-SST-M8x63   | 409322 | LMD.F-2SL-80-SST-M8x63-TV   | 80 | 63  | 12 | 70 | M8  | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 8000                        | 200 |
| 409327 | LMD.F-2SL-80-SST-M10x50  | 409328 | LMD.F-2SL-80-SST-M10x50-TV  | 80 | 50  | 12 | 70 | M10 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 14000                       | 234 |
| 409329 | LMD.F-2SL-80-SST-M10x60  | 409330 | LMD.F-2SL-80-SST-M10x60-TV  | 80 | 60  | 12 | 70 | M10 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 14000                       | 238 |
| 409331 | LMD.F-2SL-80-SST-M10x80  | 409332 | LMD.F-2SL-80-SST-M10x80-TV  | 80 | 80  | 12 | 70 | M10 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 14000                       | 248 |
| 409333 | LMD.F-2SL-80-SST-M10x100 | 409334 | LMD.F-2SL-80-SST-M10x100-TV | 80 | 100 | 12 | 70 | M10 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 14000                       | 259 |
| 409339 | LMD.F-2SL-80-SST-M12x60  | 409340 | LMD.F-2SL-80-SST-M12x60-TV  | 80 | 60  | 12 | 70 | M12 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 20000                       | 253 |
| 409341 | LMD.F-2SL-80-SST-M12x80  | 409342 | LMD.F-2SL-80-SST-M12x80-TV  | 80 | 80  | 12 | 70 | M12 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 20000                       | 267 |
| 409343 | LMD.F-2SL-80-SST-M12x100 | 409344 | LMD.F-2SL-80-SST-M12x100-TV | 80 | 100 | 12 | 70 | M12 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 20000                       | 282 |
| 409345 | LMD.F-2SL-80-SST-M12x125 | 409346 | LMD.F-2SL-80-SST-M12x125-TV | 80 | 125 | 12 | 70 | M12 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 17 | -  | 15 | 20000                       | 299 |

Levelling feet and supports

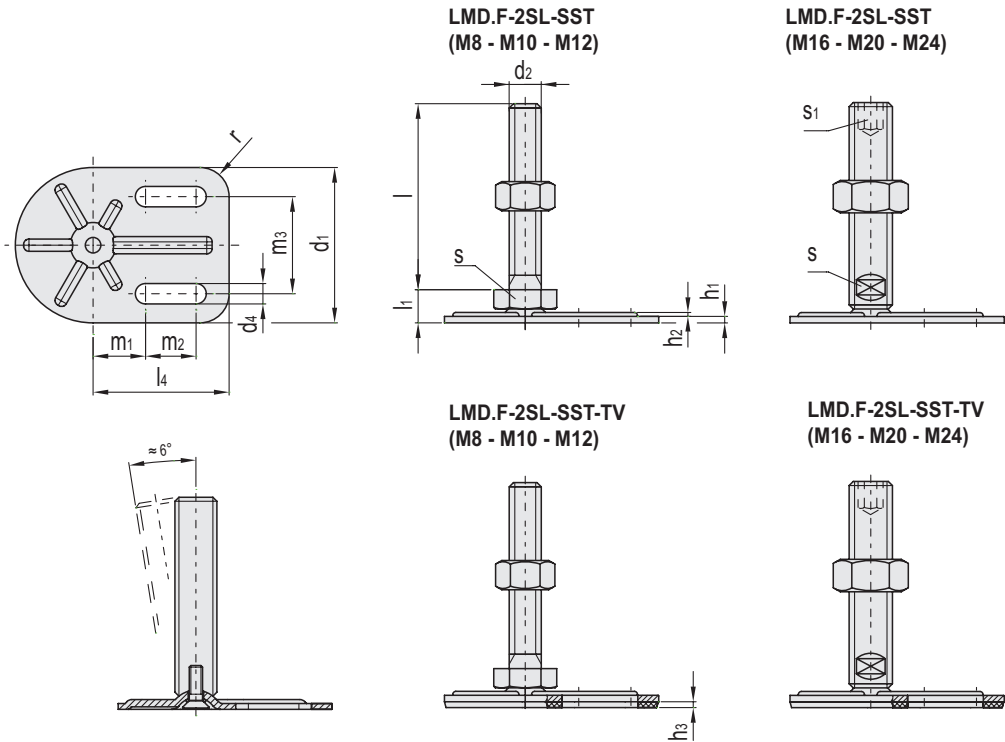

LMD.F-2SL-SST (d2 - l)

LMD.F-2SL-SST-TV (d2 - l)



| Code   | Description              | Code   | Description                 | d1 | l   | l1 | l4 | d2  | d4   | h1 | h2  | h3# | m1 | m2 | m3 | s  | s1 | r  | Max. limit static load* [N] |     |
|--------|--------------------------|--------|-----------------------------|----|-----|----|----|-----|------|----|-----|-----|----|----|----|----|----|----|-----------------------------|-----|
| 409351 | LMD.F-2SL-80-SST-M16x75  | 409352 | LMD.F-2SL-80-SST-M16x75-TV  | 80 | 75  | 18 | 70 | M16 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 12 | 8  | 15 | 20000                       | 308 |
| 409353 | LMD.F-2SL-80-SST-M16x100 | 409354 | LMD.F-2SL-80-SST-M16x100-TV | 80 | 100 | 18 | 70 | M16 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 12 | 8  | 15 | 20000                       | 340 |
| 409355 | LMD.F-2SL-80-SST-M16x125 | 409356 | LMD.F-2SL-80-SST-M16x125-TV | 80 | 125 | 18 | 70 | M16 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 12 | 8  | 15 | 20000                       | 373 |
| 409357 | LMD.F-2SL-80-SST-M16x150 | 409358 | LMD.F-2SL-80-SST-M16x150-TV | 80 | 150 | 18 | 70 | M16 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 12 | 8  | 15 | 20000                       | 405 |
| 409359 | LMD.F-2SL-80-SST-M16x200 | 409360 | LMD.F-2SL-80-SST-M16x200-TV | 80 | 200 | 18 | 70 | M16 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 12 | 8  | 15 | 20000                       | 471 |
| 409365 | LMD.F-2SL-80-SST-M20x75  | 409366 | LMD.F-2SL-80-SST-M20x75-TV  | 80 | 75  | 19 | 70 | M20 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 15 | 10 | 15 | 20000                       | 389 |
| 409367 | LMD.F-2SL-80-SST-M20x100 | 409368 | LMD.F-2SL-80-SST-M20x100-TV | 80 | 100 | 19 | 70 | M20 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 15 | 10 | 15 | 20000                       | 627 |
| 409369 | LMD.F-2SL-80-SST-M20x125 | 409370 | LMD.F-2SL-80-SST-M20x125-TV | 80 | 125 | 19 | 70 | M20 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 15 | 10 | 15 | 20000                       | 490 |
| 409371 | LMD.F-2SL-80-SST-M20x150 | 409372 | LMD.F-2SL-80-SST-M20x150-TV | 80 | 150 | 19 | 70 | M20 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 15 | 10 | 15 | 20000                       | 548 |
| 409373 | LMD.F-2SL-80-SST-M20x200 | 409374 | LMD.F-2SL-80-SST-M20x200-TV | 80 | 200 | 19 | 70 | M20 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 15 | 10 | 15 | 20000                       | 643 |
| 409377 | LMD.F-2SL-80-SST-M24x100 | 409378 | LMD.F-2SL-80-SST-M24x100-TV | 80 | 100 | 22 | 70 | M24 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 19 | 12 | 15 | 22000                       | 666 |
| 409379 | LMD.F-2SL-80-SST-M24x125 | 409380 | LMD.F-2SL-80-SST-M24x125-TV | 80 | 125 | 22 | 70 | M24 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 19 | 12 | 15 | 22000                       | 658 |
| 409381 | LMD.F-2SL-80-SST-M24x150 | 409382 | LMD.F-2SL-80-SST-M24x150-TV | 80 | 150 | 22 | 70 | M24 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 19 | 12 | 15 | 22000                       | 739 |
| 409383 | LMD.F-2SL-80-SST-M24x200 | 409384 | LMD.F-2SL-80-SST-M24x200-TV | 80 | 200 | 22 | 70 | M24 | 10.5 | 3  | 1.3 | 3   | 27 | 26 | 50 | 19 | 12 | 15 | 22000                       | 875 |

# only for TV executions

