

MATERIAL

AISI 304 stainless steel.

RIVETS

AISI 304 stainless steel.

PUSH LEVER

AISI 304 stainless steel.

GUIDE BUSHINGS

AISI 303 stainless steel.

NUT

AISI 304 stainless steel.

HANDLE

Polyurethane, red colour.

ANTI RELEASE LEVER

AISI 304 stainless steel.

LEVER ANTI-RELEASE COVERING

Polyurethane, red colour.

SPRING

AISI 302 stainless steel.

CLAMPING BOLT


to be ordered separately

FEATURES AND APPLICATIONS

Anti-release lever to prevent accidental opening in the presence of strong vibrations.

All articulated joints are lubricated with special grease.

MFB-SST clamps ensure only perfect push clamping.

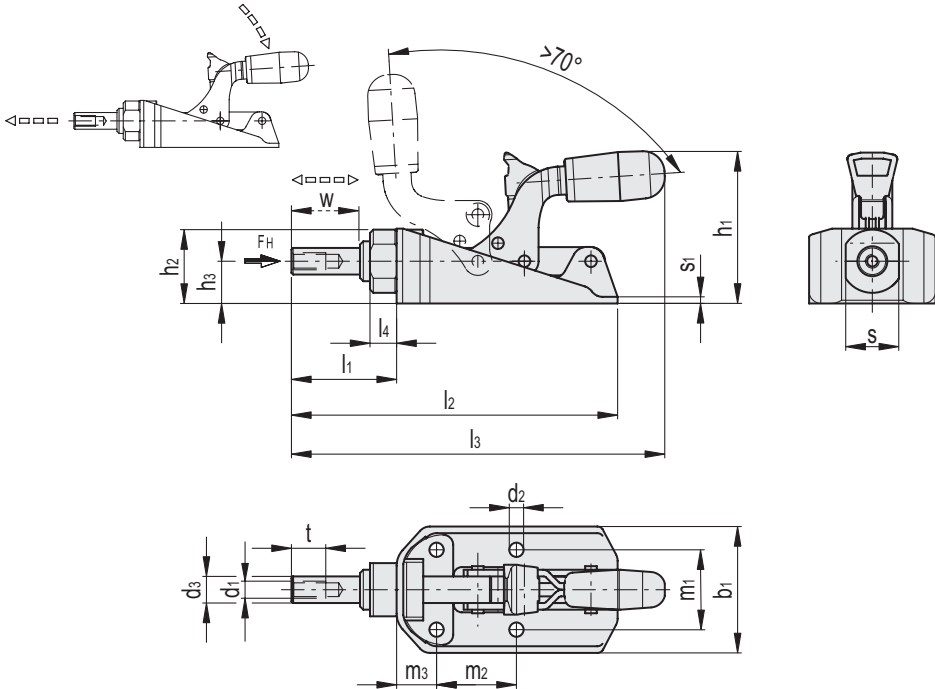

Code	Description	b1	d1	d2	d3	h1	h2	h3	l1	l2	l3	l4	m1	m2	m3	s	s1	t	w Stroke	FH* [N]	
GG.AS389	MFB-S.85-ASLX	38	M5	4.3	8	46	22.5	12.7	31.5	98	112	8	24	24	12	16	2	10	15	4000	146
GG.AS391	MFB-S.125-ASLX	48	M6	5.5	12	62	30	17	41	126	165	10	30	34	18	22	2.5	12	19	5200	352
GG.AS393	MFB-S.305-ASLX	58	M8	6.5	14	74	36	20	53	158	197	12	34	50	18	24	3	16	25	6750	620

* Holding force.