

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

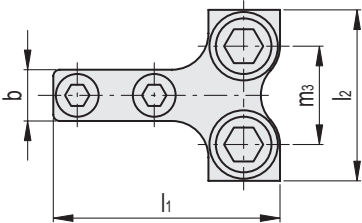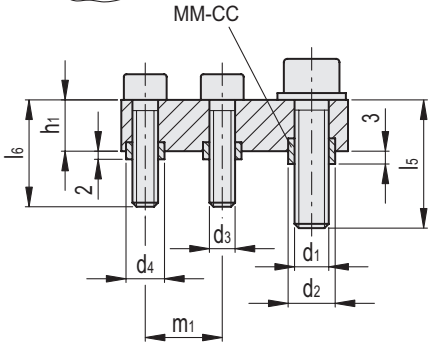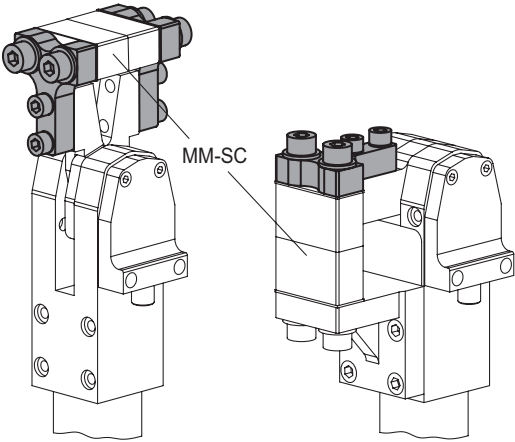

Code	Description	b	d1	d2 H8 / h6	d3	d4 H8 / h6	h1	l1	l2	l5	l6	m1	m3	ΔΔ
MM.21020-NK	MM-A-SC-20-NK	10	M6	9	M5	7	10	37	30	20	20	12	17	30
MM.21032-NK	MM-A-SC-32-NK	12	M8	11	M6	9	12	53	40	25	25	18	23	138
MM.21040-NK	MM-A-SC-40-NK	16	M10	13	M8	11	14	63	50	30	35	22	30	248
MM.21050-NK	MM-A-SC-50-NK	18	M10	13	M10	13	16	73	60	40	30	27	40	335