

MATERIAL

Nickel-plated steel bracket.  
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




I-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Jaw blocks MM-SC (see page -).

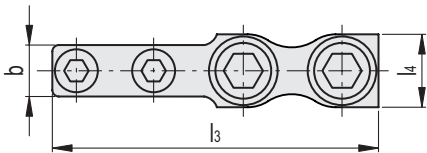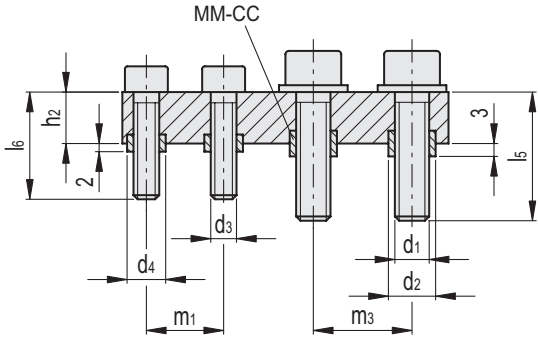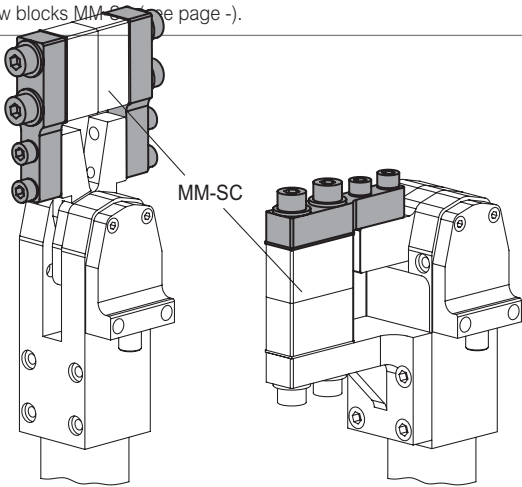

| Code        | Description    | b  | d1  | d2 H8 / h6 | d3  | d4 H8 / h6 | h2 | l3  | l4 | l5 | l6 | m1 | m3 | △   |
|-------------|----------------|----|-----|------------|-----|------------|----|-----|----|----|----|----|----|-----|
| MM.35020-NK | MM-A-SCL-20-NK | 10 | M6  | 9          | M5  | 7          | 10 | 54  | 13 | 20 | 20 | 12 | 17 | 62  |
| MM.35032-NK | MM-A-SCL-32-NK | 12 | M8  | 11         | M6  | 9          | 14 | 76  | 17 | 25 | 25 | 18 | 23 | 142 |
| MM.35040-NK | MM-A-SCL-40-NK | 16 | M10 | 13         | M8  | 11         | 16 | 93  | 20 | 30 | 35 | 22 | 30 | 273 |
| MM.35050-NK | MM-A-SCL-50-NK | 18 | M10 | 13         | M10 | 13         | 18 | 113 | 20 | 40 | 30 | 27 | 40 | 379 |