

MATERIAL

Nickel-plated steel bracket.
Screws and centering bushings MM-CC (see page -) in black-oxide steel.

FEATURES




The brackets are compatible with the pneumatic fastening clamps MM-BI-NK (see page -).

SPECIAL EXECUTIONS ON REQUEST

Y-shaped brackets are compatible with pneumatic fastening clamps MM-BL-NK (see page -), MM-BI-NK (see page -) or MM-BC-NK (see page -).

ACCESSORIES ON REQUEST

Clamping screws with ball terminal MM-RG (see page -).

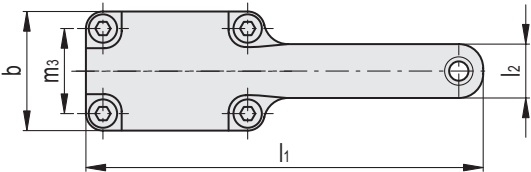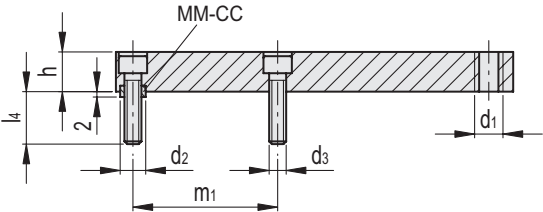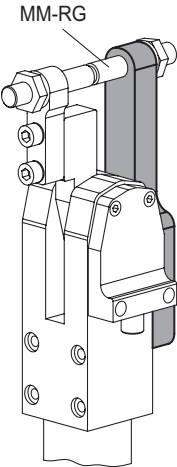

Code	Description	b	d1	d2 H8 / h6	d3	h	l1	l2	l4	m1	m3	△
MM.41020-NK	MM-FI-RG1-20-NK	32	M8	7	M5	10	98.5	15	8	34	22	166
MM.41032-NK	MM-FI-RG1-32-NK	42	M10	9	M6	14	140	19	8.5	51	30	436
MM.41040-NK	MM-FI-RG1-40-NK	52	M12	11	M8	16	168	22	12.5	62	37	732
MM.41050-NK	MM-FI-RG1-50-NK	62	M12	13	M10	18	192.5	26	12.5	71.5	44	898