



HANDLE SHANKS

Glass-fibre reinforced polyamide based (PA) technopolymer, RAL 9005 black colour, semi-matte finish.
Pass-through holes for cylindrical-head screws with hexagon socket.

STANDARD EXECUTIONS



- **RHRS-62:** aluminium tube, ground surfaces, anodised in natural colour, matte finish.
Black zinc-plated screws, zinc-plated nuts and washers, included in the supply.
- **RHRS-37:** AISI 304 stainless steel tube, ground surfaces.
AISI 304 stainless steel screws, nuts and washers, included in the supply.
- **RHRS-47:** AISI 316L stainless steel tube, ground surfaces.
AISI 316L stainless steel screws, nuts and washers, included in the supply.

FEATURES

RH-RS series tubular handles are provided with a special anti-rotation system.

SPECIAL EXECUTIONS ON REQUEST

- Different lengths.
- Plastic-coated aluminium tube, black colour, grooved finish.
- Executions with central shanks (for Ø 30 mm tube only), screw with hexagonal head, black zinc-plated nuts and washers, included in the supply.

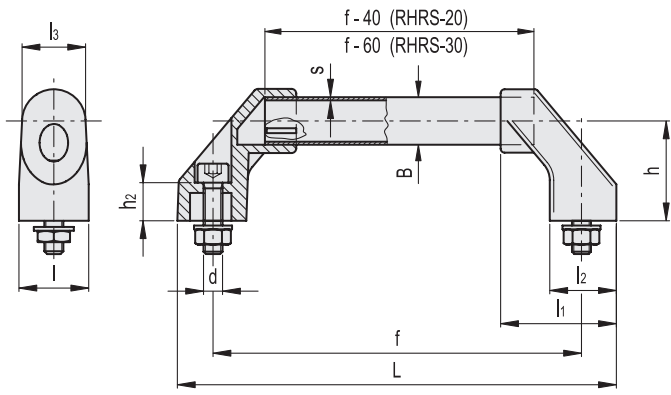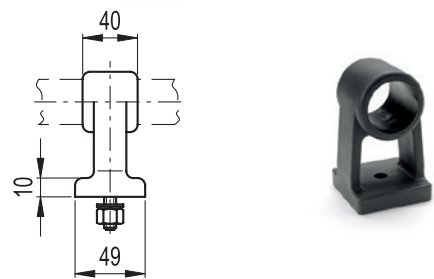

RHRS-62

Code	f	L	d	h2	B	s	h	l	l1	l2	l3	⚖
RHRS-20.200.62	200	230	M8x30	16	20	2	42	30	50	28	27	169
RHRS-20.250.62	250	280	M8x30	16	20	2	42	30	50	28	27	184
RHRS-20.300.62	300	330	M8x30	16	20	2	42	30	50	28	27	198
RHRS-20.400.62	400	430	M8x30	16	20	2	42	30	50	28	27	227
RHRS-20.500.62	500	530	M8x30	16	20	2	42	30	50	28	27	257
RHRS-30.250.62	250	294	M10x45	25	30	1.5	60	44	73	42	40	397
RHRS-30.300.62	300	344	M10x45	25	30	1.5	60	44	73	42	40	410
RHRS-30.350.62	350	394	M10x45	25	30	1.5	60	44	73	42	40	428
RHRS-30.400.62	400	444	M10x45	25	30	1.5	60	44	73	42	40	453
RHRS-30.500.62	500	544	M10x45	25	30	1.5	60	44	73	42	40	493
RHRS-30.600.62	600	644	M10x45	25	30	1.5	60	44	73	42	40	533

RHRS-37

Code
-
-
-
-
-
RHRS-30.250.37
RHRS-30.300.37
RHRS-30.350.37
RHRS-30.400.37
RHRS-30.500.37
RHRS-30.600.37

RHRS-47

Code
-
-
-
-
-
RHRS-30.250.47
RHRS-30.300.47
RHRS-30.350.47
RHRS-30.400.47
RHRS-30.500.47
RHRS-30.600.47