

HANDLE SHANKS


AISI 316L stainless steel, with ground, shot-blasted and electrolytically polished semi-matte surfaces.

BAR

Round-section AISI 316L stainless steel, with ground, shot-blasted and electrolytically polished semi-matte surfaces.

SPECIAL EXECUTIONS ON REQUEST

Handles with different lengths.

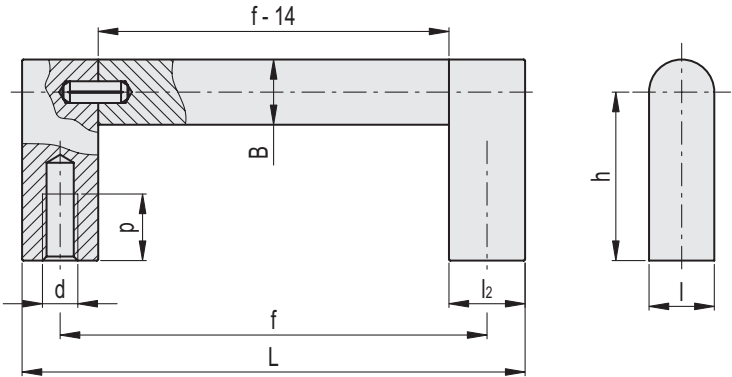

Code	f	L	d	p	B	h	l	l2	⚖
RHUG-08.100.36	100	114	M6	12	12	31	12	14	163
RHUG-08.120.36	120	134	M6	12	12	31	12	14	180
RHUG-08.140.36	140	154	M6	12	12	31	12	14	199
RHUG-08.160.36	160	174	M6	12	12	31	12	14	217
RHUG-08.180.36	180	194	M6	12	12	31	12	14	235