



STANDARD EXECUTIONS


- **TLAS.Z:** lever body and bracket in zinc-plated steel with spring.
- **TLAS.NH:** lever body and bracket in nickel-plated steel, RAL 3000 red technopolymer push button.
- **TLAS.SST-16.4:** lever body and bracket in AISI 304 stainless steel with spring.
- **TLAS.SST-30:** lever body and bracket in AISI 304 stainless steel, RAL 3000 red technopolymer push button.

SPECIAL EXECUTIONS ON REQUEST


- Hook clamps in unplated steel.
- Catch brackets in different shapes and finishes.



TLAS.NH-30/193.5+R
TLAS.SST-30/193.5+R

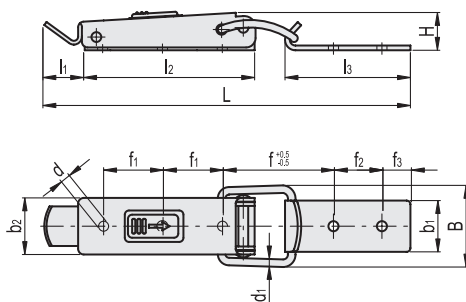

TLAS.Z-16.4/102+R
TLAS.SST-16.4/102+R

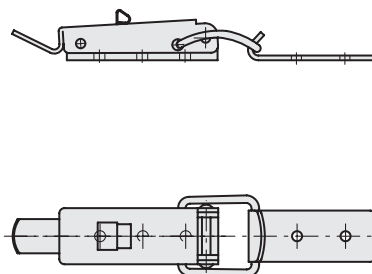

TLAS.Z

Code	Description	b2	L	B	H	d	d1	b1	l1	l2	l3	f	f1	f2	f3	Max. working load [N]	Load at breakage [N]	
420083	TLAS.Z-16.4/102+R	16.4	102	23	11	3.2	2	13	16	44	30	34.5	12.5	12	5	550	1200	32

TLAS.NH

420055	TLAS.NH-30/193.5+R	30	193.5	43	19	5.3	4	27	21.5	90	66	58.5	31.5	25.5	15	2000	4000	189
--------	--------------------	----	-------	----	----	-----	---	----	------	----	----	------	------	------	----	------	------	-----

TLAS.SST-16.4

Code	Description	b2	L	B	H	d	d1	b1	l1	l2	l3	f	f1	f2	f3	Max. working load [N]	Load at breakage [N]	
420084	TLAS.SST-16.4/102+R	16.4	102	23	11	3.2	2	13	16	44	30	34.5	12.5	12	5	550	1200	32

TLAS.SST-30

420056	TLAS.SST-30/193.5+R	30	193.5	43	19	5.3	4	27	21.5	90	66	58.5	31.5	25.5	15	2000	4000	189
--------	---------------------	----	-------	----	----	-----	---	----	------	----	----	------	------	------	----	------	------	-----