

MATERIAL



Polyamide based (PA) technopolymer, in 4 standard colours: black, orange, grey, red, matte finish.

STANDARD EXECUTION

Blind holes for fitting by means of no. 2 self-tapping screws for plastic materials Ø3.5 (UNI ISO 7049), not included in the supply.
Maximum tightening torque of the self-tapping screws 1,2 [Nm].

TECHNICAL DATA

Tensile stress and impact strength: the values F2 and L1 indicated in the table were obtained during breaking tests carried out with the appropriate dynamometric equipment under the test conditions shown in the figure with ambient temperature.

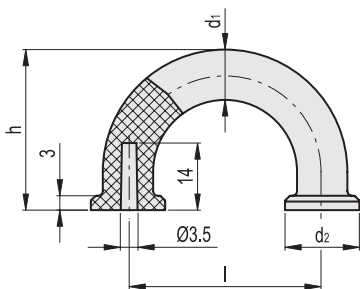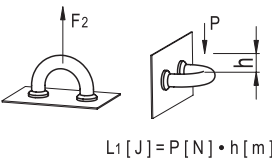

* Complete with colour index, example: 138201-C2 MFH-30-AF 3.5-C2

 C9	 C2	 C3	 C6
RAL9005	RAL2004	RAL7035	RAL3000

Code	Description	l	d1	d2	h	F2 [N]	L1 [J]	
138201-*	MFH-30-AF 3,5-*	29.5	9	12	27	2300	6	6
138221-*	MFH-40-AF 3,5-*	39.5	10	15	33.5	2300	10	9