




















- 1 
- 2 
- 3 
- 4 
- 5 
- 6 
- 7 
- 8 
- 9 
- 10 
- 11 
- 12 
- 13 
- 14 
- 15 
- 16 
- 17 
- 18** 
- 19 

MATERIAL


AISI 304 stainless steel.

STANDARD EXECUTION

Cylindrical-head screw with hexagon socket with anti-seizure treatment and self-locking nut.



ELESA Original design

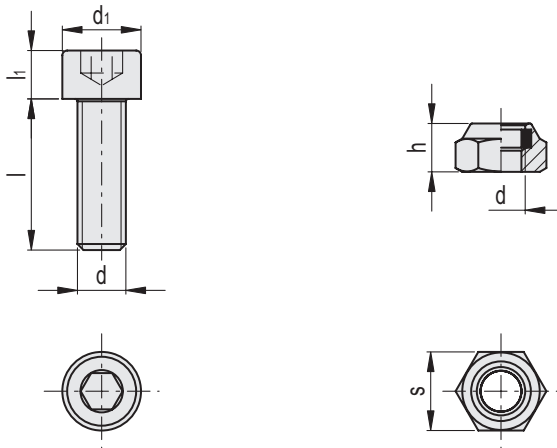

Code	Description	d	d1	h	l	l1	s	⚖
600706	TCC-KV-M6	M6	10	6	18	6	10	8
600708	TCC-KV-M8	M8	13	8	25	8	13	19