



EXÉCUTION STANDARD


Poignée I.622 en technopolymère, couleur noire, finition brillante, fixée au bras en acier zingué brillant, non amovible.

EXÉCUTIONS SPÉCIALES SUR DEMANDE

Poignée en différentes couleurs RAL.



ELESA Original design

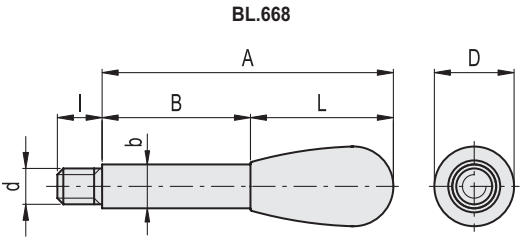

BL.668

| Code | Description   | A   | D  | L  | d6g | B   | b  | l  | △△  |
|------|---------------|-----|----|----|-----|-----|----|----|-----|
| 5011 | BL.668/10x57  | 57  | 20 | 32 | M8  | 25  | 10 | 9  | 31  |
| 5012 | BL.668/10x67  | 67  | 20 | 32 | M8  | 35  | 10 | 9  | 37  |
| 5013 | BL.668/10x77  | 77  | 20 | 32 | M8  | 45  | 10 | 9  | 43  |
| 5015 | BL.668/10x107 | 107 | 20 | 32 | M8  | 75  | 10 | 9  | 62  |
| 5016 | BL.668/10x137 | 137 | 20 | 32 | M8  | 105 | 10 | 11 | 81  |
| 5021 | BL.668/12x79  | 79  | 26 | 42 | M10 | 37  | 12 | 14 | 65  |
| 5022 | BL.668/12x95  | 95  | 26 | 42 | M10 | 53  | 12 | 14 | 79  |
| 5023 | BL.668/12x142 | 142 | 26 | 42 | M10 | 100 | 12 | 14 | 122 |
| 5024 | BL.668/12x180 | 180 | 26 | 42 | M10 | 138 | 12 | 14 | 154 |
| 5031 | BL.668/14x100 | 100 | 33 | 55 | M12 | 45  | 14 | 15 | 120 |
| 5032 | BL.668/14x135 | 135 | 33 | 55 | M12 | 80  | 14 | 15 | 156 |
| 5033 | BL.668/14x175 | 175 | 33 | 55 | M12 | 120 | 14 | 15 | 216 |
| 5041 | BL.668/16x70  | 70  | 33 | 55 | M14 | 15  | 16 | 15 | 96  |
| 5042 | BL.668/16x108 | 108 | 33 | 55 | M14 | 53  | 16 | 15 | 154 |
| 5043 | BL.668/16x129 | 129 | 33 | 55 | M14 | 74  | 16 | 15 | 186 |
| 5044 | BL.668/16x155 | 155 | 33 | 55 | M14 | 100 | 16 | 15 | 228 |

Poignées de manoeuvre