

MATERIALE

Barra a sezione tonda.


GN 224.1: acciaio cromato.

GN 224.5: acciaio INOX AISI 304, finitura spazzolata mat.

RONDELLE DI APPOGGIO

GN 224.1: lega di zinco nichelata.

GN 224.5: acciaio INOX AISI 303.

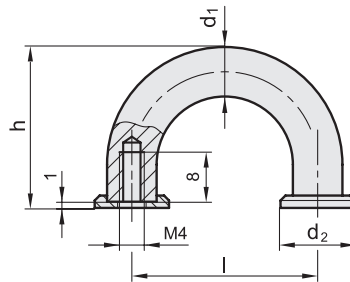

GN 224.1

Codice	Descrizione	d1	l	d2	h	⚖
GN.10381	GN 224.1-8-30-CR	8	30±0.25	12	26	20
GN.10382	GN 224.1-10-40-CR	10	40±0.25	15	31	40

GN 224.5

Codice	Descrizione	d1	l	d2	h	⚖
GN.10385	GN 224.5-8-30	8	30±0.25	12	26	20
GN.10386	GN 224.5-10-40	10	40±0.25	15	31	40