

MATERIALE

Acciaio INOX, finitura mat da sabbiatura.

ESECUZIONE STANDARD


Mozzo, foro cieco filettato.

ESECUZIONI SPECIALI A RICHIESTA

- Foro passante filettato.
- Foro cieco alesato H7.
- Finitura lucida.



ELESA Original design

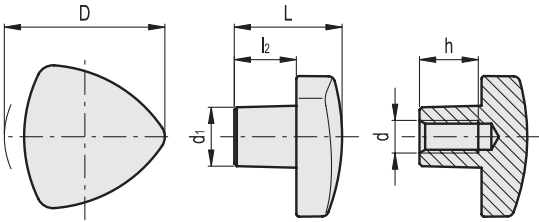

Codice	Descrizione	D	d	L	d1	l2	h	⚖
85002	VTRM-SST-32-M5	32	M5	21	12	12	10	60
85003	VTRM-SST-32-M6	32	M6	21	12	12	12	58
85012	VTRM-SST-40-M6	40	M6	26	14	14	12	94
85013	VTRM-SST-40-M8	40	M8	26	14	14	15	92
85022	VTRM-SST-50-M8	50	M8	33	18	19	15	155
85023	VTRM-SST-50-M10	50	M10	33	18	19	18	150
85032	VTRM-SST-60-M10	60	M10	41	20	23	18	245
85033	VTRM-SST-60-M12	60	M12	41	20	23	22	235