


MATERIAL

Stång med runt tvärsnitt.
GN 224.1: förkromat stål.
GN 224.5: AISI 304 rostfritt stål, borstad matt yta.

BRICKOR

GN 224.1: förnicklad zinklegering.
GN 224.5: AISI 304 rostfritt stål.

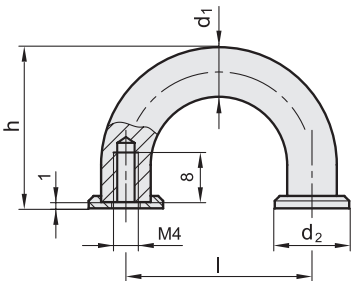

GN 224.1

Kod	Benämning	d1	l	d2	h	△△
GN.10381	GN 224.1-8-30-CR	8	30±0.25	12	26	20
GN.10382	GN 224.1-10-40-CR	10	40±0.25	15	31	40

GN 224.5

Kod	Benämning	d1	l	d2	h	△△
GN.10385	GN 224.5-8-30	8	30±0.25	12	26	20
GN.10386	GN 224.5-10-40	10	40±0.25	15	31	40

