



MATERIAL



Aluminium.

Ytbehandlings index:

- **BL**: naturlig färg.
- **SW**: epoxybeläggning mot UV-strålar, RAL 9005 svart färg.

KÄNNETECKEN OCH ANVÄNDNING

GN 271 fästen kan monteras med svängbar rörkoppling GN 273 (se sidan 1343), GN 275 (se sidan 1346) eller GN 277 (se sidan 1347).

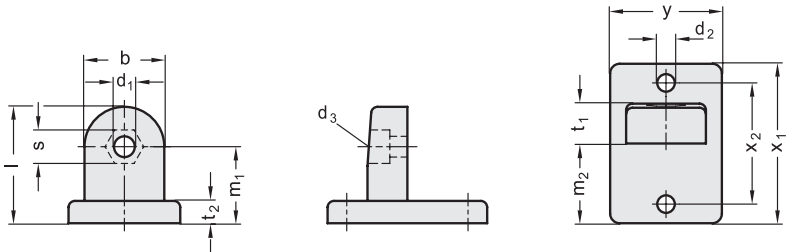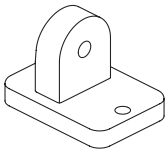

Kod	Benämning	b	d1	d2	d3	l	m1	m2	t1	t2	s	x1	x2	y	△
GN.56906	GN 271-25-SW	25	6.5	5.5	M6	36.5	24	25	12.5	7	10	50	38	35	44
GN.56901	GN 271-25-BL	25	6.5	5.5	M6	36.5	24	25	12.5	7	10	50	38	35	44