


STANDARDUTFÖRANDE

Aluminium med epoxybeläggning

- Svart, RAL 9005, strukturerad yta **SW**
- Grå, RAL 9006, matt yta **SR**
- Naturlig färg **BL**

KÄNNETECKEN OCH ANVÄNDNING

The GN 426.4 bygelhandtag för skåp är tillverkade av en böjd aluminiumprofil.

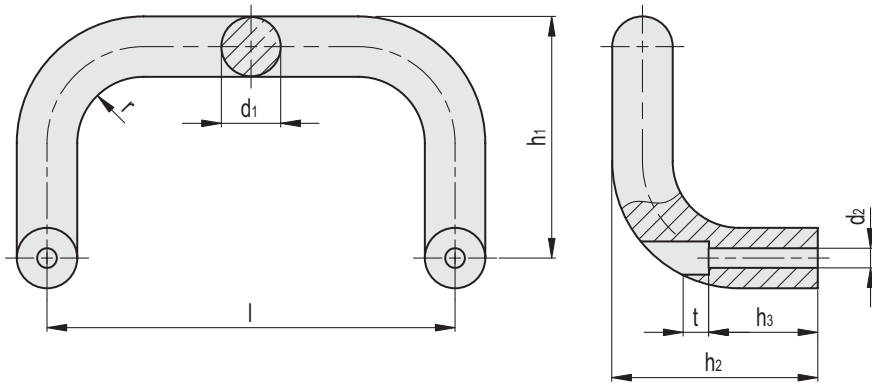

Kod	Benämning	d1	l	d2	h1	h2	h3	r	t	△
GN.81055	GN 426.4-AL-20-200-SW	20	200	6.5	105	68	36	22	9	368
GN.81053	GN 426.4-AL-20-200-SR	20	200	6.5	105	68	36	22	9	368
GN.81051	GN 426.4-AL-20-200-BL	20	200	6.5	105	68	36	22	9	368
GN.81061	GN 426.4-AL-20-300-SW	20	300	6.5	105	68	36	22	9	467
GN.81059	GN 426.4-AL-20-300-SR	20	300	6.5	105	68	36	22	9	467
GN.81057	GN 426.4-AL-20-300-BL	20	300	6.5	105	68	36	22	9	467
GN.81075	GN 426.4-AL-28-250-SW	28	250	9	125	78	34	32	11	834
GN.81073	GN 426.4-AL-28-250-SR	28	250	9	125	78	34	32	11	834
GN.81071	GN 426.4-AL-28-250-BL	28	250	9	125	78	34	32	11	834
GN.81081	GN 426.4-AL-28-350-SW	28	350	9	125	78	34	32	11	1030
GN.81079	GN 426.4-AL-28-350-SR	28	350	9	125	78	34	32	11	1030
GN.81077	GN 426.4-AL-28-350-BL	28	350	9	125	78	34	32	11	1030
GN.81087	GN 426.4-AL-28-500-SW	28	500	9	125	78	34	32	11	1280
GN.81085	GN 426.4-AL-28-500-SR	28	500	9	125	78	34	32	11	1280
GN.81083	GN 426.4-AL-28-500-BL	28	500	9	125	78	34	32	11	1280