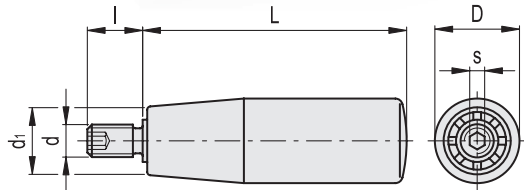


**MATERIAL**

Motståndskraftig polypropylenbaserad (PP) teknopolymer, svart, matt yta.

STANDARDUTFÖRANDE

- **I.601+x**: gängad tapp i förzinkat stål, invändig sexkant i den gängade änden.
- **I.601+x-SST**: gängad tapp i AISI 303 rostfritt stål, invändig sexkant i den gängade änden.

**I.601+x**

Kod	Benämning	D	L	d _{6g}	d ₁	I	s	⚖
24921	I.601/40+x-M6	18	40	M6	15	13	3	25
24931	I.601/50+x-M6	21	50	M6	17	13	3	35
24941	I.601/56+x-M6	22	56	M6	18	13	3	40
24951	I.601/65+x-M8	23	65	M8	19	15	4	68
24952	I.601/65+x-M10	23	65	M10	19	17	5	70
24961	I.601/80+x-M8	26	80	M8	21	15	4	75
24962	I.601/80+x-M10	26	80	M10	21	17	5	78
24971	I.601/90+x-M10	28	90	M10	22	17	5	85
24972	I.601/90+x-M12	28	90	M12	22	20	5	100

I.601+x-SST

Kod	Benämning	D	L	d _{6g}	d ₁	I	s	⚖
24925	I.601/40+x-M6-SST	18	40	M6	15	13	3	25
24935	I.601/50+x-M6-SST	21	50	M6	17	13	3	35
24955	I.601/65+x-M8-SST	23	65	M8	19	15	4	68
24965	I.601/80+x-M10-SST	26	80	M10	21	17	5	78
24975	I.601/90+x-M10-SST	28	90	M10	22	17	5	85