

I.780 | Handtag

Teknopolymer



MATERIAL

Glasfiberförstärkt polyamidbaserad (PA) teknopolymer, svart eller röd färg, matt yta.


MONTERING

Gångat hål.

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18



ELESA Original design

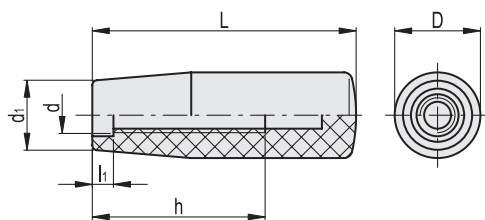

C9
 RAL9005
 C6
 RAL3000

Kod	Benämning	D	L	d	d1	h	l1	△
124791	I.780/65-M8-C9	24.5	65	M8	20.5	30	7	34
124801	I.780/65-M8-C6	24.5	65	M8	20.5	30	7	34
124792	I.780/65-M10-C9	24.5	65	M10	20.5	40	7	34
124806	I.780/80-M8-C9	26.5	80	M8	21	40	7	45
124807	I.780/80-M10-C9	26.5	80	M10	21	55	7	45
124812	I.780/80-M10-C6	26.5	80	M10	21	55	7	45
124808	I.780/80-M12-C9	26.5	80	M12	21	55	7	45
124817	I.780/90-M10-C9	28.5	90	M10	22.5	55	7	50
124818	I.780/90-M12-C9	28.5	90	M12	22.5	58	7	50
124822	I.780/90-M12-C6	28.5	90	M12	22.5	58	7	50

Handtag