



1

STANDARDUTFÖRANDE

- **SRH.**: förzinkat stål.
- **SRH-SST**: AISI 304 rostfritt stål.



2

FOTPLATTA

Svart neopren, hårdhet 85 Shore A.



3

MUTTRAR

Förzinkat stål eller AISI 304 rostfritt stål.



4



5



6



7



8



9



10



11



12



13



14



15



16



17



18



19



20



21



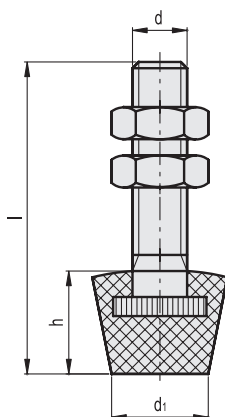
22



23



24

**SRH.**

Kod	Benämning	d	d1	h	l	⚖
GG.AU139	SRH.M4x25	M4	6	5	25	5
GG.AU140	SRH.M5x45	M5	10	11	45	9
GG.AU141	SRH.M6x55	M6	13	12	55	16
GG.AU142	SRH.M8x68	M8	16	16	68	33
GG.AU143	SRH.M10x80	M10	20	20	80	64
GG.AU144	SRH.M12x100	M12	24	25	100	95
GG.AU145	SRH.M12x130	M12	24	25	130	125

SRH-SST

Kod	Benämning	d	d1	h	l	⚖
GG.AU539	SRH-SST-M4x25	M4	6	5	25	5
GG.AU540	SRH-SST-M5x45	M5	10	11	45	9
GG.AU541	SRH-SST-M6x55	M6	13	12	55	16
GG.AU542	SRH-SST-M8x68	M8	16	16	68	33