

BEL-RB | Level bubbles

Ganter Norm GN 2276 for screw mounting, aluminium



SENSITIVITY

- **6**: movement of the bubble by 2 mm for an inclination of the body of 6 angle minutes with respect to the horizontal surface.
- **50**: movement of the bubble by 2 mm for an inclination of the body of 50 angle minutes with respect to the horizontal surface.

TYPES

- Type **AV**: aligned, mounting from the front side (not adjustable)
- Type **JV**: adjustable, mounting from the front side

Housing

Aluminium
 anodized, natural colour **AN**
 anodized, black **ANB**

Spirit level element
 Glass body

Contrast fluid
 green-transparent **G**

Casting compound
 mineral-based

See Bull's eye levels and screw-on levels technical data (on page 780).

FEATURES AND APPLICATIONS

BEL-RB bull's eye levels are used to control the horizontal positioning of jigs, machines, devices, equipment and instruments.

The spirit levels of type AV are aligned in relation to the reference surface so that the bubbles are centred in the middle of the marking lines once the horizontal position of the contact surface is reached.


The spirit levels of type JV are aligned using the fastening holes that are offset by 120°.

The adjustment pin in the lower part allows the adjustment of the bubbles acting as a fulcrum point. With careful tightening, it is possible to achieve an alignment that places the bubbles between the middle marking lines.


ON REQUEST

- Filling, colourless-transparent
- Other sensitivities

Application example

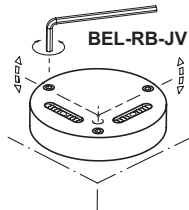

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
62	2.42

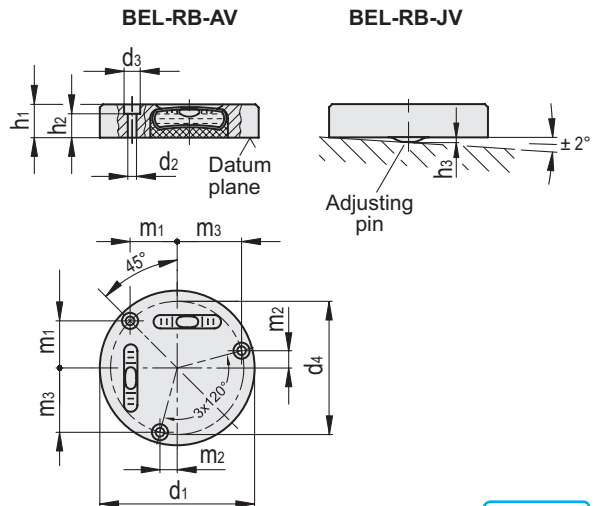

BEL-RB-AV

Code	Description	d1	d2	d3	d4	h1	h2	m1	m2	m3	△
156621	BEL-RB-AN-62-G-6-AV	62	3.4	6.3	52	13	9.8	18.4	6.7	25.1	95
156631	BEL-RB-ANB-62-G-6-AV	62	3.4	6.3	52	13	9.8	18.4	6.7	25.1	95
156625	BEL-RB-AN-62-G-50-AV	62	3.4	6.3	52	13	9.8	18.4	6.7	25.1	95
156635	BEL-RB-ANB-62-G-50-AV	62	3.4	6.3	52	13	9.8	18.4	6.7	25.1	95

BEL-RB-JV

Code	Description	d1	d2	d3	d4	h1	h2	h3	m1	m2	m3	△
156623	BEL-RB-AN-62-G-6-JV	62	3.4	6.3	52	13	9.8	1	18.4	6.7	25.1	95
156633	BEL-RB-ANB-62-G-6-JV	62	3.4	6.3	52	13	9.8	1	18.4	6.7	25.1	95
156627	BEL-RB-AN-62-G-50-JV	62	3.4	6.3	52	13	9.8	1	18.4	6.7	25.1	95
156637	BEL-RB-ANB-62-G-50-JV	62	3.4	6.3	52	13	9.8	1	18.4	6.7	25.1	95