




STANDARD EXECUTION

Handle I.280 in Duroplast, black colour, glossy finish, fixed to the chrome-plated steel arm, not removable.



ELESA Original design

Conversion Table			
1 mm = 0.039 inch			
A			
mm	inch	mm	inch
65	2.56	143	5.63
75	2.95	155	6.10
85	3.35	160	6.30
95	3.74	164	6.46
102	4.02	165	6.55
105	4.13	190	7.48
118	4.65	200	7.87
125	4.92	203	7.99

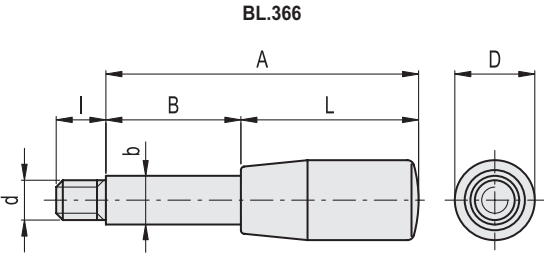

BL.366

Code	Description	A	D	L	d6g	B	b	I	⚖
3401	BL.366/8x65	65	14	28	M6	37	8	8	22
3402	BL.366/8x75	75	14	28	M6	47	8	8	25
3404	BL.366/8x95	95	14	28	M6	67	8	8	33
3500	BL.366/10x75	75	18	40	M8	35	10	9	40
3501	BL.366/10x65	65	18	40	M8	25	10	9	35
3502	BL.366/10x85	85	21	50	M8	35	10	9	48
3503	BL.366/10x95	95	21	50	M8	45	10	9	55
3504	BL.366/10x125	125	21	50	M8	75	10	9	73
3505	BL.366/10x155	155	21	50	M8	105	10	11	92
3601	BL.366/12x102	102	23	65	M10	37	12	14	80
3602	BL.366/12x118	118	23	65	M10	53	12	14	95
3603	BL.366/12x165	165	23	65	M10	100	12	14	138
3604	BL.366/12x203	203	23	65	M10	138	12	14	165
3701	BL.366/14x125	125	26	80	M12	45	14	15	130
3702	BL.366/14x160	160	26	80	M12	80	14	15	165
3703	BL.366/14x200	200	26	80	M12	120	14	15	220
3801	BL.366/16x105	105	28	90	M14	15	16	15	120
3802	BL.366/16x143	143	28	90	M14	53	16	15	178
3803	BL.366/16x164	164	28	90	M14	74	16	15	210
3804	BL.366/16x190	190	28	90	M14	100	16	15	252