



Fixed & Revolving handles


STANDARD EXECUTION

Handle I.222 in Duroplast, black colour, glossy finish, fixed to the chrome-plated steel arm, not removable.



ELESA Original design

Conversion Table			
1 mm = 0.039 inch			
A			
mm	inch	mm	inch
57	2.24	108	4.25
67	2.64	129	5.08
70	2.76	135	5.31
77	3.03	137	5.39
79	3.11	142	5.59
95	3.74	155	6.10
100	3.94	175	6.89
107	4.21	180	7.09

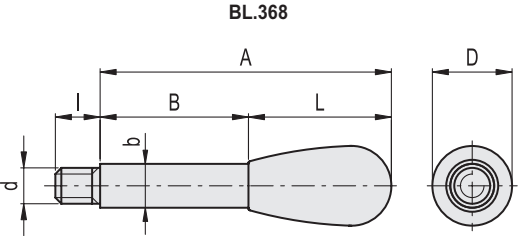

BL.368

Code	Description	A	D	L	d6g	B	b	l	△△
4001	BL.368/10x57	57	20	32	M8	25	10	9	33
4002	BL.368/10x67	67	20	32	M8	35	10	9	39
4003	BL.368/10x77	77	20	32	M8	45	10	9	45
4004	BL.368/10x107	107	20	32	M8	75	10	9	64
4005	BL.368/10x137	137	20	32	M8	105	10	11	83
4101	BL.368/12x79	79	26	42	M10	37	12	14	68
4102	BL.368/12x95	95	26	42	M10	53	12	14	82
4103	BL.368/12x142	142	26	42	M10	100	12	14	125
4104	BL.368/12x180	180	26	42	M10	138	12	14	157
4201	BL.368/14x100	100	33	55	M12	45	14	15	124
4202	BL.368/14x135	135	33	55	M12	80	14	15	160
4203	BL.368/14x175	175	33	55	M12	120	14	15	220
4301	BL.368/16x70	70	33	55	M14	15	16	15	100
4302	BL.368/16x108	108	33	55	M14	53	16	15	158
4303	BL.368/16x129	129	33	55	M14	74	16	15	190
4304	BL.368/16x155	155	33	55	M14	100	16	15	232