


STANDARD EXECUTION

Handle l.280 in Duroplast, black colour, glossy finish, fixed to the zinc-plated steel arm, not removable.



ELESA Original design

Conversion Table			
1 mm = 0.039 inch			
A			
mm	inch	mm	inch
65	2.56	143	5.63
75	2.95	155	6.10
85	3.35	160	6.30
95	3.74	164	6.46
102	4.02	165	6.55
105	4.13	190	7.48
118	4.65	200	7.87
125	4.92	203	7.99

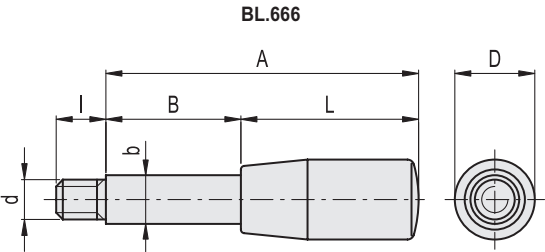

BL.666

METRIC

Code	Description	A	D	L	d6g	B	b	I	⚖
4406	BL.666/8x75	75	14	28	M6	47	8	8	25
4407	BL.666/8x95	95	14	28	M6	67	8	8	33
4411	BL.666/10x65	65	18	40	M8	25	10	9	35
4412	BL.666/10x75	75	18	40	M8	35	10	9	40
4413	BL.666/10x85	85	21	50	M8	35	10	9	48
4414	BL.666/10x95	95	21	50	M8	45	10	9	55
4415	BL.666/10x125	125	21	50	M8	75	10	9	73
4416	BL.666/10x155	155	21	50	M8	105	10	11	92
4421	BL.666/12x102	102	23	65	M10	37	12	14	80
4422	BL.666/12x118	118	23	65	M10	53	12	14	95
4423	BL.666/12x165	165	23	65	M10	100	12	14	138
4424	BL.666/12x203	203	23	65	M10	138	12	14	165
4431	BL.666/14x125	125	26	80	M12	45	14	15	130
4432	BL.666/14x160	160	26	80	M12	80	14	15	165
4433	BL.666/14x200	200	26	80	M12	120	14	15	220
4441	BL.666/16x105	105	28	90	M14	15	16	15	120
4442	BL.666/16x143	143	28	90	M14	53	16	15	178
4443	BL.666/16x164	164	28	90	M14	74	16	15	210
4444	BL.666/16x190	190	28	90	M14	100	16	15	252

Fixed & Revolving handles