

STANDARD EXECUTION

Handle I.622 in technopolymer, black colour, glossy finish, fixed to the zinc-plated steel arm, not removable.


SPECIAL EXECUTIONS ON REQUEST

Handles in different RAL colours.



ELESA Original design

Conversion Table			
1 mm = 0.039 inch			
A			
mm	inch	mm	inch
57	2.24	108	4.25
67	2.64	129	5.08
70	2.76	135	5.31
77	3.03	137	5.39
79	3.11	142	5.59
95	3.74	155	6.10
100	3.94	175	6.89
107	4.21	180	7.09

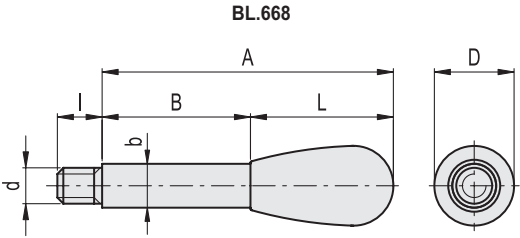

BL.668

Code	Description	A	D	L	d6g	B	b	l	△△
5011	BL.668/10x57	57	20	32	M8	25	10	9	31
5012	BL.668/10x67	67	20	32	M8	35	10	9	37
5013	BL.668/10x77	77	20	32	M8	45	10	9	43
5015	BL.668/10x107	107	20	32	M8	75	10	9	62
5016	BL.668/10x137	137	20	32	M8	105	10	11	81
5021	BL.668/12x79	79	26	42	M10	37	12	14	65
5022	BL.668/12x95	95	26	42	M10	53	12	14	79
5023	BL.668/12x142	142	26	42	M10	100	12	14	122
5024	BL.668/12x180	180	26	42	M10	138	12	14	154
5031	BL.668/14x100	100	33	55	M12	45	14	15	120
5032	BL.668/14x135	135	33	55	M12	80	14	15	156
5033	BL.668/14x175	175	33	55	M12	120	14	15	216
5041	BL.668/16x70	70	33	55	M14	15	16	15	96
5042	BL.668/16x108	108	33	55	M14	53	16	15	154
5043	BL.668/16x129	129	33	55	M14	74	16	15	186
5044	BL.668/16x155	155	33	55	M14	100	16	15	228