

MATERIAL

Zinc-plated steel

STANDARD EXECUTIONS

- **DCE-GU**: for use with DCE-S standard series (DIN 3015-1) and DCE-D double series (DIN 3015-3) tube clamps.
- **DCE-GU-H**: for use with DCE-H heavy-duty series tube clamps (DIN 3015-2).

FEATURES AND APPLICATIONS


Different C-profile dimensions to suit different DIN 3015 series. The guide is the ideal solution for creating modular structures for fixing tube clamps.

Length 2 m

ACCESSORIES

For the assembly kit DCK-S, DCK-H and DCK-D.

- DCE-S: standard series tube clamps.
- DCE-H: heavy-duty series tube clamps.
- DCE-D: double series tube clamps.
- DCE-PU: top plate.
- DCE-SRE: hexagonal-head screw.
- DCE-WA: flat washer.
- DCE-NTG: nut for mounting guide.

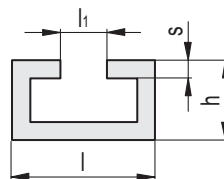

DCE-GU

METRIC

| Code | Description | l | l1 | h | s | For tube clamps | ⚖ |
|--------|----------------------|----|----|----|---|-----------------|------|
| 570511 | DCE-GU-28-11-2000-ZN | 28 | 11 | 11 | 2 | DCE-S - DCE-D | 847 |
| 570513 | DCE-GU-28-14-2000-ZN | 28 | 11 | 14 | 2 | DCE-S - DCE-D | 940 |
| 570515 | DCE-GU-28-30-2000-ZN | 28 | 11 | 30 | 2 | DCE-S - DCE-D | 1425 |

DCE-GU-H

| Code | Description | l | l1 | h | s | For tube clamps | ⚖ |
|--------|------------------------|----|----|----|---|-----------------|------|
| 570521 | DCE-GU-H-40-22-2000-ZN | 40 | 13 | 22 | 5 | DCE-H | 3227 |