

# DIN 39 | Shaped handles

Steel or stainless steel



- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

## MATERIAL


Turned and mirror polished steel.

## STANDARD EXECUTION

- **DIN 39-ST**: turned and mirror polished steel.
- **DIN 39-A4**: AISI 316L stainless steel.

## SPECIAL EXECUTIONS ON REQUEST

h8 plain pin (DIN 39-D).

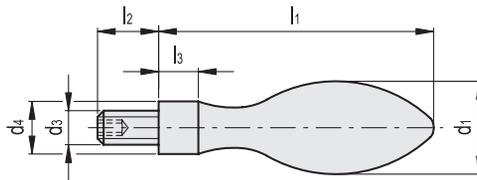

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
16	0.63
20	0.79
25	0.98
32	1.26
36	1.42

## DIN 39-ST



Code	Description	d1	d3	d4 h13	l1	l2	l3	⚖
GN.10935	DIN 39-ST-16-E	16	M6	10	50	11	7	45
GN.10955	DIN 39-ST-20-E	20	M8	13	64	13	8	91
GN.10975	DIN 39-ST-25-E	25	M10	16	80	14	10	177
GN.10995	DIN 39-ST-32-E	32	M12	20	100	21	13	360
GN.10998	DIN 39-ST-36-E	36	M16	22	112	26	14	526

## DIN 39-A4



Code	Description	d1	d3	d4 h13	l1	l2	l3	⚖
GN.10911	DIN 39-A4-16-E	16	M6	10	50	11	7	40
GN.10914	DIN 39-A4-20-E	20	M8	13	64	13	8	100
GN.10917	DIN 39-A4-25-E	25	M10	16	80	14	10	177

Fixed & Revolving handles