

**CABLE**

Cable with grey PVC sheath  $\varnothing$  5.8 mm, 2.5 or 5 m long.

**CONNECTOR (PROTECTION IP67)**

8 pole M12x1 female connector with polyamide-based (PA) technopolymer housing and contact holder.

**NUT**

AISI 316 stainless steel nut.


**COMPATIBILITY**

ESC-SFT: handles with built-in safety switch (see page -).



Technical data	
<b>Conductors cross-section</b>	6xAWG 24 STYLE 2517
<b>Maximum applicable voltage</b>	30Vac/dc
<b>Maximum current intensity</b>	1A
<b>Insulation resistance</b>	$\geq 100M\Omega$ 500VDC
<b>Working temperature</b>	-25°C, +80°C
<b>Protection class</b>	IP67 *

\* With the connector properly screwed

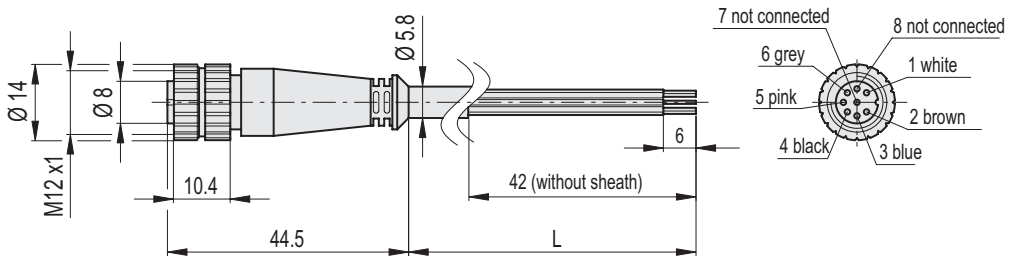

Handles

1

Code	Description	L	$\Delta$
426513	FC-ESC-P8-2.5	2500	225
426516	FC-ESC-P8-5.0	5000	423