

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

**CABLE**

Shielded cable with PVC sheath, bend radius in fixed position  $\geq 50$  mm.

**CONNECTORS**

Male and female SMA-RP connectors.

**APPLICATIONS**


If the extension is used as a spare part in an existing equipment, please contact the EleSa technical service to check its compatibility.

**SPECIAL EXECUTIONS ON REQUEST**

Extensions with cables in different lengths.



Mechanical and electrical characteristics	
Impedance	50 Ohm
Working temperature	-40 °C + 70 °C

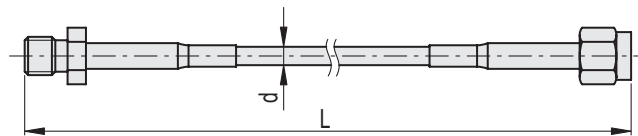

Position indicators

2

**METRIC**

Code	Description	L $\pm$ 50	d $\pm$ 0.5	$\Delta$
CE.99263	FC-UC-1.0-R	1000	3	48
CE.99265	FC-UC-2.5-R	2500	5	106
CE.99267	FC-UC-5.0-R	5000	5	208
CE.99269	FC-UC-10.0-R	10000	5	206