

RINGS (SUPPLIED NOT ASSEMBLED)

Stainless steel.

CLAMPING PLATE

Stainless steel.


SPIRAL CABLE

Polyurethane (PUR) black colour.

FEATURES AND APPLICATIONS

GN 111.4 spiral retaining cables are mainly used in combination with the different types of self-locking pins.

The load values shown in the table have to be considered as purely indicative.

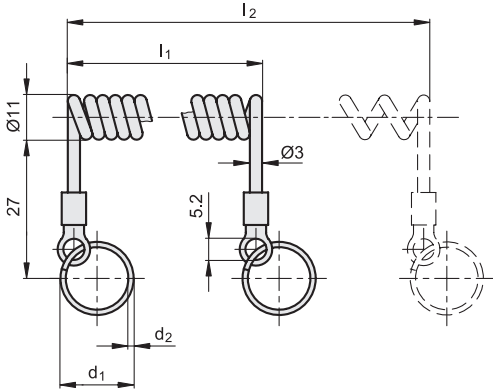

Conversion Table	
1 mm = 0.039 inch	
mm	inch
50	1.97
100	3.94
200	7.87

Code	Description	d1	d2	l1 min	l2 max	Static load with ring [N]	Static load without ring [N]	⚖
GN.11391	GN 111.4-50-14	14*	1	50	250	50	60	10
GN.11392	GN 111.4-50-18	18**	1.3	50	250	60	60	10
GN.11393	GN 111.4-50-24	24	1.5	50	250	60	60	10
GN.11394	GN 111.4-100-14	14*	1	100	500	50	60	10
GN.11395	GN 111.4-100-18	18**	1.3	100	500	60	60	15
GN.11396	GN 111.4-100-24	24	1.5	100	500	60	60	15
GN.11397	GN 111.4-200-14	14*	1	200	1000	50	60	15
GN.11398	GN 111.4-200-18	18**	1.3	200	1000	60	60	15
GN.11399	GN 111.4-200-24	24	1.5	200	1000	60	60	18

* Suitable for the following lock pins: GN 124 only Ø6, Ø8; GN 113.1, GN 113.3, GN 113.5, GN 113.6, GN 113.7, GN 113.8, GN 114.2, GN 114.3, GN 114.6 all the Ø.

** Suitable for the following lock pins: GN 124 only Ø10, Ø12, Ø16.