

MAIN SPECIFICATIONS



Buckle
Steel, black lacquered **ST**
Stainless Steel AISI 304 **NI**

Strap
Polypropylene
Woven
Black **SW**

FEATURES AND APPLICATIONS

Lashing straps GN 1110 are used in various applications to tightly fasten and secure material.

Application example

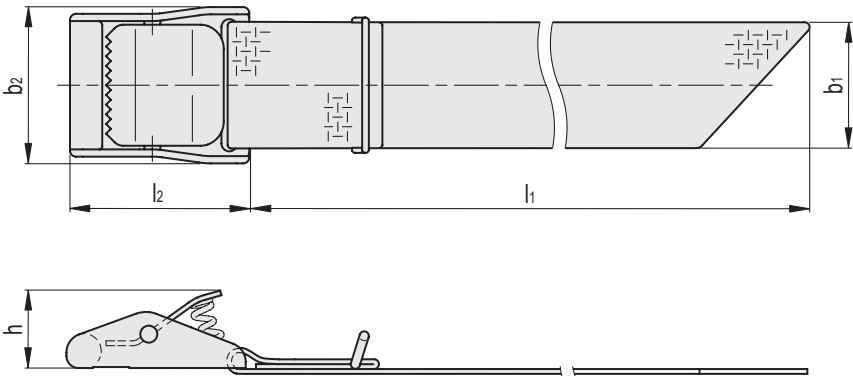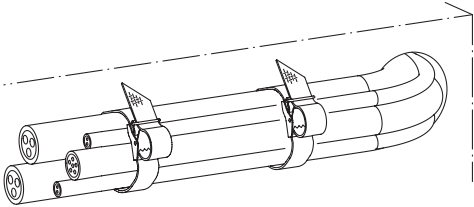

Conversion Table	
1 mm = 0.039 inch	
	l2
mm	inch
39	1.52

GN 1110-ST

METRIC

Code	Description	l1	l2	h	b1	b2	Max. load carrying capacity [kN]	⚖
GN.11181	GN 1110-25-250-ST-SW	250	39	16	25	32	4	31
GN.11183	GN 1110-25-400-ST-SW	400	39	16	25	32	4	34
GN.11185	GN 1110-25-600-ST-SW	600	39	16	25	32	4	39
GN.11187	GN 1110-25-1000-ST-SW	1000	39	16	25	32	4	48
GN.11189	GN 1110-25-1500-ST-SW	1500	39	16	25	32	4	60

GN 1110-NI

INOX STAINLESS STEEL

Code	Description	l1	l2	h	b1	b2	Max. load carrying capacity [kN]	⚖
GN.11182	GN 1110-25-250-NI-SW	250	39	16	25	32	6	34
GN.11184	GN 1110-25-400-NI-SW	400	39	16	25	32	6	38
GN.11186	GN 1110-25-600-NI-SW	600	39	16	25	32	6	42
GN.11188	GN 1110-25-1000-NI-SW	1000	39	16	25	32	6	51
GN.11190	GN 1110-25-1500-NI-SW	1500	39	16	25	32	6	63