

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14**
- 15
- 16
- 17
- 18
- 19

VERSIONS

- Version **SW9**: with two wrench flats SW9
- Version **SW13**: with two wrench flats SW13

Plastic

Technopolymer (Polyamide PA) **PA**

- Glass fiber reinforced
- Blue **BL**



FEATURES AND APPLICATIONS

Socket keys GN 1151 can be used to operate latches in hygienic areas. The material used protects the drive surface from damage.


The bore d2 serves for storing the socket key near the place of use, for example, or can be used to attach a key ring or retaining cable to prevent loss.



Application example

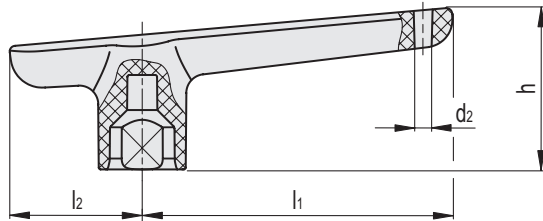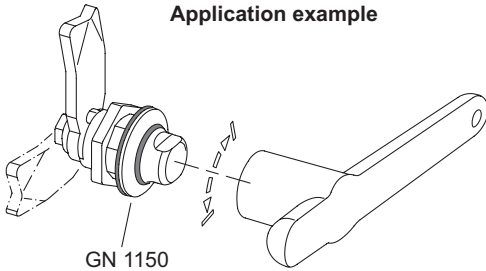

Conversion Table	
1 mm = 0.039 inch	
l1	
mm	inch
82	3.20

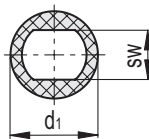

METRIC

Code	Description	l1	h	d1	d2	l2	sw	For latches	△△
GN.11152	GN 1151-82-SW9-PA-BL	82	42.7	23	5	35	9	GN 1150	34
GN.11157	GN 1151-82-SW13-PA-BL	82	42.7	23	5	35	13	GN 1150 / GN 115-AZ13	34

Latches

1