

TYPES

- Type **H**: vertically adjustable
- Type **B**: horizontally adjustable
- Type **HB**: vertically and horizontally adjustable

Die-cast zinc alloy
epoxy resin coating

black, RAL 9005, matte finish

SW

silver, RAL 9006, matte finish

SR

AISI 316 stainless steel

A4

matte shot-blasted

GS


Rotating pin

AISI 316Ti stainless Steel


FEATURES AND APPLICATIONS

With hinges GN 127 doors and covers can be positioned snugly and in a finely adjusted manner by moving the adjusting bushings. In this way, door gaps can be readjusted and manufacturing tolerances can be compensated. The arrowheads mark the middle of the adjustable range w.


The Stainless Steel variants are also generally suited for applications under especially aggressive conditions.

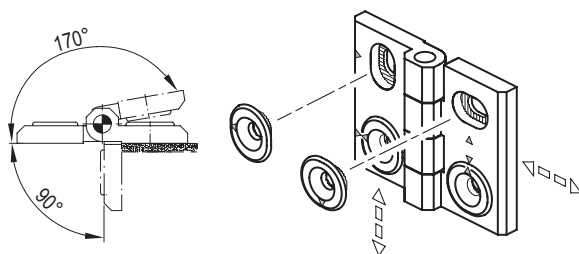


GN 127-H

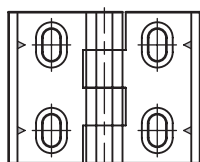


GN 127-B

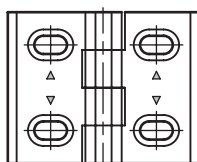

GN 127-HB

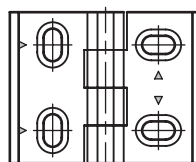

Conversion Table	
1 mm = 0.039 inch	
l2	
mm	inch
40	1.56
50	1.95
60	2.34

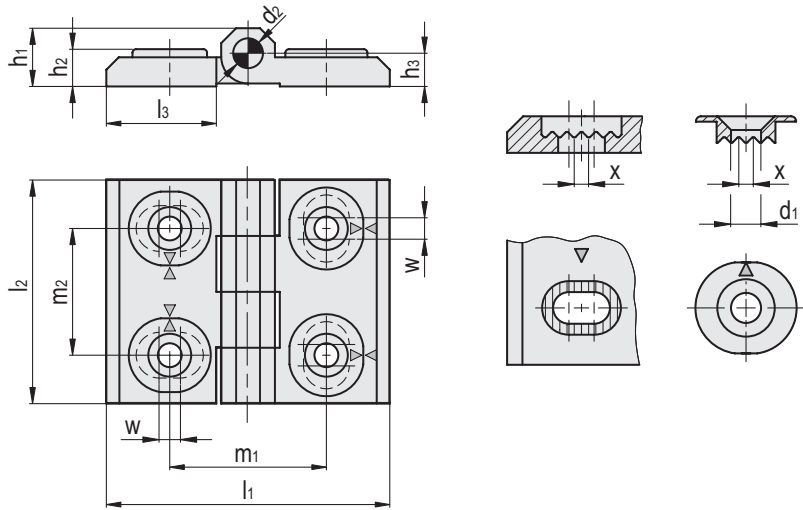

GN 127-H

METRIC

Code	Description	h1	l1	l2	d1	d2	h2	h3	l3	m1	m2	x	w	
GN.79041	GN 127-ZD-52-40-H-SW	9.5	52	40	4.5	4	6	5.5	22	30	22	0.5	2	69
GN.79061	GN 127-ZD-64-50-H-SW	11.5	64	50	5.5	6	6.5	7.5	28	37	27	0.75	3	115
GN.79081	GN 127-ZD-76-60-H-SW	15	76	60	6.5	8	9	8.5	33.5	42	34	1	4	205
GN.79039	GN 127-ZD-52-40-H-SR	9.5	52	40	4.5	4	6	5.5	22	30	22	0.5	2	69
GN.79059	GN 127-ZD-64-50-H-SR	11.5	64	50	5.5	6	6.5	7.5	28	37	27	0.75	3	115
GN.79079	GN 127-ZD-76-60-H-SR	15	76	60	6.5	8	9	8.5	33.5	42	34	1	4	205

GN 127-B

Code	Description	h1	l1	l2	d1	d2	h2	h3	l3	m1	m2	x	w	
GN.79033	GN 127-ZD-52-40-B-SW	9.5	52	40	4.5	4	6.5	5.5	22	30	22	0.5	2	69
GN.79053	GN 127-ZD-64-50-B-SW	11.5	64	50	5.5	6	7	7.5	28	37	27	0.75	3	115
GN.79073	GN 127-ZD-76-60-B-SW	15	76	60	6.5	8	9	8.5	33.5	42	34	1	4	205
GN.79031	GN 127-ZD-52-40-B-SR	9.5	52	40	4.5	4	6.5	5.5	22	30	22	0.5	2	69
GN.79051	GN 127-ZD-64-50-B-SR	11.5	64	50	5.5	6	7	7.5	28	37	27	0.75	3	115
GN.79071	GN 127-ZD-76-60-B-SR	15	76	60	6.5	8	9	8.5	33.5	42	34	1	4	205

GN 127-HB

Code	Description	h1	l1	l2	d1	d2	h2	h3	l3	m1	m2	x	w	
GN.79037	GN 127-ZD-52-40-HB-SW	9.5	52	40	4.5	4	6.5	5.5	22	30	22	0.5	2	69
GN.79057	GN 127-ZD-64-50-HB-SW	11.5	64	50	5.5	6	7	7.5	28	37	27	0.75	3	115
GN.79077	GN 127-ZD-76-60-HB-SW	15	76	60	6.5	8	9	8.5	33.5	42	34	1	4	205
GN.79035	GN 127-ZD-52-40-HB-SR	9.5	52	40	4.5	4	6.5	5.5	22	30	22	0.5	2	69
GN.79055	GN 127-ZD-64-50-HB-SR	11.5	64	50	5.5	6	7	7.5	28	37	27	0.75	3	115
GN.79075	GN 127-ZD-76-60-HB-SR	15	76	60	6.5	8	9	8.5	33.5	42	34	1	4	205

GN 127-A4-H

INOX STAINLESS STEEL

METRIC

Code	Description	h1	l1	l2	d1	d2	h2	h3	l3	m1	m2	x	w	
GN.79005	GN 127-A4-52-40-H-GS	9.5	52	40	4.5	4	6	5.5	22	30	22	1	2	78
GN.79015	GN 127-A4-64-50-H-GS	11.5	64	50	5.5	6	7	6.5	28	37	27	1.5	3	140
GN.79025	GN 127-A4-76-60-H-GS	15	76	60	6.5	8	9	8.5	33.5	42	34	2	4	259

GN 127-A4-B

Code	Description	h1	l1	l2	d1	d2	h2	h3	l3	m1	m2	x	w	
GN.79001	GN 127-A4-52-40-B-GS	9.5	52	40	4.5	4	6	5.5	22	30	22	1	2	76
GN.79011	GN 127-A4-64-50-B-GS	11.5	64	50	5.5	6	7	6.5	28	37	27	1.5	3	137
GN.79021	GN 127-A4-76-60-B-GS	15	76	60	6.5	8	9	8.5	33.5	42	34	2	4	253

GN 127-A4-HB

Code	Description	h1	l1	l2	d1	d2	h2	h3	l3	m1	m2	x	w	
GN.79003	GN 127-A4-52-40-HB-GS	9.5	52	40	4.5	4	6	5.5	22	30	22	1	2	77
GN.79013	GN 127-A4-64-50-HB-GS	11.5	64	50	5.5	6	7	6.5	28	37	27	1.5	3	138
GN.79023	GN 127-A4-76-60-HB-GS	15	76	60	6.5	8	9	8.5	33.5	42	34	2	4	256