

GN 131-NI

Two-way connecting clamps

Stainless steel



MATERIAL


Stainless steel, matte finish.
AISI 304 stainless steel screws and nuts.

FEATURES AND APPLICATIONS


The assembly holes of GN 131-NI connecting clamps allow an excellent match with tubes GN 990 (see page 1954).
The clamping screws d3 may be replaced by clamping kits GN 911 (see page 1958).

SPECIAL EXECUTIONS ON REQUEST

Different combinations of holes d1/d2.

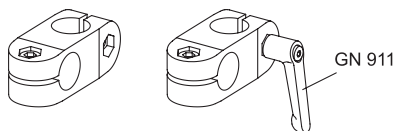

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
12	0.46
14	0.55
15	0.59
16	0.63
18	0.71
20	0.79

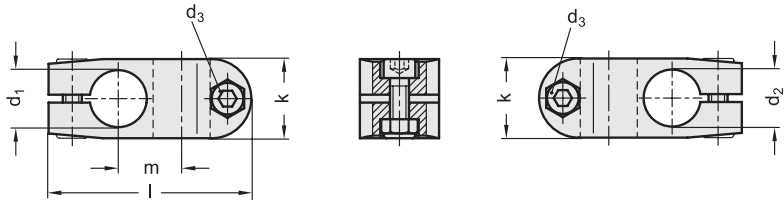

Code	Description	d1	d2	d3	k	l	m	d3	⚖
								Clamping kit	
GN.42033	GN 131-B12-B12-2-NI	12	12	M6	25	64	20	GN 911-M6-22	203
GN.42053	GN 131-B14-B14-2-NI	14	14	M6	25	64	20	GN 911-M6-22	180
GN.42073	GN 131-B15-B15-2-NI	15	15	M6	25	64	20	GN 911-M6-22	190
GN.42093	GN 131-B16-B16-2-NI	16	16	M6	25	64	20	GN 911-M6-22	170
GN.42113	GN 131-B18-B18-2-NI	18	18	M6	25	64	20	GN 911-M6-22	148
GN.42123	GN 131-B20-B20-2-NI	20	20	M6	25	64	20	GN 911-M6-22	144