

MATERIAL


Aluminium, matte finish.
AISI 304 stainless steel screws and nuts.

STANDARD EXECUTIONS




Surface finish index:
- **BL**: natural colour.
- **SW**: epoxy resin coating resistant to UV rays, RAL 9005 black colour.

FEATURES AND APPLICATIONS

The assembly hole of GN 146.3 connecting clamps allows an excellent match with tubes GN 990 (see page 1368).
The clamping screw d3 may be replaced by clamping kit GN 911 (see page 1372).

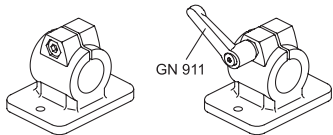

Conversion Table 1 mm = 0.039 inch	
d1	
mm	inch
20	0.78
25	0.98
30	1.17
32	1.25
35	1.37
40	1.56

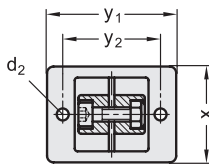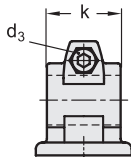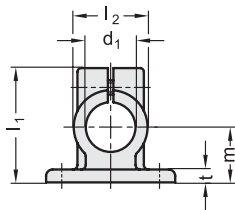

Code BL	Code SW	Description	d1	d2	d3	k	l1	l2	m	t	x	y1	y2	d3 Clamping kit	△
GN.46711	GN.46716	GN 146.3-B20-40-2-*	20	6.5	M8	40	62	40	30	7	52	70	53	GN 911-M8-32	180
GN.46731	GN.46736	GN 146.3-B25-40-2-*	25	6.5	M8	40	62	40	30	7	52	70	53	GN 911-M8-32	180
GN.46751	GN.46756	GN 146.3-B30-40-2-*	30	6.5	M8	40	62	40	30	7	52	70	53	GN 911-M8-32	160
GN.46771	GN.46776	GN 146.3-B30-56-2-*	30	8.5	M10	56	83	56	42	10	78	108	82	GN 911-M10-40	510
GN.46791	GN.46796	GN 146.3-B32-56-2-*	32	8.5	M10	56	83	56	42	10	78	108	82	GN 911-M10-40	480
GN.46811	GN.46816	GN 146.3-B35-56-2-*	35	8.5	M10	56	83	56	42	10	78	108	82	GN 911-M10-40	480
GN.46831	GN.46836	GN 146.3-B40-56-2-*	40	8.5	M10	56	83	56	42	10	78	108	82	GN 911-M10-40	440

* Complete the description of the standard item needed by adding the finish of the connector clamps: BL (blank) or SW (black).