



- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

**MATERIAL**

Aluminium, epoxy resin coating, RAL 9005 black colour, matte finish.  
 AISI 304 stainless steel screws and nuts.  
 Connector nut in natural steel.

**FEATURES AND APPLICATIONS**

GN 147.1 connecting clamps can normally be matched with square linear actuators GN 291.1 (see page 1376).  
 By clamping the guide hole *s* it is possible to adjust the actuator positioning and to lock the slider after having set up the final position.  
 The clamping screws *d2* may be replaced by clamping kits GN 911 (see page 1372).

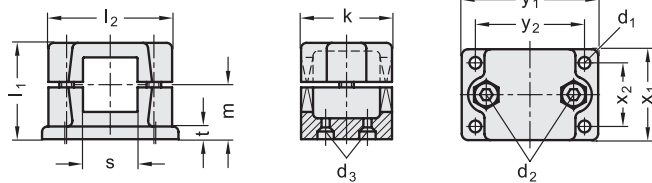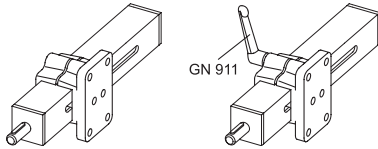

Conversion Table	
1 mm = 0.039 inch	
s	
mm	inch
30	1.18
40	1.57
50	1.97

**METRIC**

Code	Description	s		d2	d3	k	l1	l2	m	t	x1	x2	y1	y2	d2 Clamping kit	Δ
		d1	Square hole													
GN.47506	GN 147.1-V30-2-SW	6.5	30	M8	M4	50	53	68	30	7	50	35	75	60	GN 911-M8-45	221
GN.47516	GN 147.1-V40-2-SW	11	40	M10	M5	76	81.5	98	46.5	14	76	50	115	90	GN 911-M10-70	643
GN.47526	GN 147.1-V50-2-SW	11	50	M10	M6	76	81.5	98	46.5	14	76	50	115	90	GN 911-M10-70	595